


PXMBNI23FPM12ASC Datasheet

Product Name // M23 Series A Code Brass Nickel Plated
M20 Front Panel Mount Connector 12 Contact Pins

[View Product Page](#)

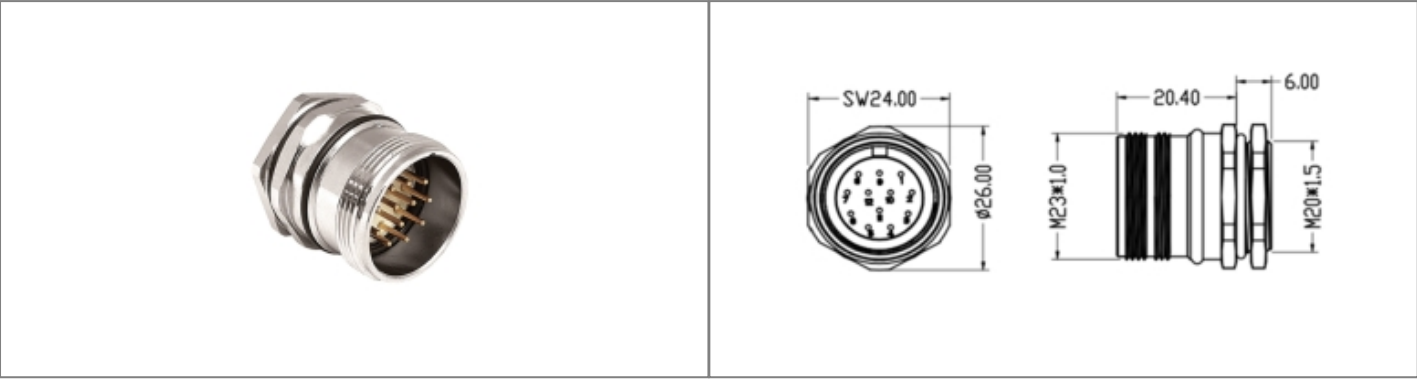

// Product Description:

- M23 Series Panel Mount Connectors
 - Water and dustproof to IP67 when mated with compatible connector
 - A Code
 - Front Panel Mount
- 12, 19 Contact
 - Solder Terminals
 - Mate with M23 Series Inline Body and Flex Body Connectors, depending on part code

// General Information:

Product Display Title:	M23 Series Panel Mount Connectors
Product Family:	Circular Automation Connectors
Product Series:	M23 Series
Change Notes:	PRODUCT-MOQ-ADJUSTMENT
Body Material:	Brass - Nickel Plated
Contact Type:	Plug Contact
Coupling Type:	Screw
Current Max:	8A
Diameter Over Coupling Ring Mm:	26mm
Function:	Front Panel Mount Connector
Ip Rating:	IP67
M12 Series Mounting Nut:	M20
Max Operating Temperature:	+80°C
Min Operating Temperature:	-25°C
Number Of Contacts:	12 Contacts
Pin Layout Code:	A Code
Thread Size:	M23 x 1
Voltage Max:	200V

// Product PDF Links



// Product 3D CAD Model Links



Have a question or project enquiry
you'd like to talk to us about?



[Click Here To Contact Us](#)