

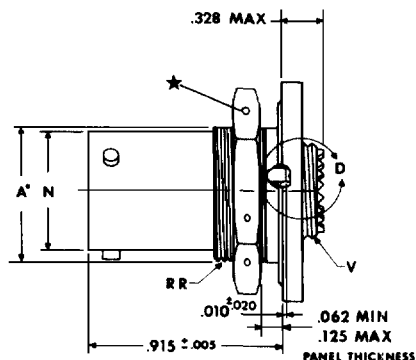
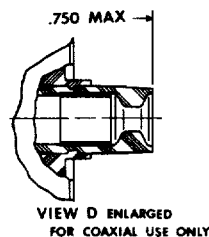


LJT07R (MS27468) — crimp jam nut receptacle

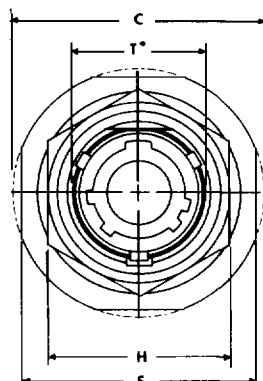

*LJT07RE-XX-XXX (MS27468E)

*LJT07RT-XX-XXX (MS27468T)

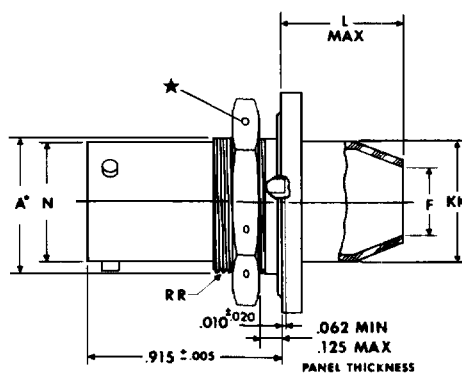

*LJT07RP-XX-XXX (MS27468P)

- ★ .059 dia min. 3 lockwire holes.
- Formed lockwire hole design (6 holes) is optional.
- "D" shaped mounting hole dimensions.
- * To complete order number see page 47.

Shell Size	RR Thread Class 2A (Plated)	N +.001 -.005	A* +.000 -.010	T* +.010 -.000	C Max.	H Hex +.017 -.016	S ±.016	V Thread Class 2A (Plated)	KK Dia. Max.	F Dia.	L Max.
9	.6875-24UNEF	.572	.669	.697	1.199	.875	1.062	.4375-28UNEF	.608	.327	.625
11	.8125-20UNEF	.700	.769	.822	1.386	1.000	1.250	.5625-24UNEF	.734	.444	.625
13	1.0000-20UNEF	.850	.955	1.007	1.511	1.188	1.375	.6875-24UNEF	.858	.558	.625
15	1.1250-18UNEF	.975	1.084	1.134	1.636	1.312	1.500	.8125-20UNEF	.984	.683	.625
17	1.2500-18UNEF	1.100	1.208	1.259	1.761	1.438	1.625	.9375-20UNEF	1.110	.808	.625
19	1.3750-18UNEF	1.207	1.333	1.384	1.949	1.562	1.812	1.0625-18UNEF	1.234	.909	.656
21	1.5000-18UNEF	1.332	1.459	1.507	2.073	1.688	1.938	1.1875-18UNEF	1.360	1.034	.750
23	1.6250-18UNEF	1.457	1.580	1.634	2.199	1.812	2.062	1.3125-18UNEF	1.484	1.159	.750
25	1.7500-18UNS	1.582	1.709	1.759	2.323	2.000	2.188	1.4375-18UNEF	1.610	1.284	.750

All dimensions for reference only.