




&lt; List of part numbers with package codes &gt;

LLA219R60J105MA01L, LLA219R60J105MA01K

## Shape

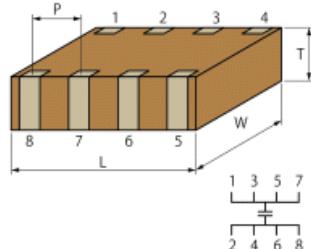

L size	$2.0 \pm 0.1\text{mm}$
W size	$1.25 \pm 0.1\text{mm}$
T size	$0.85 \pm 0.1\text{mm}$
Distance between external terminals P	$0.5 \pm 0.05\text{mm}$
Size code in inch(mm)	0805 (2012M)

## References

Packaging	Specifications	Minimum quantity
L	$\phi 180\text{mm}$ Embossed taping	3000
K	$\phi 330\text{mm}$ Embossed taping	10000

Mass (typ.)	
1 piece	11mg
$\phi 180\text{mm}$ Reel	162g

## Specifications

Capacitance	$1.0\mu\text{F} \pm 20\%$
Rated voltage	6.3Vdc
Temperature characteristics (complied standard)	X5R(EIA)
Capacitance change rate	$\pm 15.0\%$
Temperature range of temperature characteristics	-55 to 85°C
Operating temperature range	-55 to 85°C

### Attention

1. This datasheet is downloaded from the website of Murata Manufacturing Co., Ltd. Therefore, its specifications are subject to change or our products in it may be discontinued without advance notice. Please check with our sales representatives or product engineers before ordering.

2. This datasheet has only typical specifications because there is no space for detailed specifications.

Therefore, please review our product specifications or consult the approval sheet for product specifications before ordering.