


PXPPAM08FBF04AST Datasheet

Product Name // M8 Series A Code Polyamide PG7 Flex
Body 4 Contact Socket

 [View Product Page](#)

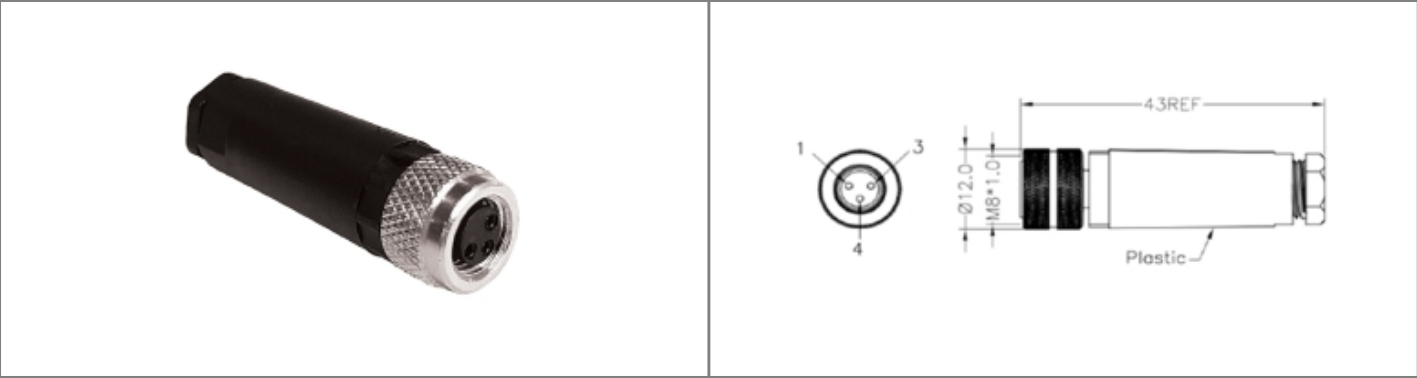

// Product Description:

- M8 Series Plastic Flex Body Connectors
- Water and dustproof to IP67 when mated with compatible connector
- A Code
- Socket only
- 3, 4 Contact
- Screw Terminals
- Mate with M8 Series Inline Body and Panel Mount Connectors

// General Information:

Product Display Title:	M8 Series Plastic Flex Body Connectors
Product Family:	Circular Automation Connectors
Product Series:	M8 Series
Approvals:	CSA, UL, RCM
Body Material:	Polyamide (PA)
Contact Type:	Socket Contact
Coupling Type:	Screw
Current Max:	3A
Diameter Over Coupling Ring Mm:	12.5mm
Function:	Flex Cable Connector Body
Ip Rating:	IP67
M12 Series Mounting Nut:	PG7
Max Operating Temperature:	+80°C
Min Operating Temperature:	-25°C
Number Of Contacts:	4 Contacts
Pin Layout Code:	A Code
Rohs Compliant:	Yes
Thread Size:	M8 x 1
Voltage Max:	30V

// Product PDF Links



// Product 3D CAD Model Links



Have a question or project enquiry
you'd like to talk to us about?



[Click Here To Contact Us](#)