

Image for illustrative purpose only

Summary

[Request a quote](#)

[Catalog](#)

Protocol	USB 2.0 (480Mb/s)
Wire Size/AWG	26 - 22
Gender	Reverse Gender
Socket / Receptacle	Socket / Receptacle - Free
Locking system	Push-pull
Jacket cable outside diameter [mm]	4.60 - 5.00 mm
Size	0T
Series	T - Small Outdoor keyed

https://www.lemo.com/int_en/solutions/originals/t-outdoor-keyed/phl-0t-304-cycc50.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

R (max)	6.1 mOhm
Rated current	7 A
Vtest (contact-contact)	1350 V (AC), 1910 V (DC)
Vtest (contact-shell)	1100 V (AC), 1560 V (DC)
Contact retention	22 N
Contact Type	Crimp
Max. Conductor	0.34 mm ² (AWG 22)
Min. Conductor	0.14 mm ² (AWG 26)
Bucket Dia.	0.8 mm (0.031in)
Contact Dia.	0.7 mm (0.028in)
Protocol	USB 2.0 (480Mb/s)
Wire Size/AWG	26 - 22
Gender	Reverse Gender

Form & Material

Shell style / Model id	PH - Free receptacle, cable collet
Socket / Receptacle	Free
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	2 keys (gamma=80, plug: female contacts, receptacle: male contacts)
Colour	Grey

https://www.lemo.com/int_en/solutions/originals/t-outdoor-keyed/phl-0t-304-cycc50.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Environment

Technical domain	Energy and Industrial, Test and Measurement
Environmental sealing (IP rating)	IP68
Temperature range	-55°C / +200°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Resistance to vibration	15 g [10 Hz - 2000 Hz]
Shock Resistance	100 g [6 ms]
Salt Spray Corrosion	>1000 hr

Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	4.60 - 5.00 mm

Recommended By Lemo

Accessories

Replacement contact	FGG.0B.555.ZZC
Compatible cap	BRF.0T.200.CAZ


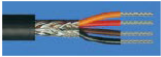

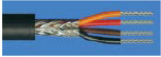

Tools

Spanner	DCP.0T.110.TN
Positionner	DCE.91.070.BVC
Extraction tool	DCC.07.04B.LAG
Crimp tool	DPC.91.701.V

https://www.lemo.com/int_en/solutions/originals/t-outdoor-keyed/phl-0t-304-cycc50.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Cables

Cable PartNumber	Material	Colour	Cable image
CMN.04.T22.047QGC	TPR	Grey	
CMN.04.T22.048QGZE	TPR (medical)	Grey	
140240	PVC	Black	
140250	PVC	Grey	
40260	PVC	Black	
4221	PVC	Black	
80080	PVC	Grey	
80082	PVC	Red	
80084	PVC	Black	

https://www.lemo.com/int_en/solutions/originals/t-outdoor-keyed/phi-0t-304-cycc50.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.