

Actuator

45-
2134.1150.000



<https://eao.com/p/45-2134.1150.000>

Your product:



45-2134.1150.000 Actuator

FRONT

Front dimension:	Ø 29,5 mm
Front bezel colour:	Black
Front bezel material:	Plastic

MOUNTING

Design:	raised
----------------	--------

OPERATING-/INDICATION PART

Lens illumination:	non illuminative
Lens colour:	Green
Lens shape:	flush
Lens material:	Plastic
Lens optics:	opaque

MECHANICAL CHARACTERISTIC

Weight:	0.024 kg
Switching action:	Maintained
Switching system:	Slow-make switching element
Mechanical lifetime:	10 Mio. cycles of operation

AMBIENT CONDITION

IP front protection:	IP66, IP67, IP69K
-----------------------------	-------------------

Operating temperature: – 25 °C ... + 70 °C

Storage temperature: – 40 °C ... + 80 °C

Climate resistance: During operation according to IEC 60721: 3K6, 3C3, 3S2, 3M6

Vibration resistance: According to IEC 60068-2-6: 20 ... 500 Hz: 5 g

Shock resistance: According to IEC 60068-2-27: Sinusoidal half-wave 50 g / 11 ms

OTHER


Housing colour: Black

Housing material: Plastic


Short Description: Actuator, Ø 29,5 mm, flush, non illuminative, Green, Plastic, opaque, Black, Plastic, Maintained, IP66, IP67, IP69K

Hints: Push to unlatch


Dimension drawings:

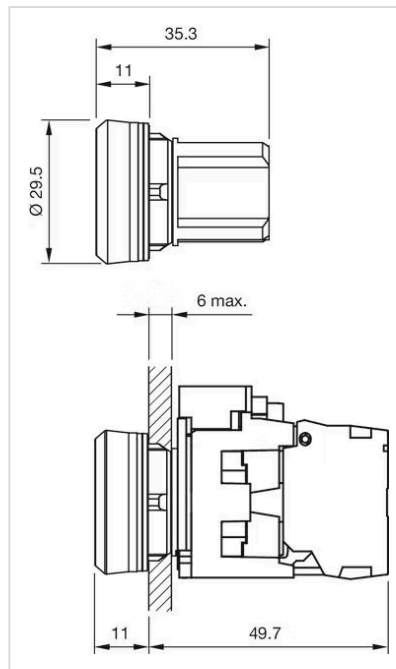

Mounting cut-outs:

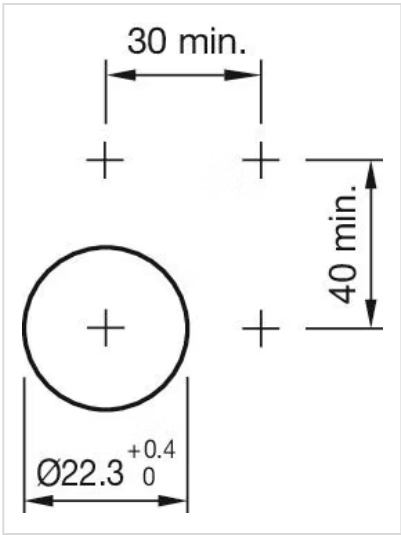

Wiring diagrams:

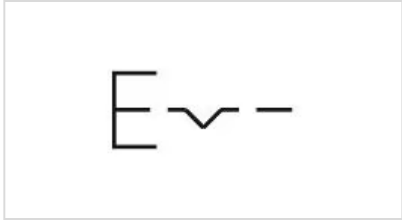

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[EAO:](#)

[45-2134.1150.000](#)