


PXMBNI08RAM03APCM8 Datasheet

Product Name // PXMBNI08RAM03APCM8

 [View Product Page](#)

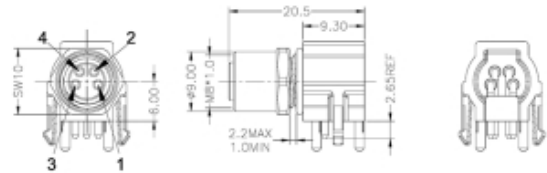

// Product Description:

- Material=Metal
- Pins=3
- Max Rating=60Vac
- Ingress Protection=IP67
- Operating Temperature= -25°C to +85°C
- Termination=Solder Tags
- Contact Resistance=5? max.
- Insulation Resistance=>100M?
- Mechanical Cycles=100 (min)

// General Information:

Product Display Title:	M12 Right Angle Rear Panel Mount
Product Family:	Circular Automation Connectors
Product Series:	M8 Series
Body Material:	Brass - Nickel Plated
Contact Type:	Plug Contact
Number Of Contacts:	3 Contacts

// Product PDF Links

 M8 Series automation connectors...

// Product 3D CAD Model Links

 PXMBNI08RAM03APCM8 3D CAD Model



Have a question or project enquiry
you'd like to talk to us about?



[Click Here To Contact Us](#)