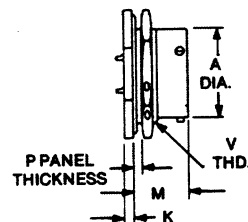
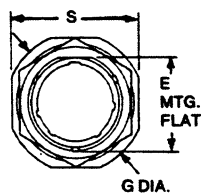
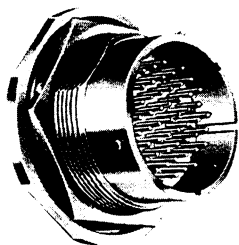


Jam Nut Receptacle


MS 3114H

KPT07H


KPTH/
PVAH

Shell Size	A	E	G	K	M	P		S	V
	± .003 (0.08)	± .005 (0.13)	Max.	+ .001 (0.03) - .016 (0.41)	± .015 (0.38)	Min.	Max.	Max.	
8	.471 (11.96)	.525 (13.34)	1.078 (27.38)	.094 (2.39)	.707 (17.96)	.062 (1.57)	.125 (3.18)	.954 (24.23)	9/16-24UNEF-2A
10	.588 (14.94)	.650 (16.51)	1.203 (30.56)	.094 (2.39)	.707 (17.96)	.062 (1.57)	.125 (3.18)	1.078 (27.38)	11/16-24UNEF-2A
12	.748 (19.00)	.813 (20.65)	1.391 (35.33)	.094 (2.39)	.707 (17.96)	.062 (1.57)	.125 (3.18)	1.266 (32.16)	7/8-20UNEF-2A
14	.873 (22.17)	.937 (23.80)	1.516 (38.51)	.094 (2.39)	.707 (17.96)	.062 (1.57)	.125 (3.18)	1.391 (35.33)	1-20UNEF-2A
16	.998 (25.35)	1.061 (26.95)	1.641 (41.68)	.094 (2.39)	.707 (17.96)	.062 (1.57)	.125 (3.18)	1.516 (38.51)	1-1/8-18UNEF-2A
18	1.123 (28.52)	1.186 (30.12)	1.766 (44.86)	.094 (2.39)	.707 (17.96)	.062 (1.57)	.125 (3.18)	1.641 (41.68)	1-1/4-18UNEF-2A
20	1.248 (31.70)	1.311 (33.30)	1.954 (49.63)	.125 (3.18)	.895 (22.73)	.062 (1.57)	.250 (6.35)	1.828 (46.43)	1-3/8-18UNEF-2A
22	1.373 (34.87)	1.436 (36.47)	2.078 (52.78)	.125 (3.18)	.895 (22.73)	.062 (1.57)	.250 (6.35)	1.954 (49.63)	1-1/2-18UNEF-2A
24	1.498 (38.05)	1.561 (39.65)	2.203 (55.96)	.125 (3.18)	.928 (23.59)	.062 (1.57)	.250 (6.35)	2.078 (52.78)	1-5/8-18UNEF-2A

Panel Cutouts — KPTH

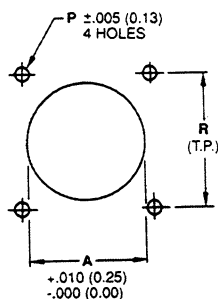Flange Mounted Receptacle
(Front Mounting)

Jam Nut Receptacle

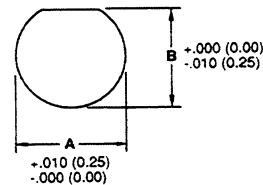

Shell Size	KPT02H/KPT01H		KPT02H	
	A	R*	± .005 (0.13)	Screw
8	.565 (14.35)	.594 (15.09)	.125 (3.18)	#4
10	.675 (17.14)	.719 (18.26)	.125 (3.18)	#4
12	.784 (19.91)	.812 (20.62)	.125 (3.18)	#4
14	.909 (23.09)	.906 (23.01)	.125 (3.18)	#4
16	1.034 (26.26)	.969 (24.62)	.125 (3.18)	#4
18	1.159 (29.44)	1.062 (26.97)	.125 (3.18)	#4
20	1.253 (31.83)	1.156 (29.36)	.125 (3.18)	#4
22	1.378 (35.00)	1.250 (31.75)	.125 (3.18)	#4
24	1.503 (38.18)	1.375 (34.92)	.155 (3.94)	#6

Shell Size	KPT07H	
	A	B
8	.567 (14.40)	.531 (13.49)
10	.692 (17.58)	.656 (16.66)
12	.880 (22.35)	.819 (20.80)
14	1.005 (25.53)	.943 (23.95)
16	1.130 (28.70)	1.067 (27.10)
18	1.255 (31.88)	1.192 (30.28)
20	1.380 (35.05)	1.317 (33.45)
22	1.505 (38.23)	1.442 (36.63)
24	1.630 (41.40)	1.567 (39.80)

*Not used in KPT01H connectors.