




SSMA CONNECTORS

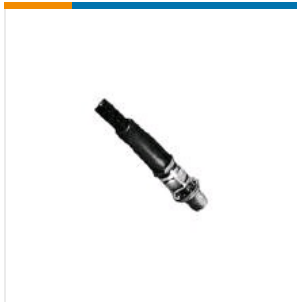

✓ Active

↓ **PRODUCT DRAWING**
English

↓ **3D PDF**

TE CONNECTIVITY (TE)
1034 7196 02
[SSA](#) , [SSRA](#)

1045506-1
TE Internal Number: 1045506-1
Alias ID: 1034-7196-02

[Always EU RoHS/ELV Compliant](#)

Applies To **Cable**

Center Contact Plating Material **Gold**

Hermetically Sealed **No**

50 Ohm **Yes**

75 Ohm **No**

Product Drawings

[OSSM BULKHEAD FEED THRU STRAIGHT CABLE JACK CRIMP CLAMP ATTACHMENT](#)

PDF ([TIFF AVAILABLE](#))
English

[OSSM BULKHEAD FEED THRU STRAIGHT CABLE JACK CRIMP CLAMP ATTACHMENT](#)

PDF ([TIFF AVAILABLE](#))
English

CAD Files

[Customer View Model](#)

3D_IGS.ZIP
English

[Customer View Model](#)

3D_STP.ZIP
English

[Customer View Model](#)

2D_DXF.ZIP
English

[3D PDF](#)

PDF
English

Instruction Sheets

Instruction Sheet (U.S.)

[SSMA Bulkhead Feedthrough Jack Connector \(Crimp Attachment\)](#)

PDF
English

Please review product documents or [contact us](#) for the latest agency approval information. Please Note: Use the Product Drawing for all design activity.

Product Type Features

Applies To

Cable

Connector Style

Jack

	Cable Type	RG 178, RG 196
	Product Type	Connector - RF
	Gasket	Without
	Dielectric Material	PTFE
Electrical Characteristics	50 Ohm	Yes
	75 Ohm	No
Signal Characteristics	Frequency (GHz)	38
Body Features	Hermetically Sealed	No
	Body Style	Straight
	Body Plating Material	Stainless Steel
	Body Material	Stainless Steel
	Body Finish	Passivated
Contact Features	Center Contact Plating Material	Gold
	Center Contact Material	Beryllium Copper
	Center Contact	With
Termination Features	Cable Termination Type	Crimp
Mechanical Attachment	Mounting Type	Bulkhead, Rear Mount
Product Compliance	Statement of Compliance PDF	
	VIEW ALL PRODUCT COMPLIANCE	