

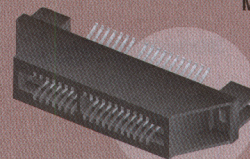


MEC1-130-02-S-D-EM1

MEC1-108-02-L-D-EM2-NP

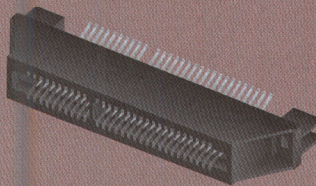

MEC1-120-02-F-D-EM1

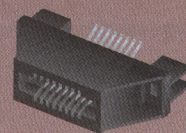

MINI EDGE-CARD SOCKET MEC1-EM SERIES

SPECIFICATIONS

For complete specifications see
www.samtec.com?MEC1-EM

Insulator Material:

Black LCP

Contact Material:

Phosphor Bronze

Current Rating:

Testing Now!

Operating Temp Range:

-65°C to +105°C with Tin;

-65°C to +125°C with Gold

Plating:

Au or Sn over 50µ"

(1,27µm) Ni

Insertion Depth:

(5,84mm) .230" to

(8,13mm) .320"



Mates with:

(1,60mm) .062" card

Important Note:
Samtec recommends that
pads on the mating board be
Gold plated.

Note: Some sizes, styles and
options are non-standard,
non-returnable.



Processing:

Max Processing Temp:

230°C for 60 seconds

Suggested PCB Layouts:

For reference only. Please
contact Samtec or go to
www.samtec.com?MEC1-EM
for recommended PCB layout.

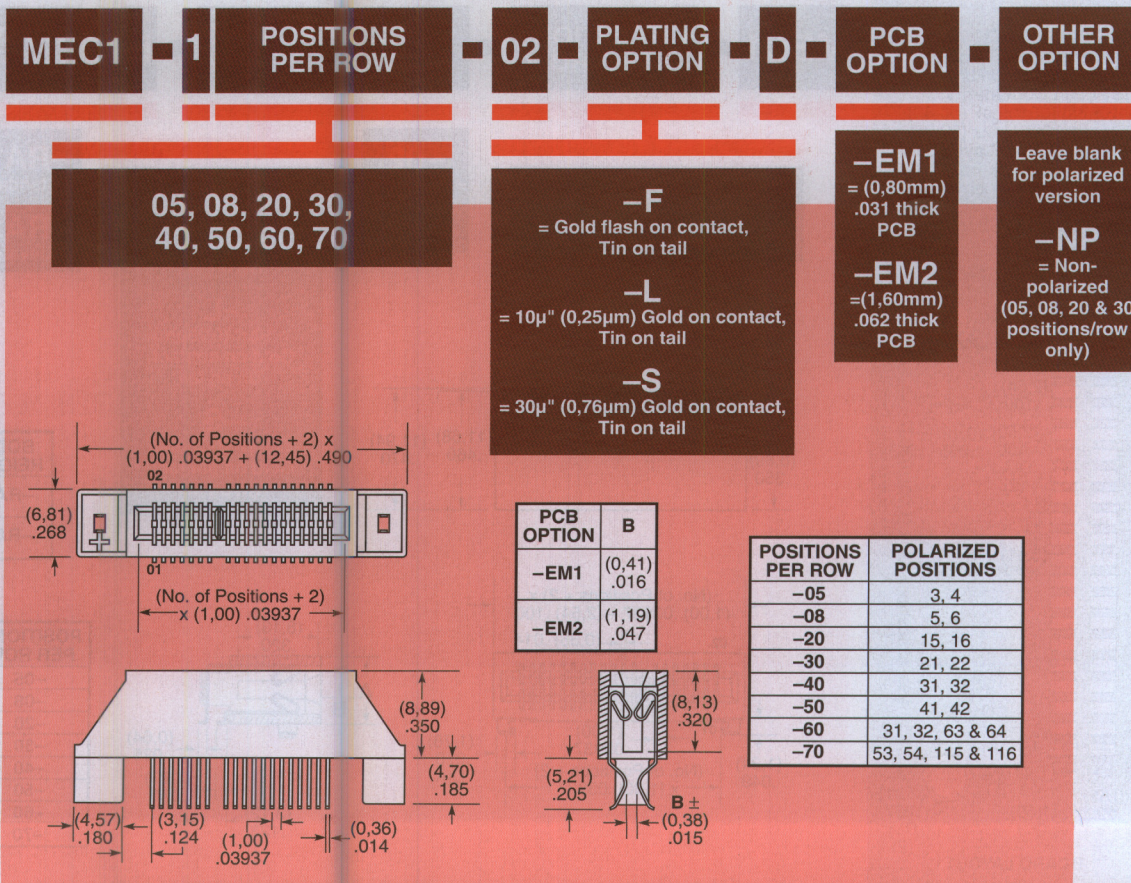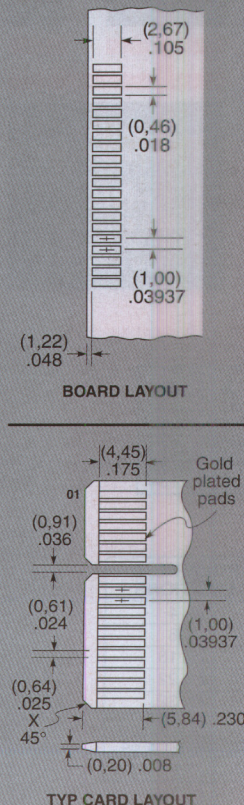

Due to technical progress, all designs, specifications and components are subject to change without notice.

WWW.SAMTEC.COM

SAMTEC USA • Tel: 1-800-SAMTEC-9 or 812-944-6733 • Fax: 812-948-5047 SAMTEC UK • Tel: 01236 739292 • Fax: 01236 727113 SAMTEC GERMANY • Tel: +49 (0) 89 / 89460-0 • Fax: +49 (0) 89 / 89460-299
SAMTEC FRANCE • Tel: 01 60 95 06 60 • Fax: 01 60 95 06 61 SAMTEC ITALY • Tel: 39 039 6890337 • Fax: 39 039 6890315 SAMTEC ISRAEL • Tel: 972-3-7526600 • Fax: 972-3-7526690
SAMTEC SCANDINAVIA • Tel: +46-84477280 • Fax: +46-87420413 SAMTEC ASIA PACIFIC • Tel: 65 6745-5955 • Fax: 65 6841-1502 SAMTEC JAPAN • Tel: 81-424-42-8318 • Fax: 81-424-42-8319
SAMTEC CHINA • Tel: 86-21-5385-4089 • Fax: 86-21-5385-4047 SAMTEC TAIWAN • Tel: 886-02-2364-6077 • Fax: 886-02-2367-9531
SAMTEC HONG KONG • Tel: 852-26904858 • Fax: 852-26904842 SAMTEC ANZ • Tel: 613 9512 7747 • Fax: 613 9512 7745