




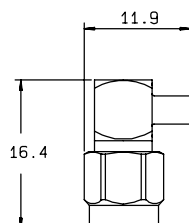


RIGHT ANGLE PLUGS SOLDER TYPE FOR SEMI RIGID CABLES

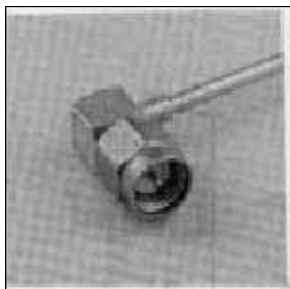



Cable group	Part number (gold)	Part number (gold/passivated nut)	Captive center contact	Assembly
.085"	R125 153 000	R125 153 002*	yes	M03
.141"	R125 154 000*	R125 154 002*	yes	M03

STRAIGHT JACKS SOLDER TYPE FOR SEMI-RIGID CABLES

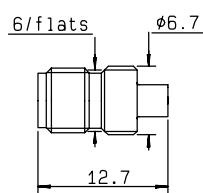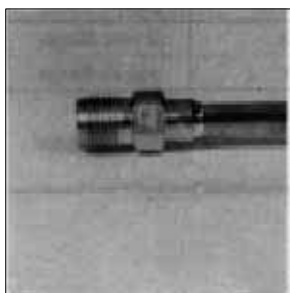

Cable group	Part number (gold)	Captive center contact	Assembly
.085"	R125 222 000*	no	M10
.141"	R125 225 000*	no	M10
.141"	R125 225 102●	yes	M12

STRAIGHT FLANGE JACKS CRIMP TYPE FOR FLEXIBLE CABLES

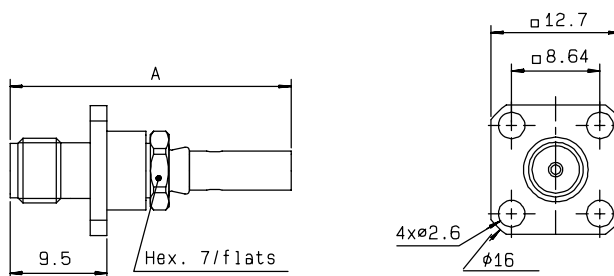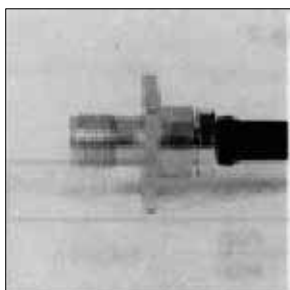

Cable group	Part number (gold)	Part number (passivated)	Dimension A (mm)	Captive center contact	Assembly	Cut out
2.6 / 50 / S	R125 272 000*	R125 272 001	27.5	no	M06	P11
5 / 50 / S	R125 277 000●	R125 277 001●	29.6	no	M06	P11
5 / 50 / D	R125 278 000●	R125 278 001●	29.6	no	M06	P11

● upon request

* packaging: 100 pieces. For unit packaging, add "W" after the P/N