




EMI & EMC Solutions > EMI Filters > Power Line Filters > 3-Phase Filters > 3 Phase Filters, Corcom AYO Series

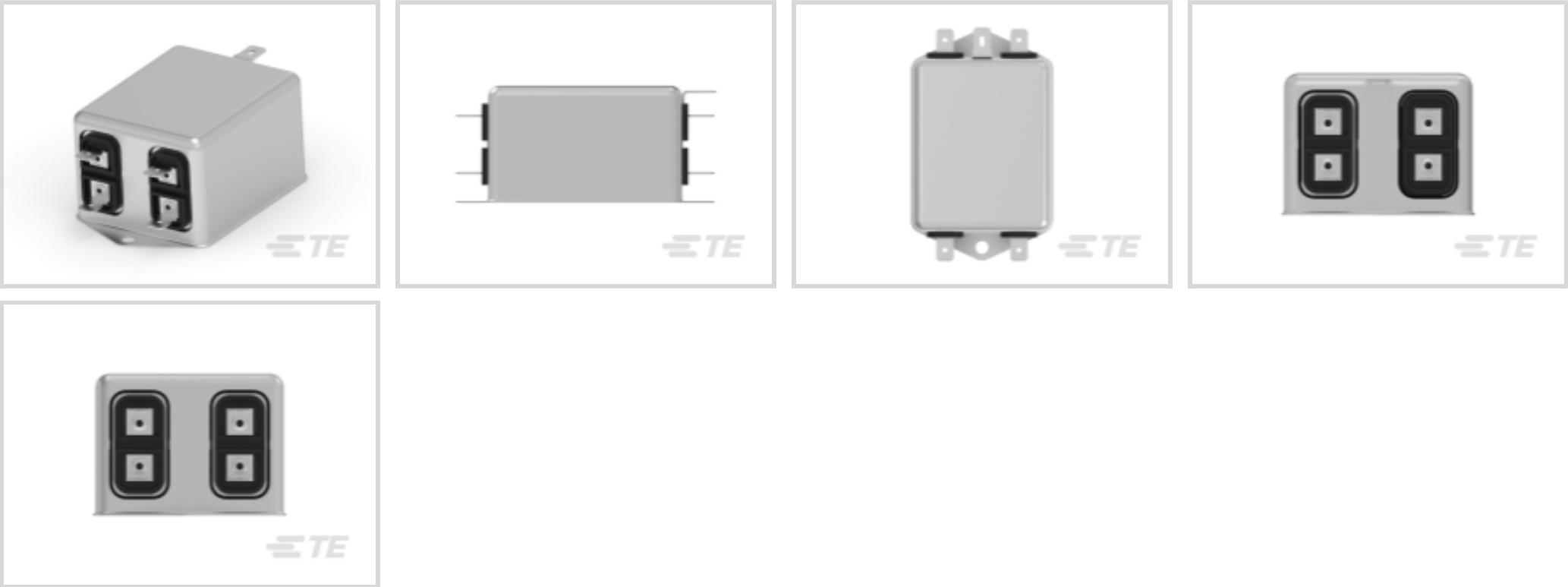

Current Rating: 10 A

Input Termination Type: .250" FASTON

Output Termination Type: .250" FASTON

Wiring Configuration: WYE (4 wire + ground)

Operating Voltage: 440 VAC

[All 3 Phase Filters, Corcom AYO Series \(0\)](#)

Features

Product Type Features

Filtering Requirements	Filtered
Input Termination Type	.250" FASTON
Output Termination Type	.250" FASTON

Configuration Features

Wiring Configuration	WYE (4 wire + ground)
----------------------	-----------------------

Electrical Characteristics

Leakage Current (Max) (250VAC, 50Hz)	3 mA
Current Rating	10 A
Operating Voltage	440 VAC

Mechanical Attachment

Product Mount Type	Chassis
--------------------	---------

Usage Conditions

Operating Temperature Range	-10 – 40 °C
-----------------------------	-------------



Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
Solder Process Capability	Not applicable for solder process capability


Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts




TE Part # CAT-C8114-AY11
3 Phase Filters, Corcom AYA Series

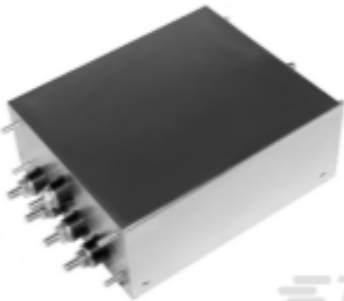


TE Part # CAT-C8114-AY91
3 Phase Filters, Corcom AYT Series



TE Part # CAT-C8114-AY18
Corcom 3-Phase Power Line Filters, AYC Series

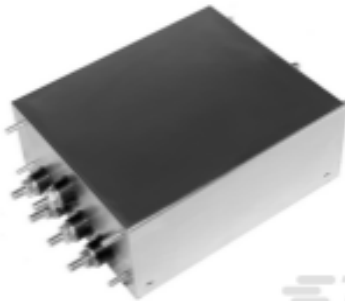

TE Part # CAT-C8114-AY68
3 Phase Filters, Corcom AYP Series

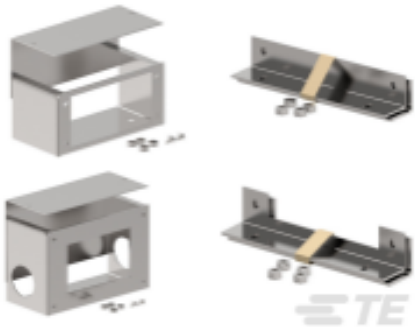


TE Part # CAT-C8114-A11
EMI Filter Accessories, Corcom A Series



TE Part # CAT-C8114-AY61
3 Phase Filters, Corcom AYO Series

Also in the Series

Customers Also Bought

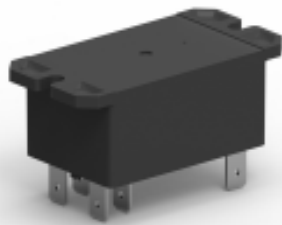

TE Part #5-1393211-4
PCB Power Relay: 40 Amp, Monostable



TE Part #1-175196-5
DYNAMIC D-3 REC CONT/L PRE-TIN



TE Part #206227-1
23-7 RECEPT REV SEX




TE Part #182920-1
CPC SQ FL. RCPT REV SEX




TE Part #165008
PLASTI-GRIP, SPADE 22-16 8



TE Part #6609034-7
10VDK1=F7611 S0

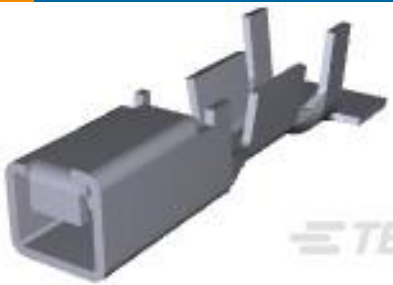

TE Part #1747418-2
DYNAMIC D4200 REC CONT M

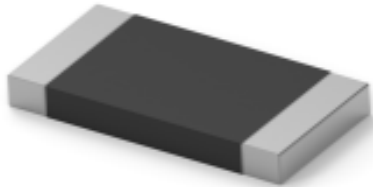

TE Part #4-2176421-3
TLRP 2512 2.0W R004 1% 50PPM 4K RL

Documents

Product Drawings

10AYO1=F7693 S0

English

CAD Files

Customer View Model

ENG_CVM_6609066-3_A.3d_igs.zip

English

Customer View Model

ENG_CVM_6609066-3_A.3d_stp.zip

English

Customer View Model

ENG_CVM_6609066-3_A.2d_dxf.zip

English

3D PDF



3D

Customer View Model

[ENG_CVM_CVM_6609066-3_A1.2d_dxf.zip](#)

English

Customer View Model

[ENG_CVM_CVM_6609066-3_A1.3d_stp.zip](#)

English

Customer View Model

[ENG_CVM_CVM_6609066-3_A1.3d_igs.zip](#)

English

[3D PDF](#)

3D

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

[1654001_Corcom_Product_Guide_AYO_Series](#)

English

[Corcom Combined Selector Charts](#)

English

[1-1654250-1_CORCOM_EMI_RFI_QRG](#)

English