

TRD13D10WLLR204

✓ ACTIVE

Alcoswitch | Alcoswitch TRD


TE Internal #: 1825426-1

Power, Panel Cutout Size 11.3 x 12.06 mm [.445 x .475 in], Silver, LED, Alcoswitch TRD, Rocker Switches

[View on TE.com >](#)



Switches > Rocker Switches

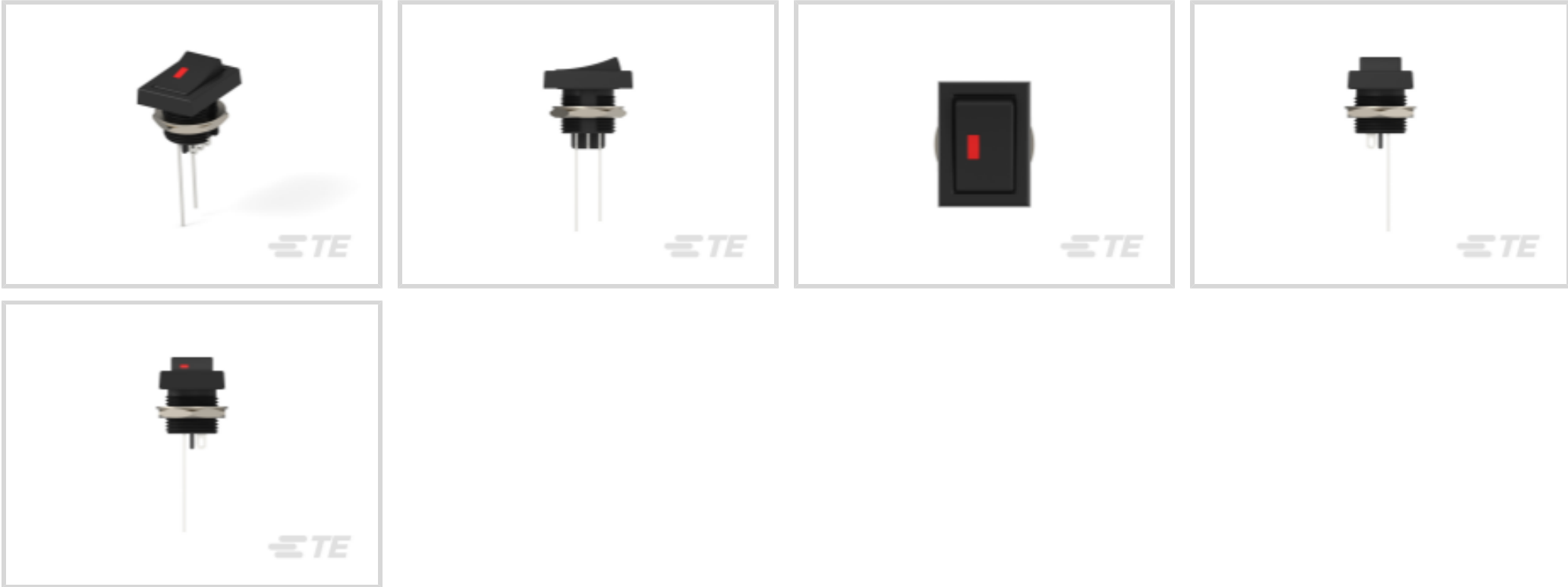

Switch Type: **Power**
Indicator/Imprint Legend: **None**
Panel Cutout Size: **11.3 x 12.06 mm [.445 x .475 in]**
Switch Contact Plating Material: **Silver**
Indicator Type: **LED**

Features

Product Type Features

Switch Type	Power
Actuator Type	Top
Actuator Style	Rocker
Switch Connection Type	Wire Lugs

Configuration Features

Indicator/Imprint Legend	None
Panel Cutout Size	11.3 x 12.06 mm[.445 x .475 in]
Configuration (Pole-Throw)	Single Pole - Double Throw
Operating Function	On None On

Electrical Characteristics

Contact Current Rating	3 A
Operating Voltage Range	28 VDC

Body Features

LED Color	Red
-----------	-----



Product Orientation	Vertical
Actuator Color	Black

Contact Features

Switch Contact Plating Material	Silver
---------------------------------	--------

Housing Features

Process Sealed	No
----------------	----

Operation/Application

Indicator Type	LED
----------------	-----

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant with Exemptions
EU ELV Directive 2000/53/EC	Compliant with Exemptions
China RoHS 2 Directive MIIT Order No 32, 2016	Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JUL 2019 (201) Does not contain REACH SVHC
Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
Solder Process Capability	Hand solderable with lead free solder

Product Compliance Disclaimer


This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts


TRD13D10WLLR204

Power, Panel Cutout Size 11.3 x 12.06 mm [.445 x .475 in], Silver, LED, Alcoswitch TRD, Rocker Switches


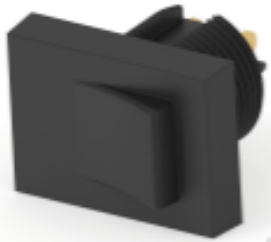


 TE Part # 1825423-1 TRD23N10QC04 rocker switch	 TE Part # 1825421-1 TRD23N10WL04 rocker switch	 TE Part # 4-1437595-1 TRD11D10WL=SPDT ROCKER BLACK	 TE Part # 5-1437595-6 TRD11G10WL=ROCKER SW SPDT (ON)
 TE Part # 1825420-1 TRD13D10WL04 rocker switch	 TE Part # 5-1437595-9 TRD11H10WL=ROCKER GOLD ON OFF	 TE Part # 4-1437595-2 TRD11D10WLLR5=SP ROCKER LIGHTE	 TE Part # 6-1437595-6 TRD13D10WL=ROCKER,SPDT,BLACK
 TE Part # 1825426-3 TRD13D10WLLR504 rocker switch	 TE Part # 8-1437595-9 TRD13F10WL=TINY ROCKER SPDT	 TE Part # 1825422-1 TRD13D10QC04 rocker switch	 TE Part # 1825426-2 TRD13D10WLLR2504 rocker switch
 TE Part # 1437596-3 TRD21N10WL=DPDT ROCKER BLACK	 TE Part # 1-1437596-9 TRD23N10WL=ROCKER,DPDT, BLACK	 TE Part # 1825425-1 TRD11F10QCLR204 rocker switch	 TE Part # 1825420-3 TRD13G10WL04 rocker switch
 TE Part # 1825426-5 TRD13G10WLLR204 rocker switch	 TE Part # 1825424-1 TRD11D10WLLR504 rocker switch	 TE Part # 5-1437595-1 TRD11F10QCLR2=SPDT MOM ROCKER	 TE Part # 6-1437595-9 TRD13D10WLLR2=SPDT ROCKER TRD

Also in the Series | [Alcoswitch TRD](#)

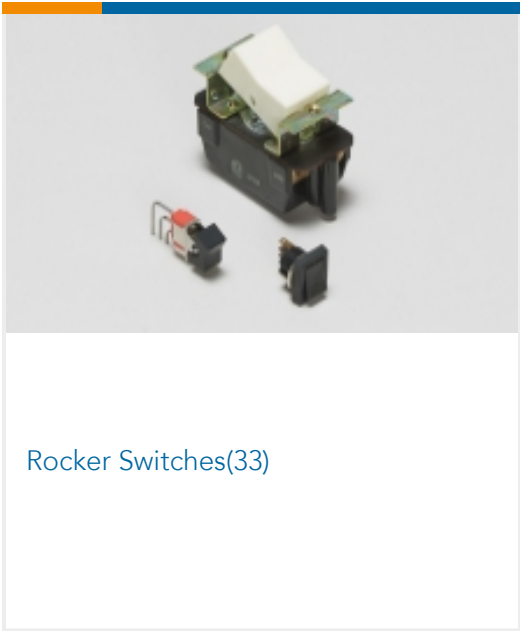

Customers Also Bought

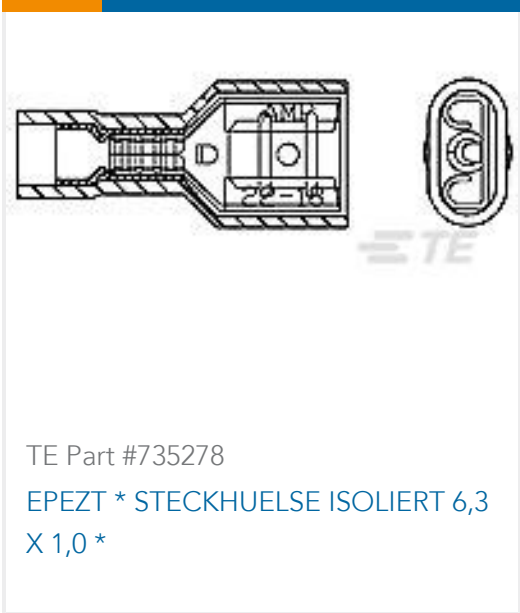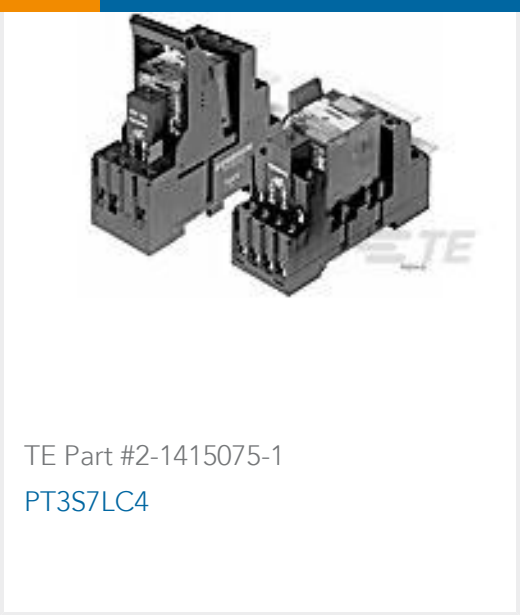

Documents

Product Drawings

TRD13D10WLLR204 rocker switch

English

CAD Files

Customer View Model

ENG_CVM_CVM_1825426-1_A.2d_dxf.zip

English

3D PDF



3D

Customer View Model

[ENG_CVM_CVM_1825426-1_A.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_1825426-1_A.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

[SWITCHES_CORE_PROGRAM_CATALOG](#)

English