

5552221-1

! PENDING OBSOLESCENCE

CHAMP


TE Internal #: 5552221-1

TE Internal Description: ASSY, PLUG, 24 POS, VERT MTG

D-Sub Plug Assembly: Vertical, 2.16mm

[View on TE.com >](#)

Connectors > D-Shaped Connectors > D-Sub Connectors > PCB D-Sub Connectors > D-Sub Plug Assembly: Vertical, 2.16mm

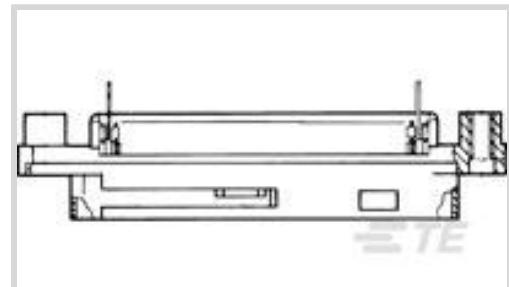Connector & Housing Type: **Plug**Connector System: **Cable-to-Board**Number of Positions: **24**Centerline (Pitch): **2.16 mm [.085 in]**Number of Rows: **2**[All D-Sub Plug Assembly: Vertical, 2.16mm \(4\)](#)**Features****Product Type Features**

Connector & Housing Type	Plug
Connector System	Cable-to-Board
Connector & Contact Terminates To	Printed Circuit Board

Configuration Features

Number of Positions	24
Number of Rows	2
PCB Mount Orientation	Vertical

Body Features

Primary Product Color	Black
Connector Profile	Standard

Contact Features

Contact Options	Installed
	30 μ in
Contact Mating Area Plating Material	Gold, Gold Flash
Contact Underplating Material	Palladium Nickel
PCB Contact Termination Area Plating Material	Tin
Contact Base Material	Phosphor Bronze

Termination Features

Rectangular Termination Post & Tail Thickness	.25 mm[.01 in]
Rectangular Termination Post & Tail Width	.5 mm[.019 in]
Termination Post & Tail Length	.18 mm
Termination Method to PCB	Through Hole - Solder

Mechanical Attachment

Mounting Feature Material	Thermoplastic
PCB Mount Retention	Without
Mating Retention	With
Mating Retention Type	Screwlocks
Connector Mounting Type	Board Mount

Housing Features

Housing Material	Thermoplastic
Centerline (Pitch)	2.16 mm[.085 in]

Dimensions

PCB Thickness (Recommended)	1.57 mm, 2.36 mm, 3.18 mm[.062 in][.093 in] [.125 in]
Row-to-Row Spacing	4.3 mm[.169 in]

Operation/Application

Shielded	No
Circuit Application	Signal

Industry Standards

UL Flammability Rating	UL 94V-0
------------------------	----------

Packaging Features

Packaging Quantity	90
Packaging Method	Tray

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold

EU REACH Regulation (EC) No. 1907/2006

Current ECHA Candidate List: JUNE 2024

(241)

Candidate List Declared Against: JAN 2024

(240)

Does not contain REACH SVHC

Halogen Content

Not Low Halogen - contains Br or Cl > 900 ppm.


Solder Process Capability

Wave solder capable to 265°C

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts

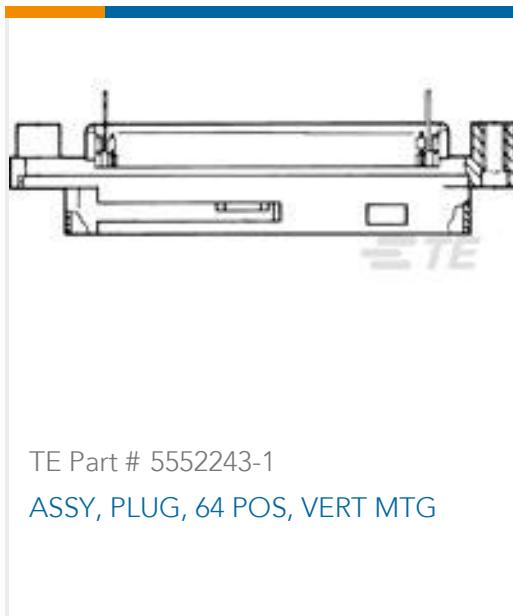

TE Part # 5552243-1
ASSY, PLUG, 64 POS, VERT MTG

Customers Also Bought



TE Part #5352332-1
Hard Metric Male Connector:
Traditional Backplane, Mezzanine,
2mm



TE Part #1-5177986-3
0.8FH,P06H.5,080,08/Sn,TR,SC



TE Part #2199230-4
M.2 0.5PITCH 4.2H KEY E 15U" AU



TE Part #104742-2
PLUGGABLE BUSBAR 062F2 POWER
CONNECTOR



TE Part #5-534206-7
14 MODII VRT DR CE 100/115



TE Part #9-2176304-0
RP 1E 0.1W 84R5 0.1% 25PPM 5K RL



TE Part #1880982003
RAYRIM-NR7-0-STK



TE Part #1-2176421-2
TLRP 2512 2.0W R003 1% 25PPM 4K RL



TE Part #1337769-2
50OHM COAX BNC STR PLUG STR P

Documents

Product Drawings

ASSY, PLUG, 24 POS, VERT MTG

English

CAD Files

3D PDF

English

Customer View Model

[ENG_CVM_5552221-1_O.2d_dxf.zip](#)

English

Customer View Model

[ENG_CVM_5552221-1_O.3d_jgs.zip](#)

English

Customer View Model

[ENG_CVM_5552221-1_O.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.