



RoHs


VER	MARK	PR. BY	DESCRIPTION	DATE

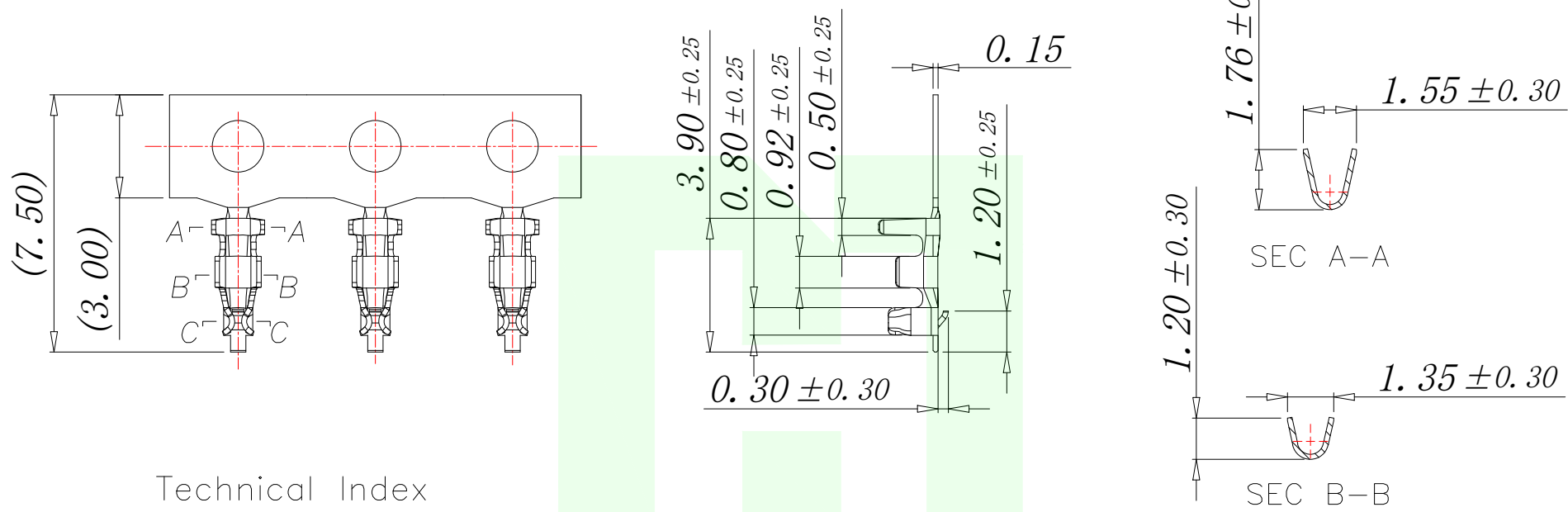

Technical Index

1. Temperature range: -25°C ~ +85°C.
2. Rated voltage: 150V DC/AC.
3. Rated current: 1.0A.
4. Contact resistance:
 - ≤ 20mΩ (Initial) per contact,
 - ≤ 40mΩ Change allowed.
5. Dielectric withstanding voltage: 500V AC/minute.
6. Insulation resistance: ≥ 500MΩ.
7. Apply to gauge: AWG#26 ~ AWG#30. (O.D 1.0mm Max)

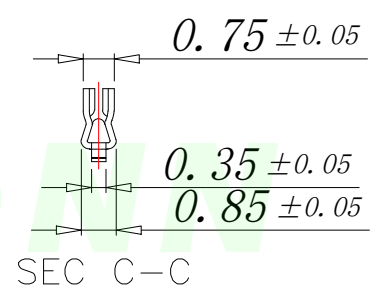

GENERAL TOLERANCES UNLESS SPECIFIED		 深圳市华明通电子有限公司 Shenzhen Huamingtong Electronics Co., Ltd	
X.X ±0.30	X.* ±5°	PART NO.	TITLE:
.XX ±0.20	X.X* ±1°	W1252-DZ221	1.25 Pitch A型(DF13) 双排公头端子
.XXX ±0.10	X.XX* ±0.5°	DESIGN: James	CUSTOMER
MANUFACTURE DWG		CHED: Talen	
		APPD: Sophia	UNITS MM
			SCALE N:A
			SHEET 1/1