
 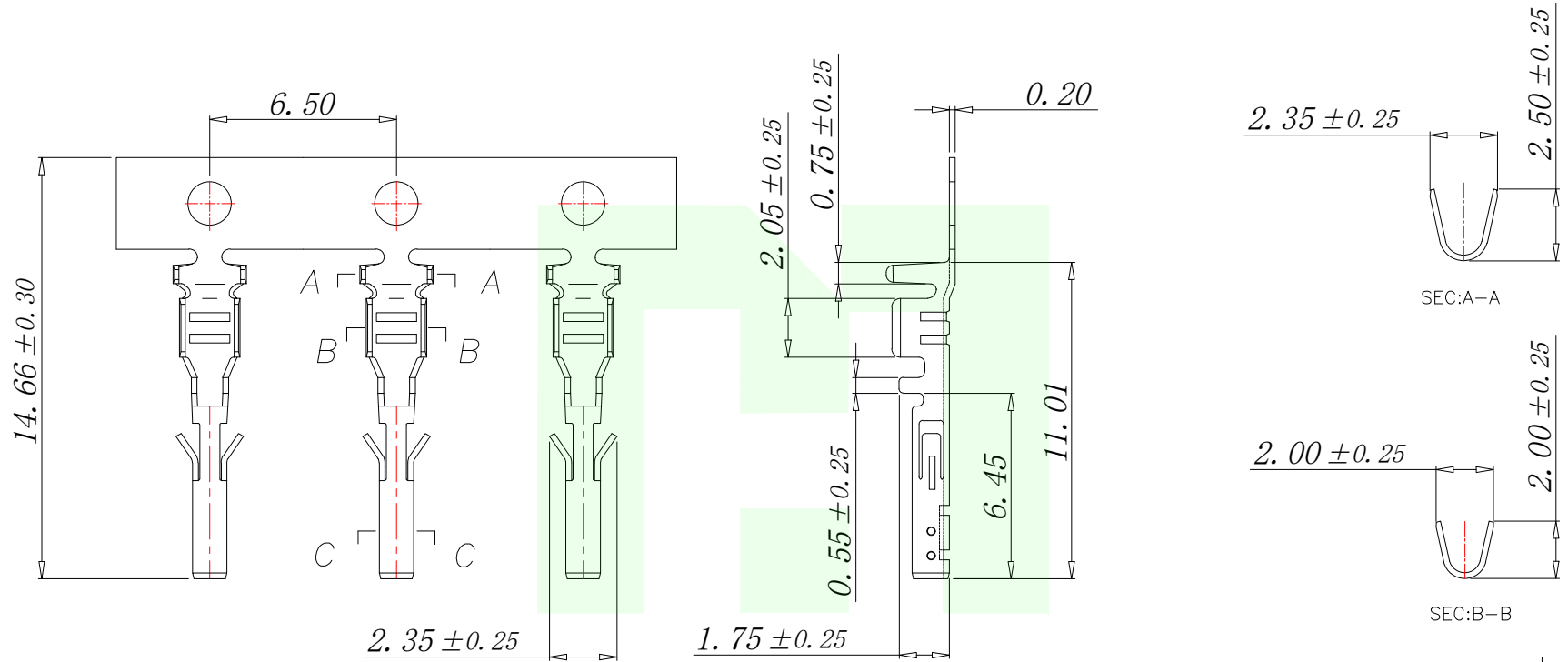


RoHs



Technical Index:

1. Temperature range: -25°C~85°C.
2. Rated voltage: 250V DC/AC(rms).
3. Rated current: 5A AC, DC.
4. Contact resistance: ≤20mΩ.
5. Dielectric withstanding voltage: 1500V AC/minute.
6. Insulation resistance: ≥1000MΩ.
7. Apply to gauge: AWG#20~#24.

GENERAL TOLERANCES UNLESS SPECIFIED				 深圳市华明通电子有限公司 Shenzhen Huamingtong Electronics Co., Ltd				
X.X	±0.30	X.°	±5°	PART NO. W3001-DZ221		TITLE: MX3.0MM TERMINAL		
.XX	±0.20	X.X°	±1°					
.XXX	±0.10	X.XX°	±0.5°	DESIGN:	James	CUSTOMER	SIZE	UNITS
				CHED:	Talen		A4	MM
MANUFACTURE DWG				APPD:	Sophia		SCALE	SHEET
							N:A	1/1