


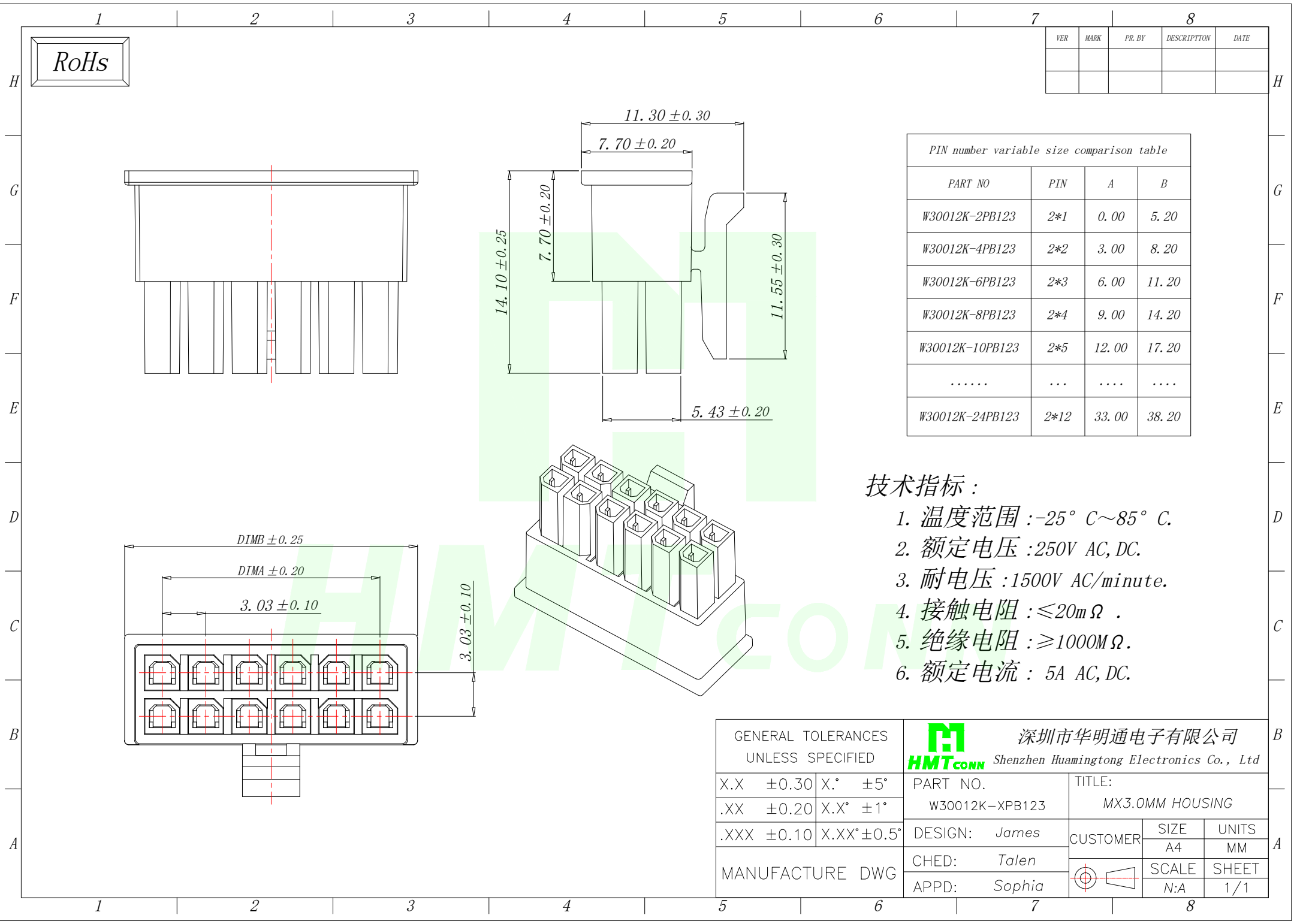

RoHS

VER	MARK	PR. BY	DESCRIPTION	DATE

PIN number variable size comparison table			
PART NO	PIN	A	B
W30012K-2PB123	2*1	0.00	5.20
W30012K-4PB123	2*2	3.00	8.20
W30012K-6PB123	2*3	6.00	11.20
W30012K-8PB123	2*4	9.00	14.20
W30012K-10PB123	2*5	12.00	17.20
.....	...		
W30012K-24PB123	2*12	33.00	38.20

- 技术指标：
1. 温度范围：-25° C~85° C.
 2. 额定电压：250V AC, DC.
 3. 耐电压：1500V AC/minute.
 4. 接触电阻：≤20mΩ .
 5. 绝缘电阻：≥1000MΩ.
 6. 额定电流：5A AC, DC.

GENERAL TOLERANCES UNLESS SPECIFIED		 深圳市华明通电子有限公司 Shenzhen Huamingtong Electronics Co., Ltd			
X.X ±0.30	X.° ±5°	PART NO. W30012K-XPB123	TITLE: MX3.0MM HOUSING		
.XX ±0.20	X.X° ±1°				
.XXX ±0.10	X.XX° ±0.5°	DESIGN: James	CUSTOMER	SIZE A4	UNITS MM
MANUFACTURE DWG		CHED: Talen			SHEET
		APPD: Sophia			1/1