


 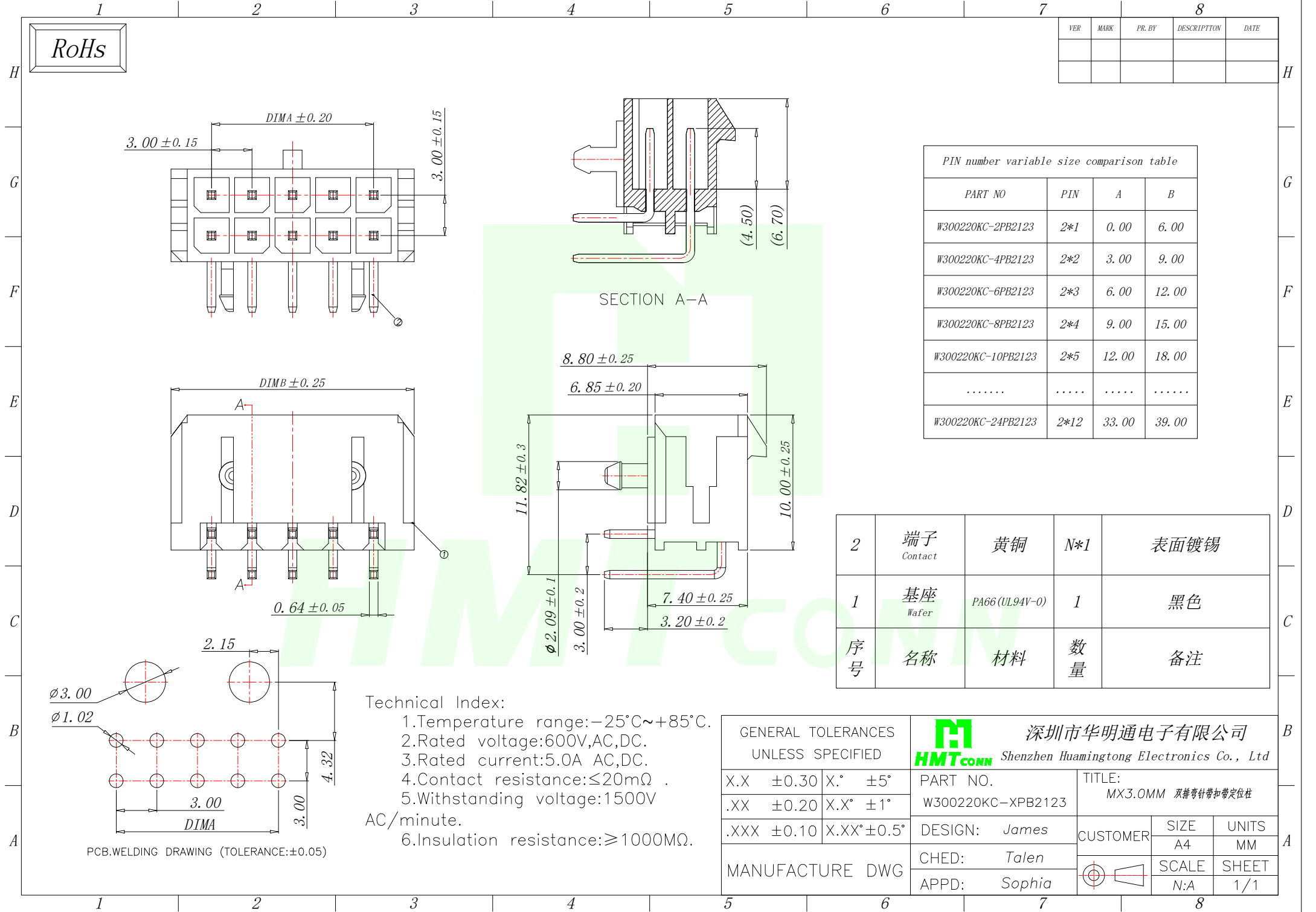


RoHS

VER	MARK	PR. BY	DESCRIPTION	DATE

PIN number variable size comparison table			
PART NO	PIN	A	B
W300220KC-2PB2123	2*1	0.00	6.00
W300220KC-4PB2123	2*2	3.00	9.00
W300220KC-6PB2123	2*3	6.00	12.00
W300220KC-8PB2123	2*4	9.00	15.00
W300220KC-10PB2123	2*5	12.00	18.00
.....			
W300220KC-24PB2123	2*12	33.00	39.00

2	端子 Contact	黄铜	N*1	表面镀锡
1	基座 Wafer	PA66 (UL94V-0)	1	黑色
序号	名称	材料	数量	备注

GENERAL TOLERANCES UNLESS SPECIFIED		 HMT CONN 深圳市华明通电子有限公司 Shenzhen Huamingtong Electronics Co., Ltd				
X.X ±0.30	X.° ±5°	PART NO. W300220KC-XPB2123		TITLE: MX3.0MM 双排弯针带扣带定位柱		
.XX ±0.20	X.X° ±1°	DESIGN: James		CUSTOMER	SIZE	UNITS
.XXX ±0.10	X.XX° ±0.5°				A4	MM
MANUFACTURE DWG		CHED: Talen			SCALE	SHEET
		APPD: Sophia			N:A	1/1