


 
RoHs

VER	MARK	PR. BY	DESCRIPTION	DATE

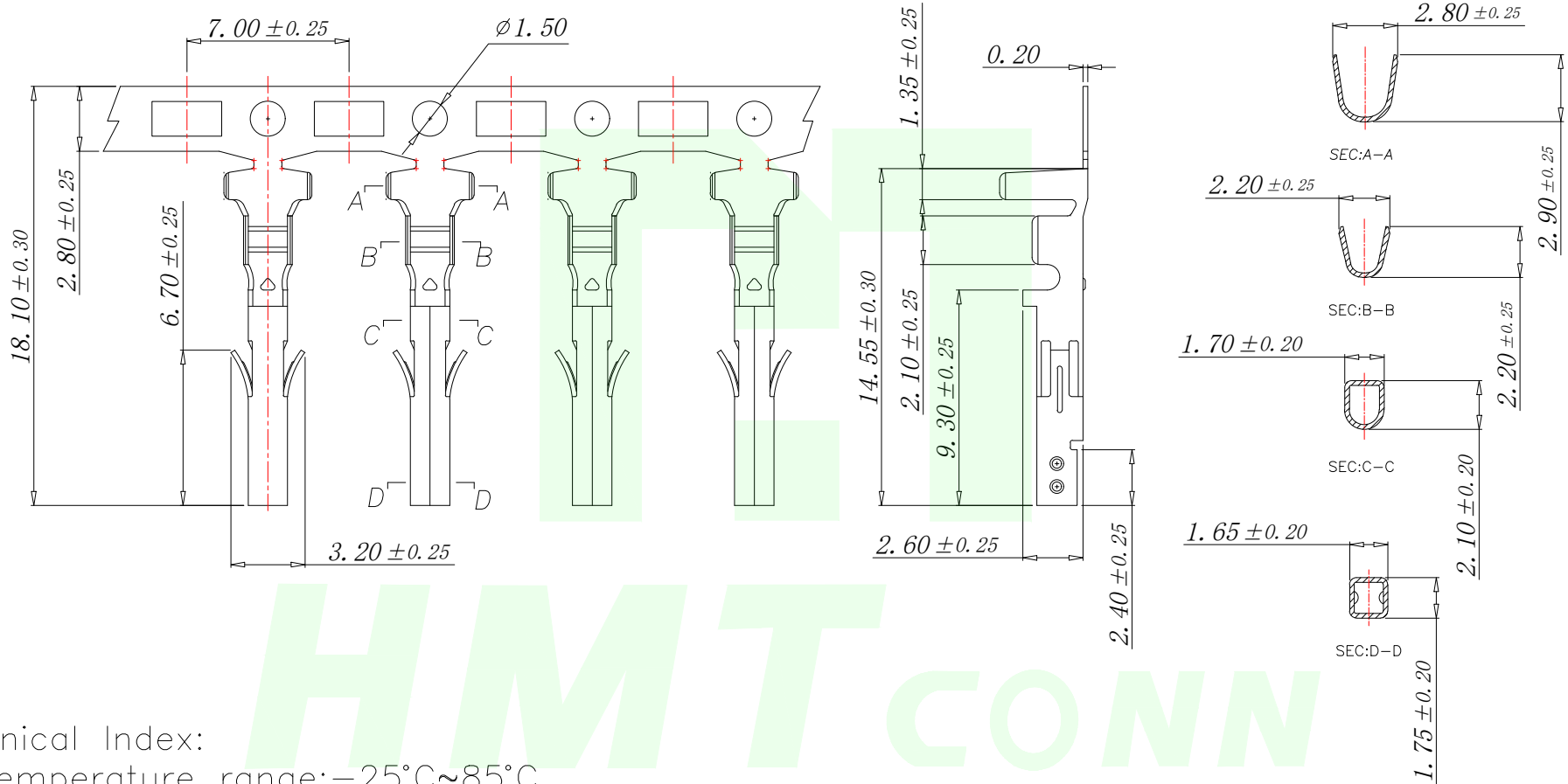

Technical Index:

1. Temperature range: $-25^{\circ}\text{C} \sim 85^{\circ}\text{C}$.
2. Rated voltage: 250V DC/AC(rms).
3. Rated current: 5A AC, DC.
4. Contact resistance: $\leq 20\text{m}\Omega$.
5. Dielectric withstanding voltage: 1500V AC/minute.
6. Insulation resistance: $\geq 1000\text{M}\Omega$.
7. Apply to gauge: AWG#22~#28 (O.D 1.80mm Max).

GENERAL TOLERANCES UNLESS SPECIFIED		 深圳市华明通电子有限公司 Shenzhen Huamingtong Electronics Co., Ltd			
X.X ±0.30	X.° ±5°	PART NO. W4201-DZ221		TITLE: WBM4.2MM TERMINAL	
.XX ±0.20	X.X° ±1°				
.XXX ±0.10	X.XX°±0.5°	DESIGN: James	CUSTOMER	SIZE	UNITS
MANUFACTURE DWG		CHED: Talen		A4	MM
		APPD: Sophia			SCALE
				N:A	1/1