
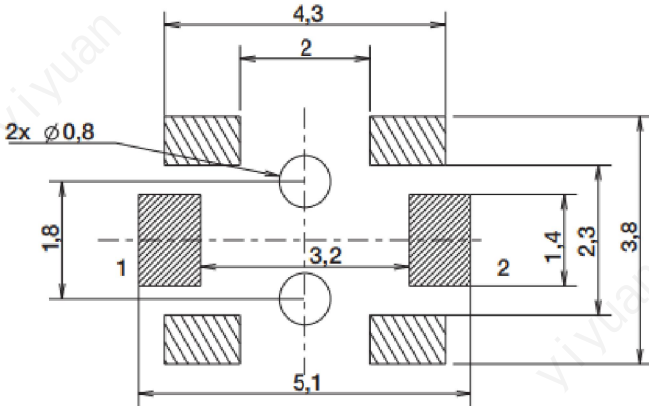
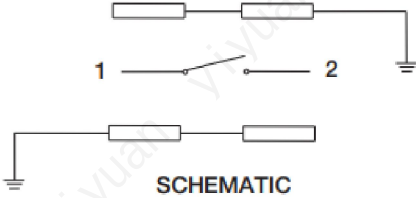
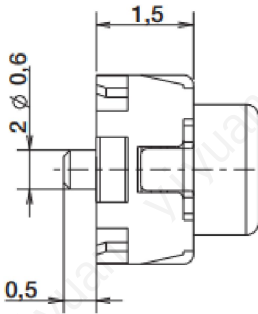
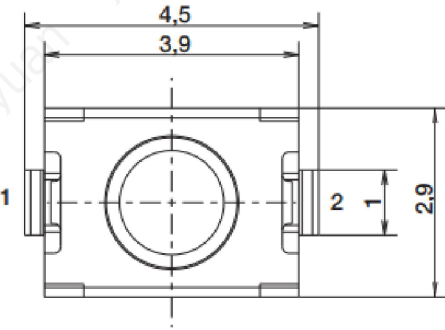


REV.	ECN. NO.	APPD.

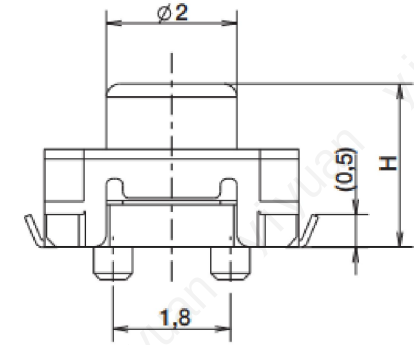

Specification

Maximum Voltage	16VDC
Maximum Current DC	50mA
Dielectric Strength	100 VA C(1mm)
Contact Resistance	≤100mΩ
Insulation Resistance	≥100MΩ
Operating Temperature	-40C° to 85C°
Travel	0.2mm +0.1mm/-0.05mm
Bounce Time	≤10 ms

Mechanical

	Operatin g Force(gf)	Life Cycles	Heiht mm	Pegs
YTS820 J25M	160±50	200,000	2.5	NO
YTS820 J25K	250±50	100,000	2.5	NO
YTS820 J25MP	160±50	200,000	2.5	YES
YTS820 J25KP	250±50	100,000	2.5	YES
YTS820 J20M	160±50	200,000	2.0	NO
YTS820 J20K	250±50	100,000	2.0	NO
YTS820 J20MP	160±50	200,000	2.0	YES
YTS820 J20KP	250±50	100,000	2.0	YES
YTS820 J15M	160±50	200,000	1.5	NO
YTS820 J15K	250±50S	100,000	1.5	NO
YTS820 J15MP	160±50	200,000	1.5	YES
YTS820 J15KP	250±50	100,000	1.5	YES

THESE DRAWINGS AND SPECIFICATIONS
ARE THE PROPERTY OF YIYUAN
TECHNOLOGY CO.,LTD
AND SHALL NOT BE REPRODUCED,
COPIED OR USED IN ANY MANNER WITHOUT
THE PRIOR WRITTEN CONSENT OF
YIYUAN TECHNOLOGY CO.,LTD

Packaging
Switches in reels of 2,500 pieces for 1.5 and 2.0mm height.
Switches in reels of 2,300 pieces for 2.5mm height.
Dimensions of reels according to EIA 481B center.
External diameter 330mm



深圳市怡远科技有限公司
SHENZHEN YIYUAN TECHNOLOGY CO.,LTD

PART NO. YTS 820	TITLE: TACTILE SWITCH
APPD: ROGER	DWG NO.: YTS 820
CHKD: ROC	SCALE SHEET REV.
DR: BILLY WANG 2020/08/21	1/1 1/1 A1