


产品/Product: **2G/3G/4G,NB-IoT,CAT.1&4, H220 MeterSpring Antenna**

料号/PN: **AH3G.405W**

应用/Application: **2G/3G/4G,NB-IoT,CAT.1&4, Remote /Transfer /Recciever ;**

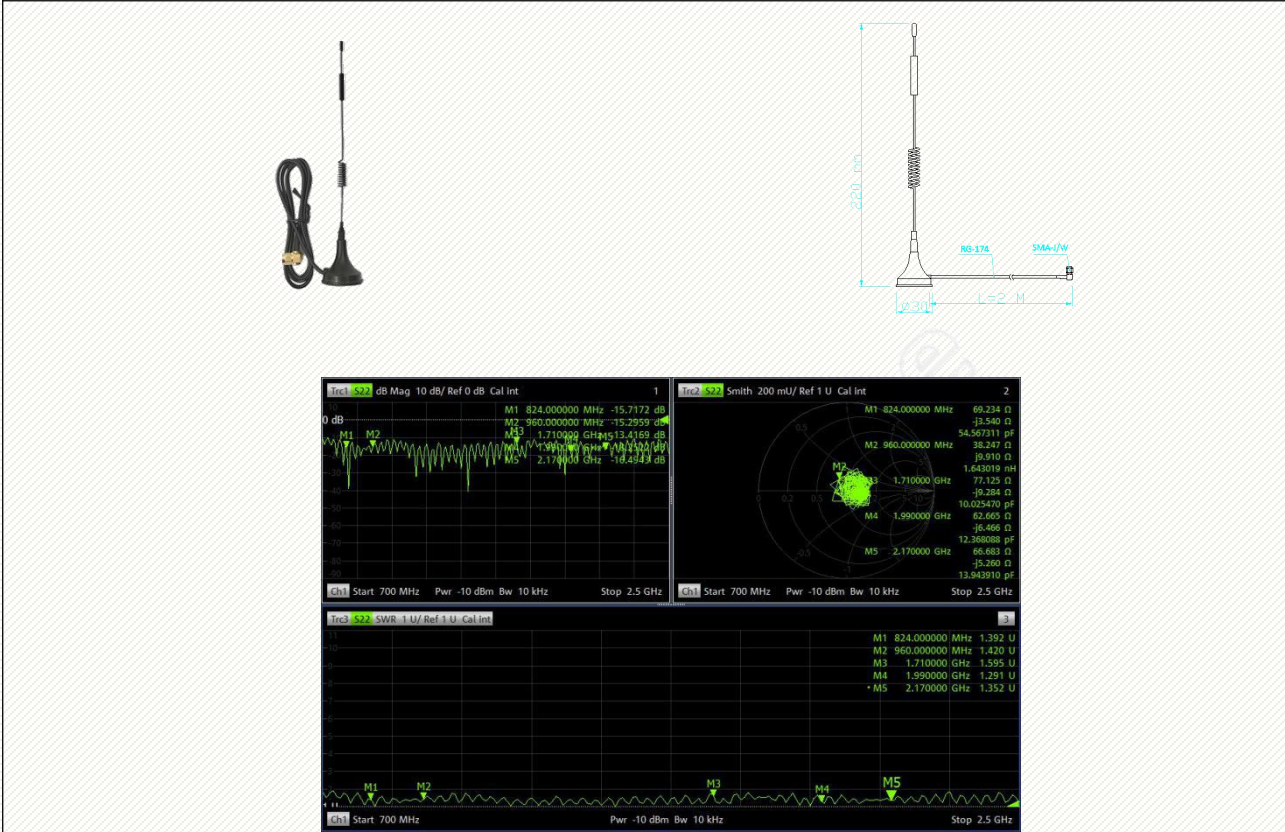

## 电气参数(Electrical Properties)

频率/Frequency:	800~2170 MHz, 2G/3G/4G,NB-IoT,CAT. 1&4
输入阻抗/Impedance:	50 Ω
驻波比/VSWR:	≤2.0
增益/Gain:	3.8 dBi
极化方式/Polarization:	Vertical / Omni

## 机械参数(Mechanical Properties)

接头&线缆/Conn&Cable:	SMA-J/W & RG-174 Cable
材料&颜色/Material&Color:	Copper/Black
安装方式/Mounting:	Magnetic
尺寸/Size:	∅30×H220 mm
重量/Weight:	52.0 g/pcs
工作温度/Operate Temp:	-40 ~ +85 °C

关联产品/Relation Product



SMA-K DIP ([AHCG.202](#))





SMA-K ASSY ([AHCG.101](#))

产品手册/ Product Catalogue



免费样品申请  
Ask free sample

下载地址/Download Link: <http://docs.AntennaHome.com/ant/catalogue.pdf>

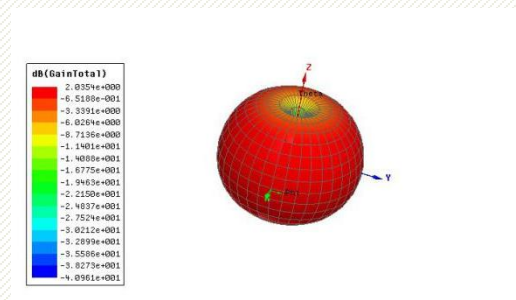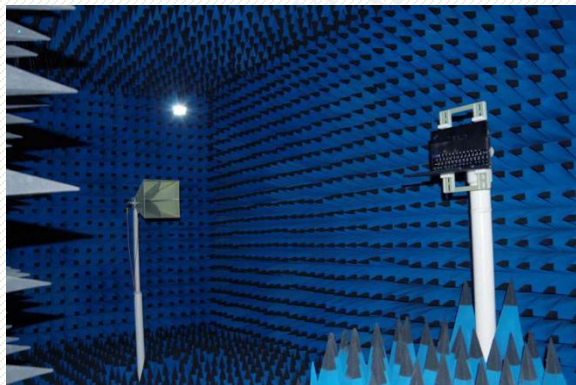

Online Support

Contact Us

E-mail : [CS@AntennaHome.com](mailto:CS@AntennaHome.com)

Website : [Http://www.AntennaHome.com](http://www.AntennaHome.com)