


产品/Product: **Internal GPS, CHIP On Board, GPS/BD Passive Antenna Series**

料号/PN: **AHGG.24X** (Include AHGG.241, AHGG.242, AHGG.243, AHGG.244)

应用/Application: **GPS / BeiDou, GNSS Position System**

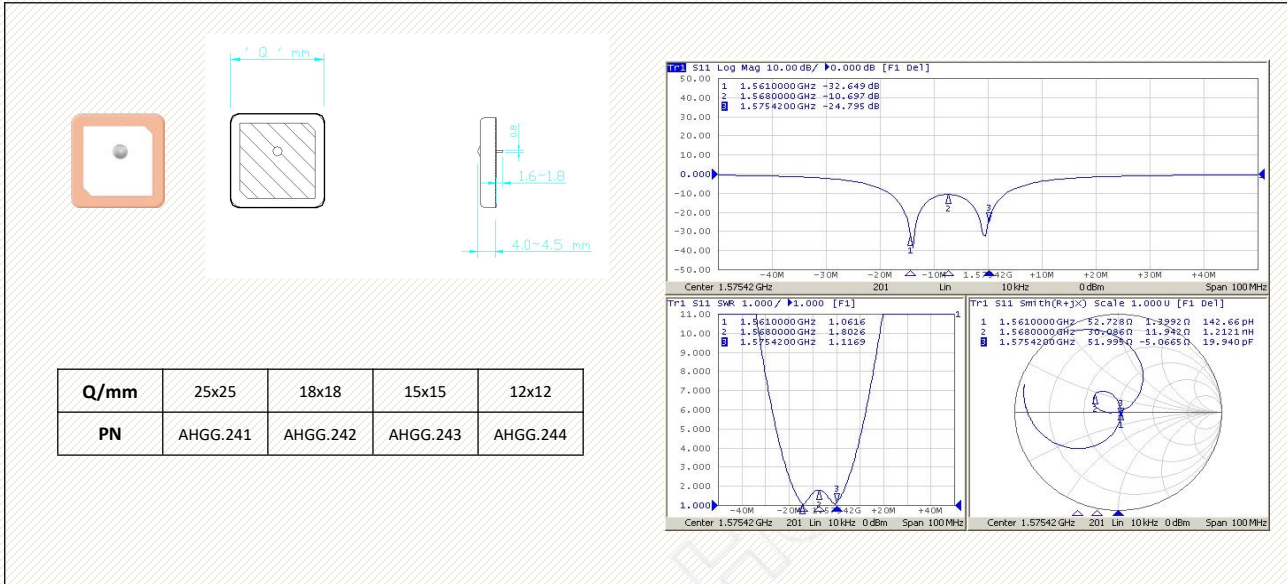


电气参数 (Electrical Properties)

频率/Frequency:	GPS/1575.42 MHz、BD/1561.02MHz、
输入阻抗/Impedance:	50 Ω
驻波比/VSWR:	≤2.0
增益/Gain:	3~5 dB
极化方式/Polarization:	RHCP



机械参数 (Mechanical Properties)

接头&线缆/Conn&Cable:	/
材料&颜色/Material&Color:	Ceramic
安装方式/Mounting:	DIP
尺寸/Size:	Q x Q x 4.0 mm (Q=25, 18, 15, 12)
重量/Weight:	5 g/pcs
工作温度/Operate Temp:	-40 ~ +85 °C

关联产品/Relation Product

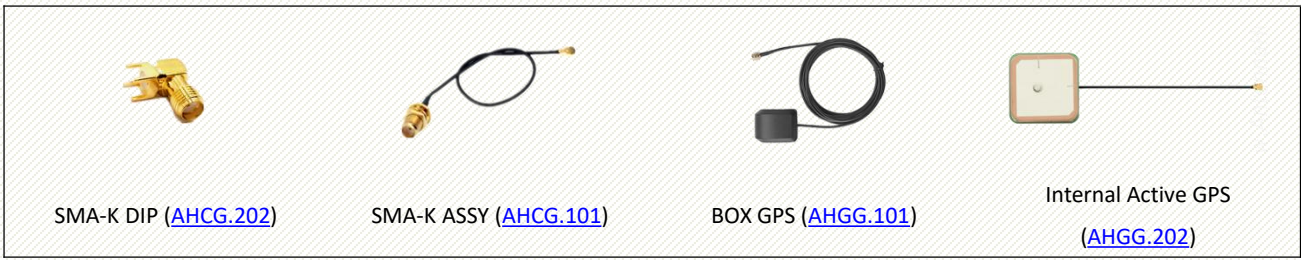

产品手册/ Product Catalogue

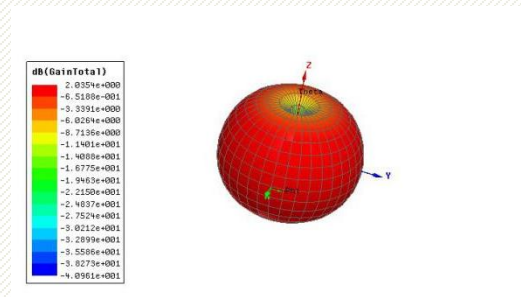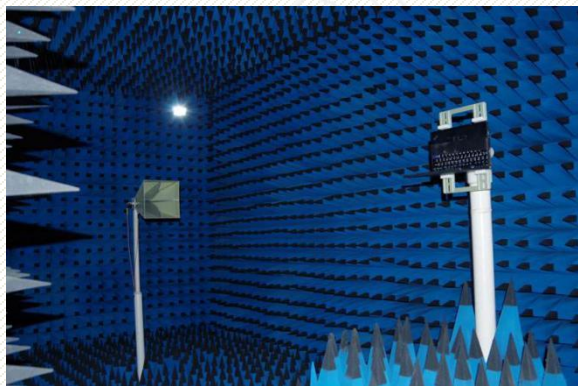

Online Support

Contact Us

E-mail : CS@AntennaHome.com

Website : [Http://www.AntennaHome.com](http://www.AntennaHome.com)