


产品/Product: **Spring DIP ,433M Antenna**

料号/PN: **AH1G.301**

应用/Application: **ISM 433MHz system, LoRa / Remote / Transfer / Receiver ;**

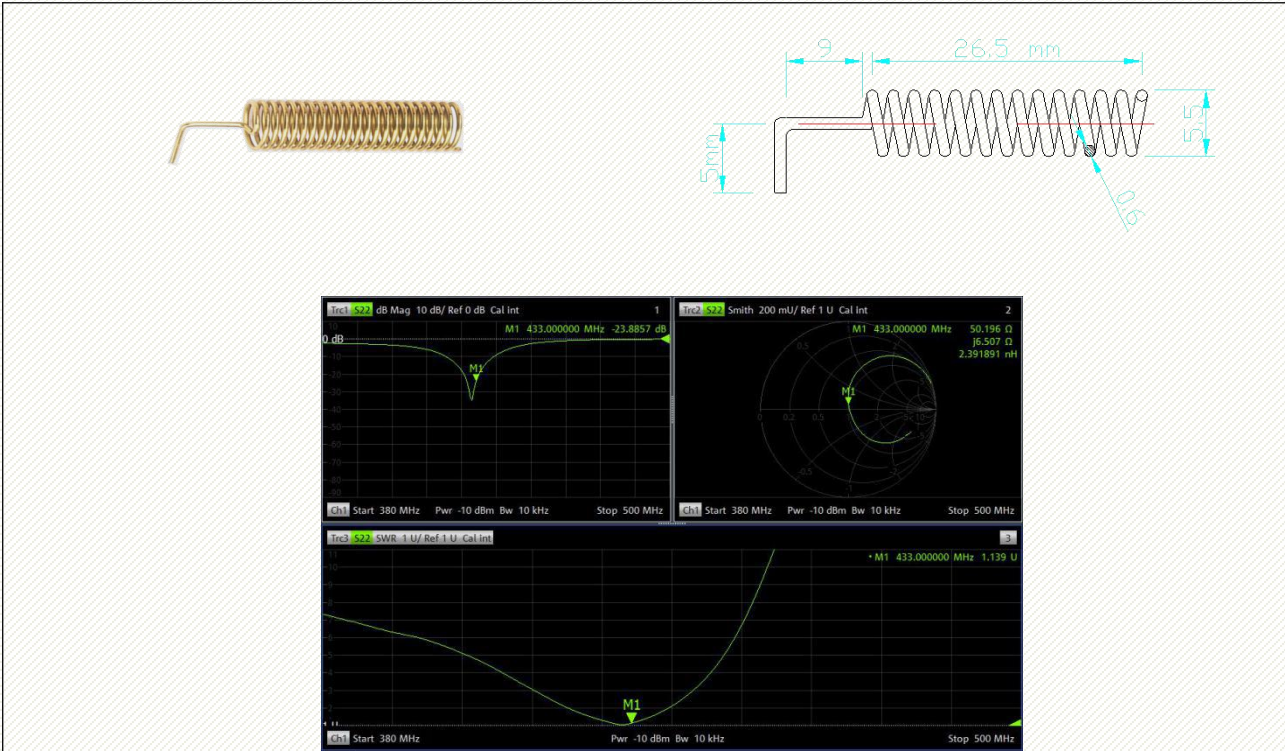


电气参数(Electrical Properties)

频率/Frequency:	433 MHz
输入阻抗/Impedance:	50 Ω
驻波比/VSWR:	≤2.0
增益/Gain:	1.0 dBi
极化方式/Polarization:	Vertical / Omni




机械参数(Mechanical Properties)

接头&线缆/Conn&Cable:	/
材料&颜色/Material&Color:	Copper
安装方式/Mounting:	DIP
尺寸/Size:	∅5.5×L36.0 mm
重量/Weight:	0.7 g/pcs
工作温度/Operate Temp:	-40 ~ +85 °C

关联产品/Relation Product

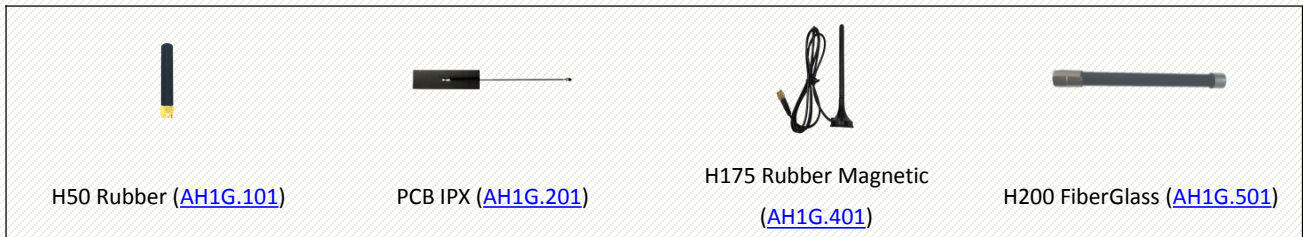

产品手册/ Product Catalogue

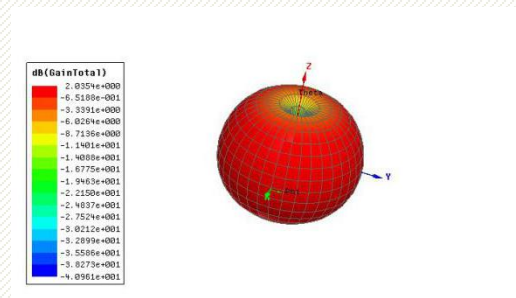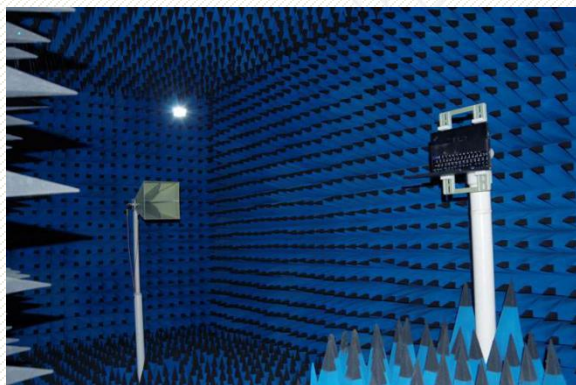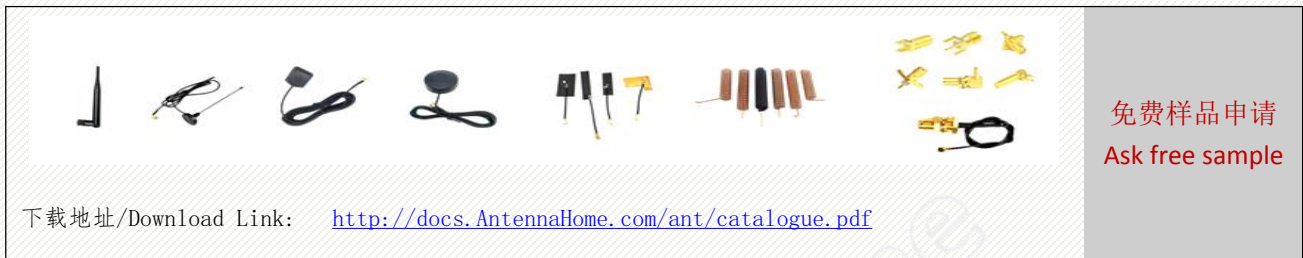

Online Support

Contact Us

E-mail : CS@AntennaHome.com

Website : [Http://www.AntennaHome.com](http://www.AntennaHome.com)