


产 品/Product : **Q48x38 Box GPS+GLONASS Fakra C, L3000, GPS/GLONASS Antenna**

料 号/PN : **AHGG.132C**

应 用/Application : **GPS / GLONASS , 1575/1602MHz, GNSS Position and Location System**

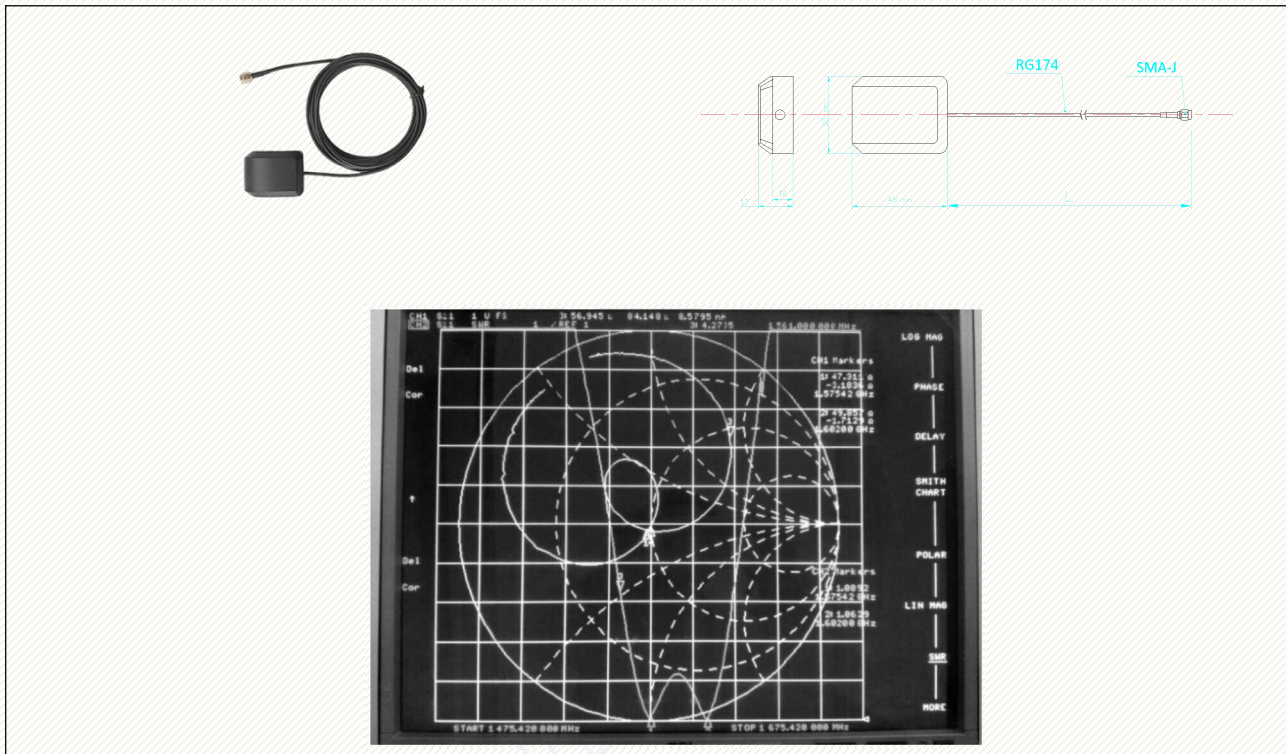

电气参数(Electrical Properties)

频率/Frequency:	GPS/1575.42 MHz、GLONASS/1602 MHz
输入阻抗/Impedance:	50 Ω
驻波比/VSWR:	≤ 2.0
增益/Gain:	28 $\pm$ 2dB @3~5V
极化方式/Polarization:	RHCP

机械参数(Mechanical Properties)

接头&线缆/Conn&Cable:	Fakra C ,RG-174 L=3M or Option ,
材料&颜色/Material&Color:	Copper / ABS
安装方式/Mounting:	Fakra C
尺寸/Size:	Q48x38x17 mm
重量/Weight:	50 g/pcs
工作温度/Operate Temp:	-40 ~ +85 $^{\circ}$ C

关联产品/Relation Product



SMA-K DIP ([AHCG.202](#))



SMA-K ASSY ([AHCG.101](#))



Internal GPS ([AHGG.232](#))





Chip GPS ([AHGG.24X7](#))

产品手册/ Product Catalogue



下载地址/Download Link: <http://docs.AntennaHome.com/ant/catalogue.pdf>

免费样品申请
Ask free sample

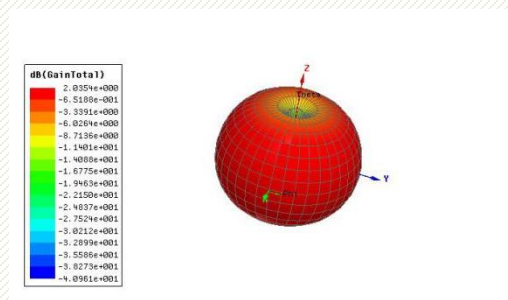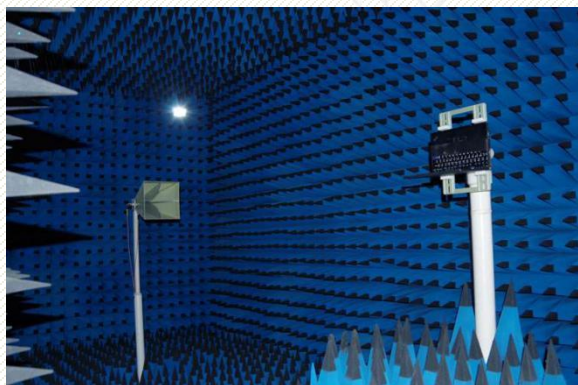

Online Support

Contact Us

E-mail : CS@AntennaHome.com

Website : [Http://www.AntennaHome.com](http://www.AntennaHome.com)