


产品/Product: **Q25x25 Internal GPS+GLONASS, L120, GPS/GLONASS Antenna**

料号/PN: **AHGG.232**

应用/Application: **GPS / GLONASS, 1575/1602MHz, GNSS Position and Location System**

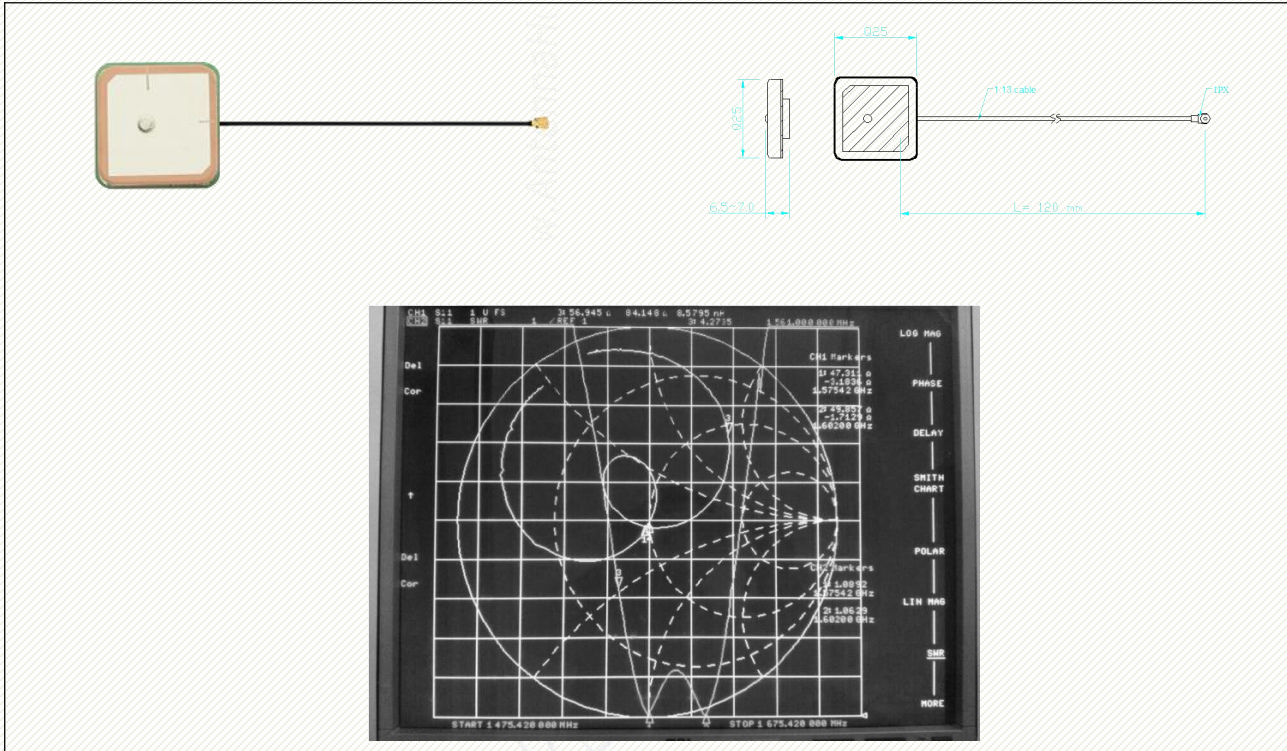





电气参数(Electrical Properties)

频率/Frequency:	GPS/1575.42 MHz、GLONASS/1602 MHz
输入阻抗/Impedance:	50 Ω
驻波比/VSWR:	≤2.0
增益/Gain:	18±2dB @2.7~3.3V
极化方式/Polarization:	RHCP

机械参数(Mechanical Properties)



接头&线缆/Conn&Cable:	IPX ,RG113 L120 ,
材料&颜色/Material&Color:	Ceramic / pcb
安装方式/Mounting:	/
尺寸/Size:	Q25 x25 x6.5 mm
重量/Weight:	11 g/pcs
工作温度/Operate Temp:	-40 ~ +85 °C

关联产品/Relation Product

			
SMA-K DIP (AHCG.202)	SMA-K ASSY (AHCG.101)	BOX GPS (AHGG.132)	Chip GPS (AHGG.2417)

产品手册/ Product Catalogue

	免费样品申请 Ask free sample
下载地址/Download Link: http://docs.AntennaHome.com/ant/catalogue.pdf	

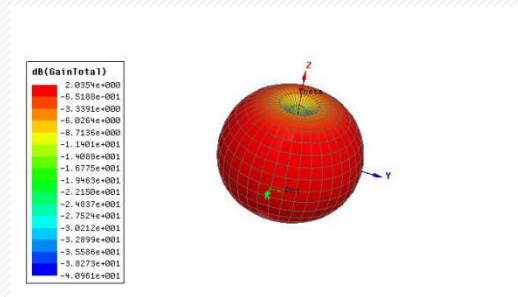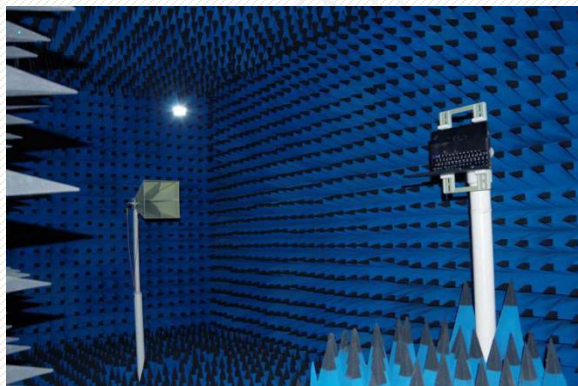

Online Support

Contact Us

E-mail : CS@AntennaHome.com

Website : [Http://www.AntennaHome.com](http://www.AntennaHome.com)