


THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

|  |  |
|--|--|
| Material   | High Conductivity<br>Seamless Copper Tube  |
| Plating  | Electro-Tin  |
| Wire Size  | 2/0 STR/FLEX   |
| Wire Type  | Stranded Copper: Class B & C,<br>Compact, Class G, H, I, K, M,<br>Locomotive   |
| Wire Strip Length                                    | 1-3/16 in.   |
| Stud Size  | 1/4 in.  |
| UL Listed Wire<br>Connector                          | Yes, for applications up to 35kv.<br>Consult cable manufacturer for<br>voltage stress relief instructions<br>with applications greater than<br>2000 volts. |
| UL Temperature<br>Rating                             | 90 ° C   |
| C.S.A Certified<br>Wire Connector                    | N/A  |
| Panduit Color Code<br>on Barrel                      | BLACK  |
| Panduit Die Index No.<br>on Barrel                   | P45  |
| Alternate Industry<br>Die Index No. ( )<br>on Barrel | (13)   |

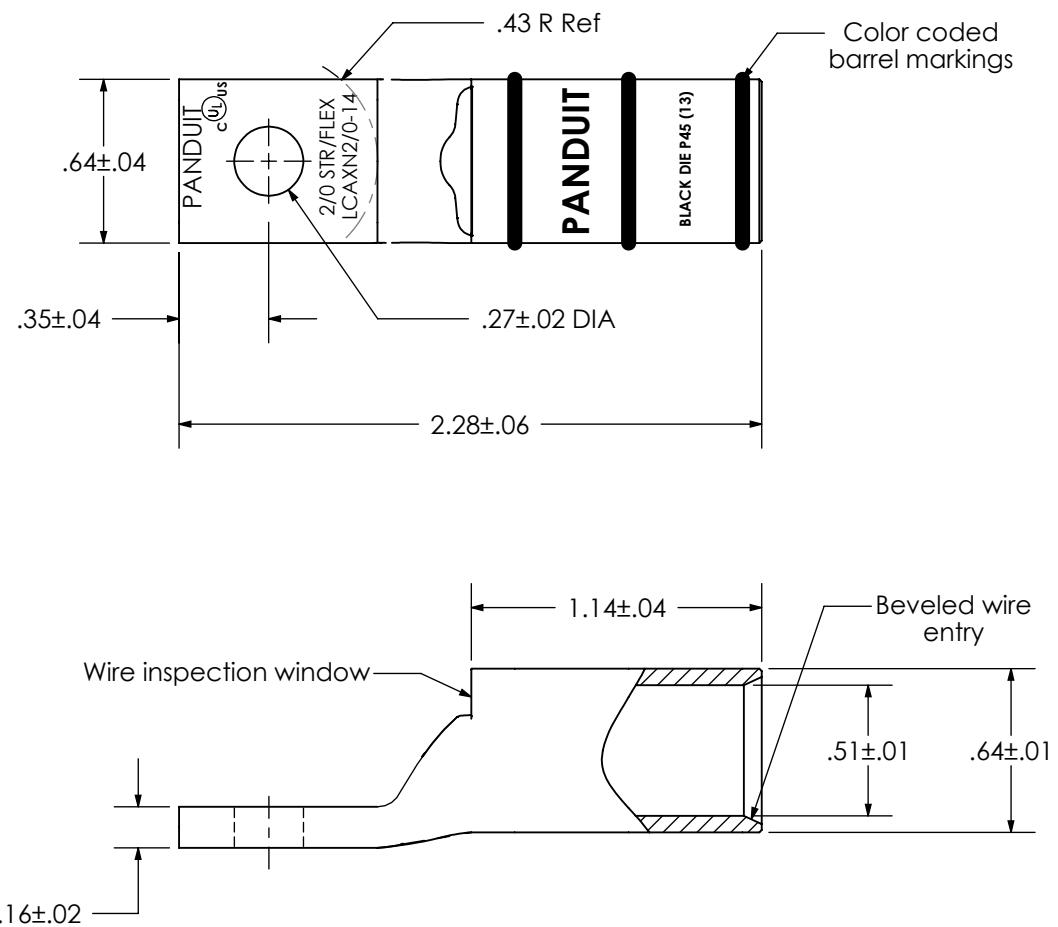

|     |       |      |      |     |                  |                               |
|-----|-------|------|------|-----|------------------|-------------------------------|
| 00  | 12/16 | JHNU | JHNU | RGB | DRAWING RELEASED | 00159NBM-<br>LCAXN2/0-14-CUST |
| REV | DATE  | BY   | CHK  | APR | DESCRIPTION      | ECN                           |

**PANDUIT** CORP. TINLEY PARK, ILLINOIS  
LCAXN2/0-14-X  
Copper Lug - One-Hole, Narrow Tongue, Standard Flex Barrel  
DRAWING NO / CAD FILE LCAXN2\_0-14-CUST