
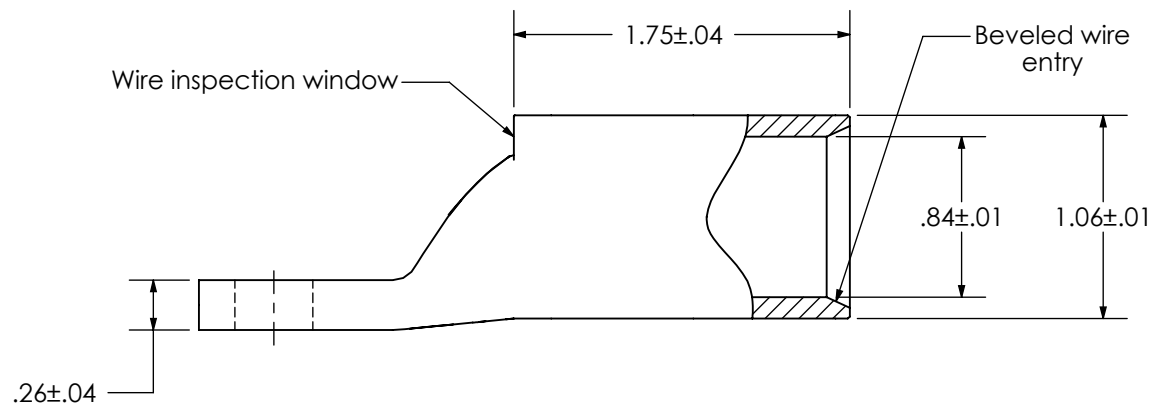



Material	High Conductivity Seamless Copper Tube
Plating	Electro-Tin
Wire Size	350 STR/FLEX
Wire Type	Stranded Copper: Class G, H, I, K, M, Locomotive
Wire Strip Length	1-13/16 in.
Stud Size	3/8 in.
UL Listed Wire Connector	Yes, for applications up to 35kv. Consult cable manufacturer for voltage stress relief instructions with applications greater than 2000 volts.
UL Temperature Rating	90° C
C.S.A Certified Wire Connector	N/A
Panduit Color Code on Barrel	BLUE
Panduit Die Index No. on Barrel	P76
Alternate Industry Die Index No. ( ) on Barrel	(19)

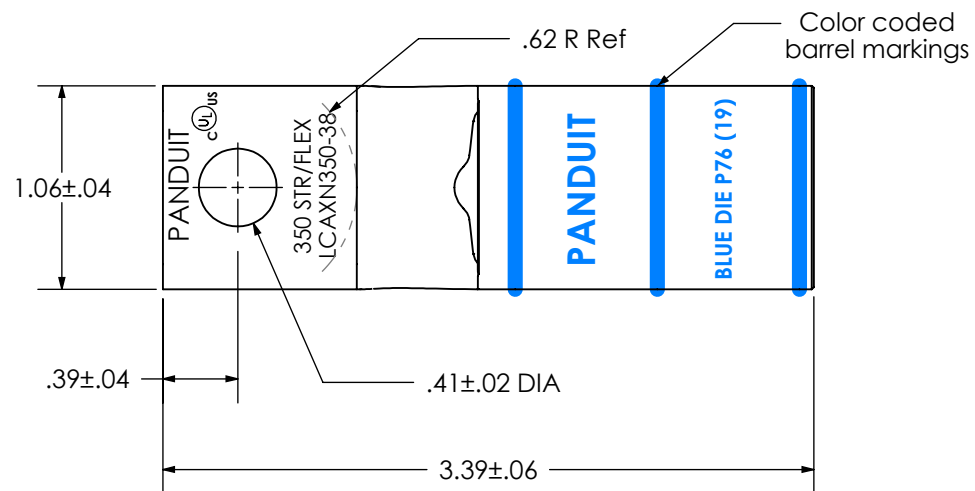

							 <b>PANDUIT CORP. TINLEY PARK, ILLINOIS</b>	
							LCAXN350-38-6 Copper Lug - One-Hole, Narrow Tongue, Standard Flex Barrel	
00	12/16	JHNU	JHNU	RGB	DRAWING RELEASED	00159NCA-LCAXN350-38-CUST		
<b>REV</b>	<b>DATE</b>	<b>BY</b>	<b>CHK</b>	<b>APR</b>	<b>DESCRIPTION</b>	<b>ECN</b>	<b>SCALE</b> N/A	<b>DRAWING NO / CAD FILE</b> LCAXN350-38-CUST