


170° WIDE BEAM LED CHANNEL for SMALL or MEDIUM CHANNEL LETTERS and SIGN BOXES

FEATURES

12V DC
IP67
50,000 Life Hours/5 Year Warranty
115 lm/W High Efficacy
Operating Temperature -20°C to +70°C
170° Wide Beam
50 Modules Per Strand
Can be Produced in Various Colors

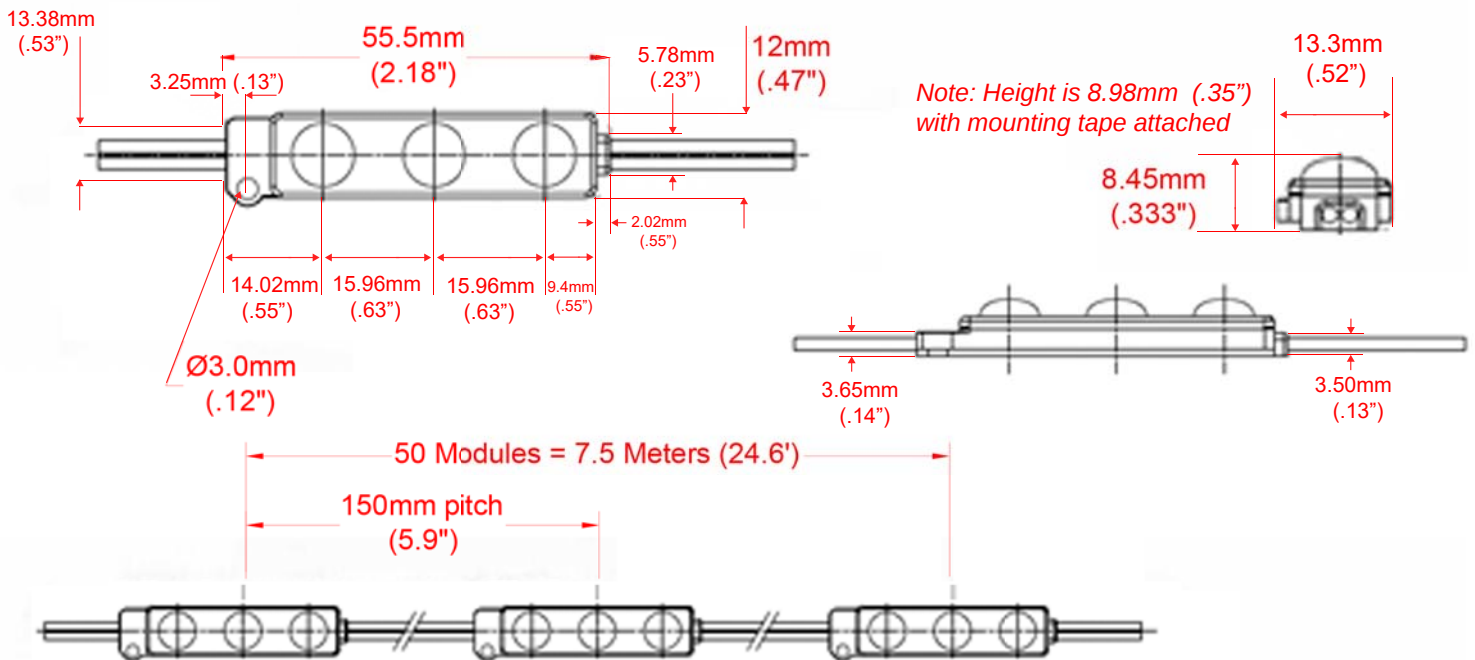

NOTES:

Mounting can be accomplished with double sided tape that is on the backside of modules. Screw holes are also present.
Wire with Red Stripe is Positive Input.
Use no more than 50 modules in series.
Take care to prevent exposed wire on the ends.

JKL US
E339601

JKL Part Number	Input Voltage	Power per Module	CCT	Beam Angle	CRI	Lumen Flux Per Module	Lumen Efficacy	No. Modules Per a Pack
ZM-333-CW	12V DC	0.66 W	6500K	170°	Ra80	76 lm	115 lm/W	50/7.5 Meters

METRIC			DIMENSIONS ARE IN mm (INCHES)			JKL COMPONENTS CORPORATION			
THIRD ANGLE PROJECTION			TOLERANCE UNLESS OTHERWISE SPECIFIED			TITLE			
DRAWN BY			APPV'D BY			DATE			
L. WENGSTROM			S.C.			9/14/19			
- CAD DRAWING -			MANUAL REVISIONS NOT PERMITTED			NONE			
A			ADDED DIMENSIONS			3/3/22			
RELEASED			9/14/19			ZM-333-CW			
REV. NO.			DESCRIPTION/ECO NUMBER			RELEASED DATE			
A			3/3/2022			REVISION DATE			
A			1 OF 1			SHEET			