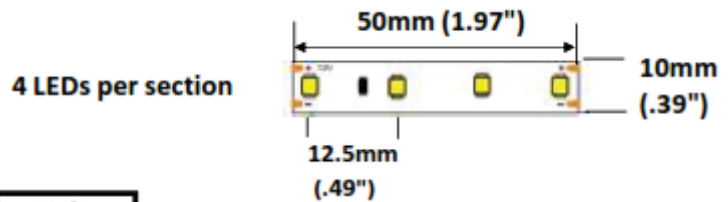
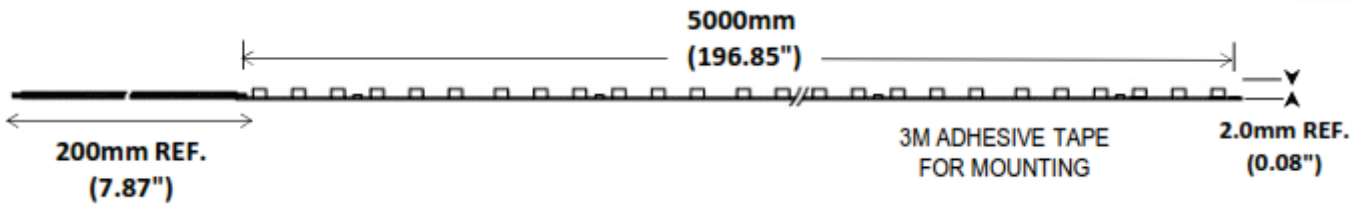
 


Features**VOLTAGE: 12V DC****CURRENT: 2.5 AMPS****LED VIEWING ANGLE: 120°****STANDARD PACKAGING:****5 METER REEL (400 LED'S)**

Parameter	Symbol	Rating	Units
Forward Current	IF	2.5	A
Power Dissipation	PD	30	W
Electrostatic Discharge	ESD	800	V
Operating Temperature	Topr	-20~+50°C	°C
Storage Temperature	Tstg	-30~+80°C	°C

**Electro-Optical Characteristics (Ta=25°C)**

JKL Part Number	Color	Number of LEDs	Input Voltage (V DC)	Power (W)	Current (A)	Radiance Angle	CCT (K)	Lumen Flux (lm)
ZFS-105000-12WW	Warm White	400	12	30	2.5	120°C	3050°K	3,750
ZFS-105000-12NW	Neutral White	400	12	30	2.5	120°C	4250°K	3,990
ZFS-105000-12CW	Cool White	400	12	30	2.5	120°C	6250°K	4,200

Note:**Maximum length in series: 5 Meters (16 feet) / 1 Reel****METRIC**THIRD ANGLE
PROJECTIONDIMENSIONS ARE
IN MILLIMETERSTOLERANCE UNLESS
OTHERWISE SPECIFIED1 PL +/- REF.
2 PL +/- REF.
ANGLE +/- 0DRAWN BY
S.NewtonAPPV'D BY DATE
S.N. 5/16/22**JKL****COMPONENTS CORPORATION**

TITLE

HIGH BRIGHTNESS 10MM LED FLEX RIBBON,12VDC

SIZE

AFSCM NO.
55335

DRAWING NO.

ZFS-105000-12 MULTI

SCALE

NONE

RELEASED DATE

5/16/22

REVISION DATE

1 OF 1

REV. NO.

1 OF 1

SHEET

1 OF 1

RELEASED

5/16/22

REV. NO.

DESCRIPTION/ECO
NUMBERAPPV'D
DATE

MANUAL REVISIONS NOT PERMITTED