

Operation:DIP/立插式 短体 导边鱼叉型 2.0USB 连接器 (Type-A)**ITEM NO.:**USB-101-B (Series) 黑色主体

(L13.1×W7.4×H10.0 2.0-USB-CONNECTORS)

表面插装 DIP

正向操作

精密部品 NICETY

可靠 STABILIZE

適合環保 RoHS

Technical parameter

PROJECT \ LEVEL		A[better product]	B[average product]
Electrical Properties	Contact Rating	0.25A, 24V DC	
	Initial Contact Resistance	50mΩ max.	
	Insulation Resistance	100MΩ min.500V DC Skey/PD: 100MΩ min.300V DC	
	Withstand Voltage	500V AC for 1 minute	350 V AC for 1 minut
Durable Performance	There No Load	6,000 Cycles	5,000 Cycles
	Rated Load	5,000 Cycles	4,000 Cycles
	Storage temp.	-35℃~+75℃(Operating Temp:)	
Operating Force		IF:20N MAX. (EF:10.0N MIN.)	
Heat Rrsistance		IR Reflow:235℃, 5sec. Manual:350℃, 3sec.	







 
Material declaration

No.	NAME	Description
① A	胶芯	黑色 PBT 耐热塑胶
② B	接触端子	磷铜 C5191 (镀金 1u" /焊尾雾锡)
③ C	外壳	黄铜 C2680/SPCC[镀镍 50u" min]

PIN SIGNAL

1	VCC	+5V
2	-DATA 0	Neagative Data Channel 0
3	+DATA 0	Positive Data Channel 0
4	GND	Ground

Unit:mm

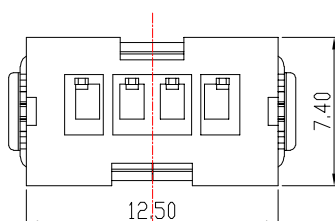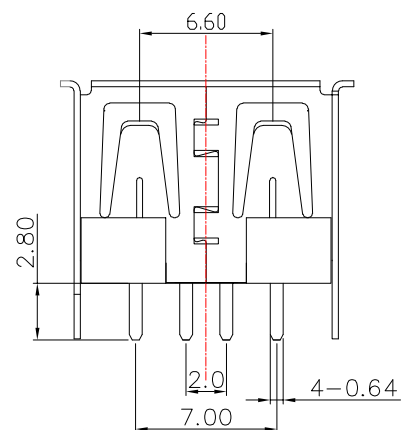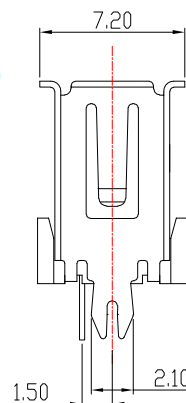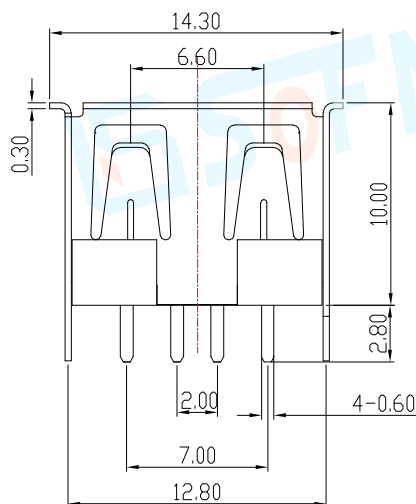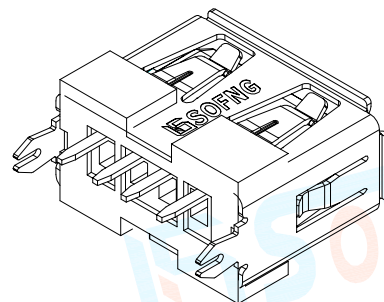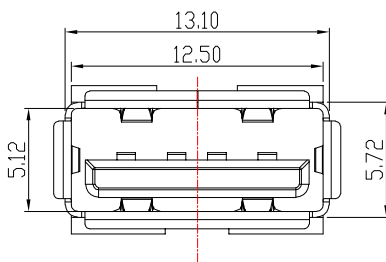

P.C.B LAYOUT

