





CHIP COMMON MODE CHOKE

High Common Mode Impedance at High Frequency.
Excellent Noise Suppression Performance.
Small Size and Low Profile, Surface Mount Type.
Operating Temperature Range: -40°C to +85°C
RoHS Compliant.


Part Number	Electrical Specifications @25°C						
	Inductance 100KHz 0.1V (uH Min)	Capacitance 100K 0.1V (pF Max)	DCR (Ω Max)	Rated Current mA Max	Rated Volt (Vdc)	Withstand Volt 1mA 1S (Vdc Max)	IR M(Ω Min)
LG3216T01 X	60	25	1.7	200	50	125	10

MECHANICAL

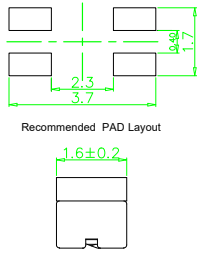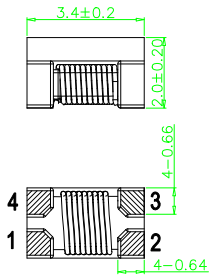


Dimensions in mm

 
SCHEMATICS




IMPEDEANCE FREQUENCY

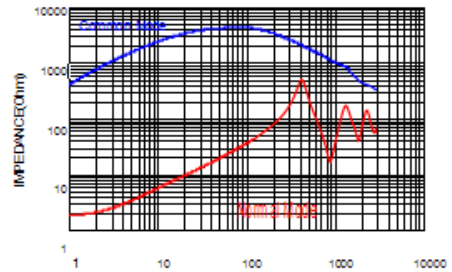

TAPING AND PACKING

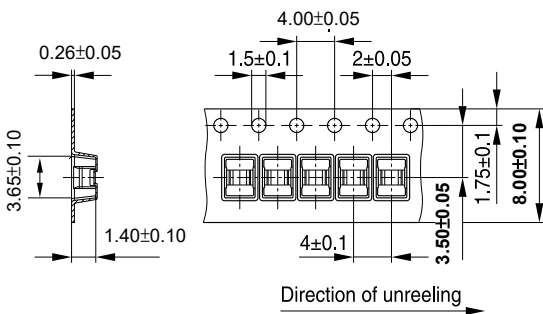

Reel

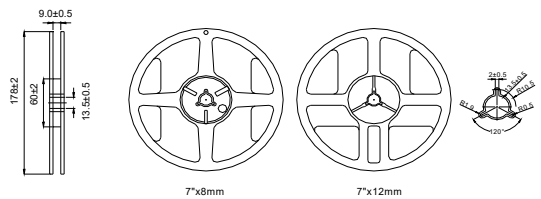

Dimensions in mm

Quantity (pcs):
2000 PCS PER REEL
5 REELS PER CARTON
10000PCS PER CARTON