

Operation: DIP/卧式 无导边 3.0USB-B 型连接器

(TYPE-A)



LTEM NO.:U30-01D (Series)

(L16.5×W13.1×H7.0 3.0-USB-CONNECTORS)

表面插装 DIP

側向操作

精密部品 NICETY

可靠 STABILIZE

適合環保 RoHS






 


Technical parameter

PROJECT	LEVEL	A[better product]	B[average product]
Electrical Properties	Contact Rating	1.0A, 24V DC	
	Initial Contact Resistance	50mΩ max.	
	Insulation Resistance	100MΩ min.500V DC Skey/PD: 100MΩ min.300V DC	
	Withstand Voltage	500V AC for 1 minute	350 V AC for 1 minut
Durable Performance	There No Load	6,000 Cycles	5,000 Cycles
	Rated Load	5,000 Cycles	4,000 Cycles
	Storage temp.	-40℃~+85℃(Operating Temp:)	
	Operating Force	IF:20N MAX. (EF:10.0N MIN.)	
	Heat Rrsistance	IR Reflow:235℃, 5sec. Manual:350℃, 3sec.	

PIN SIGNAL

No.	NAME	Description
① A	胶芯	LCP 30%UL94V-0 耐热塑胶 [Black]
② B	胶体	LCP 30%UL94V-0 耐热塑胶 [Black]
③ ④	接触端子	磷铜 C5191 (镀金 1u" /焊尾雾锡)
⑤ E	外壳	黄铜 C2680/SPCC [镀镍 50u" min]

Unit:mm

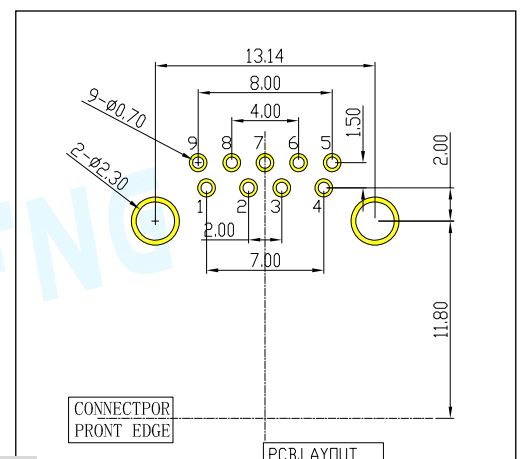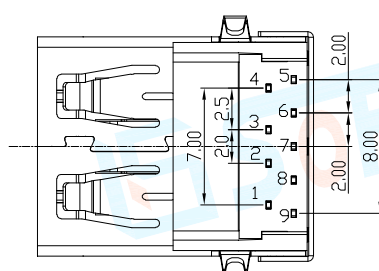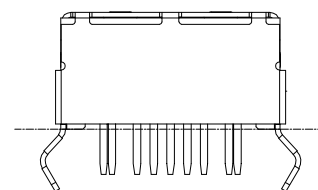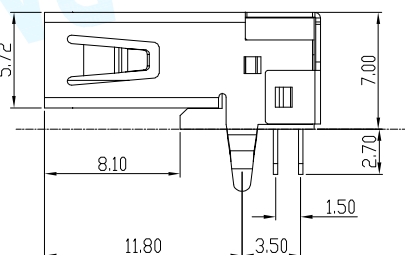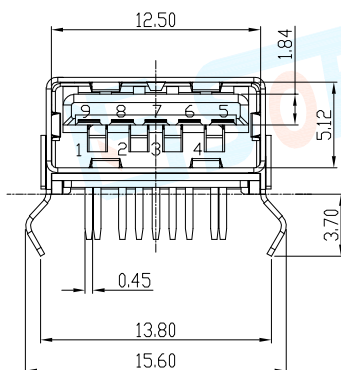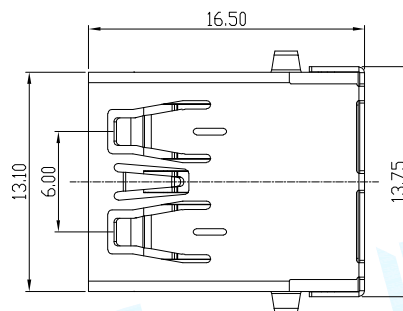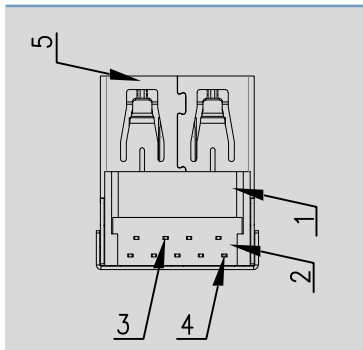

P.C.B LAYOUT