

Operation:DIP/卧式 短体导边型 2.0USB 连接器 (Type-A)



LTEM NO.:USB-100-P268 (Series)

(L10.0×W12.5×H6.8 2.0-USB-CONNECTORS)

表面插装 DIP

側向操作

精密部品 NICETY

可靠 STABILIZE

適合環保 RoHS

Technical parameter



PROJECT		LEVEL	A[better product]	B[average product]
Electrical Properties	Contact Rating		0.25A, 24V DC	
	Initial Contact Resistance		50mΩ max.	
	Insulation Resistance		100MΩ min.500V DC Skey/PD: 100MΩ min.300V DC	
Durable Performance	Withstand Voltage		500V AC for 1 minute	350 V AC for 1 minut
	There No Load		6,000 Cycles	5,000 Cycles
	Rated Load		5,000 Cycles	4,000 Cycles
Storage temp.			-35℃~+75℃(Operating Temp:)	
Operating Force			IF:20N MAX. (EF:10.0N MIN.)	
Heat Rrsistance			IR Reflow:235℃, 5sec. Manual:350℃, 3sec.	

PIN SIGNAL

No.	NAME	Description
① A	胶芯	LCP 30% UL94V-0 耐热塑胶
② B	接触端子	磷铜 C5191 (镀金 1u" /焊尾雾锡)
③ C	外壳	黄铜 C2680/SPCC [镀镍 50u" min]

1	VCC	+5V
2	-DATA 0	Neagative Data Channel 0
3	+DATA 0	Positive Data Channel 0
4	GND	Ground

Unit:mm

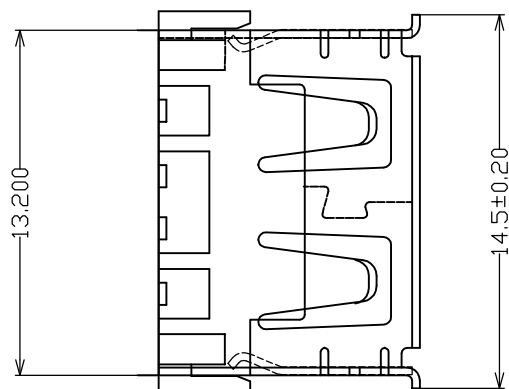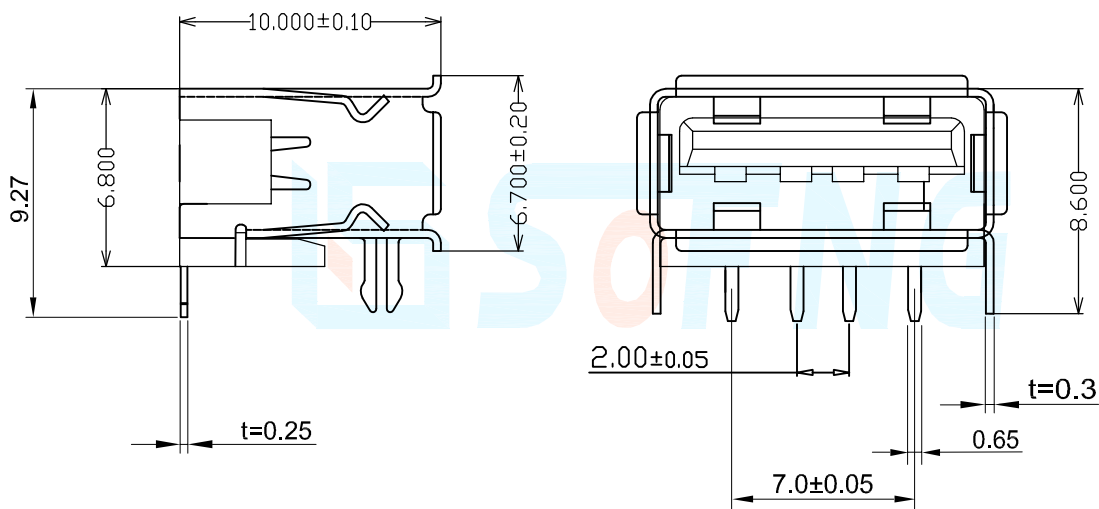

P.C.B LAYOUT

