

Operation: DIP/侧卧式 无导边 短体 2.0USB 连接器 (Type-A)



LTEM NO.: USB-108D (Series)

(L14.0×W5.7×H13.7 2.0-USB-CONNECTORS)

表面插装 DIP

侧向操作

精密部品 NICETY

可靠 STABILIZE

適合环保 RoHS

Technical parameter

PROJECT		LEVEL	A[better product]	B[average product]
Electrical Properties	Contact Rating		0.25A, 24V DC	
	Initial Contact Resistance		50mΩ max.	
	Insulation Resistance		100MΩ min.500V DC Skey/PD: 100MΩ min.300V DC	
Durable Performance	Withstand Voltage		500V AC for 1 minute	350 V AC for 1 minut
	There No Load		6,000 Cycles	5,000 Cycles
	Rated Load		5,000 Cycles	4,000 Cycles
	Storage temp.		-35℃~+75℃(Operating Temp:)	
	Operating Force		IF:20N MAX. (EF:10.0N MIN.)	
	Heat Rrsistance		IR Reflow:235℃, 5sec. Manual:350℃, 3sec.	



PIN SIGNAL

No.	NAME	Description
① A	胶芯	LCP 30% UL94V-0 耐热塑胶
② B	接触端子	磷铜 C5191 (镀金 1u" /焊尾雾锡)
③ C	外壳	黄铜 C2680/SPCC [镀镍 50u" min]

1	VCC	+5V
2	-DATA 0	Neagative Data Channel 0
3	+DATA 0	Positive Data Channel 0
4	GND	Ground

Unit:mm

P.C.B LAYOUT

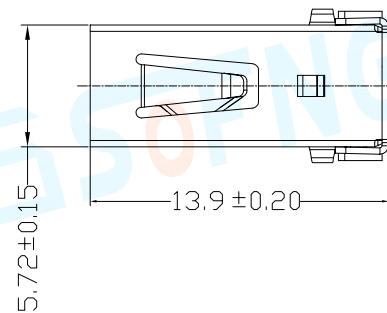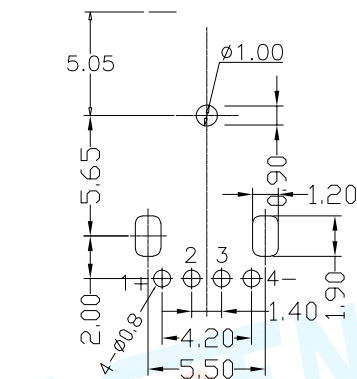

DECIMALS	ANGLES
.X :±0.25	X° :±1.5°
.XX :±0.15	XX° :±1.0°
.XXX :±0.10	XXX° :±0.5°

