
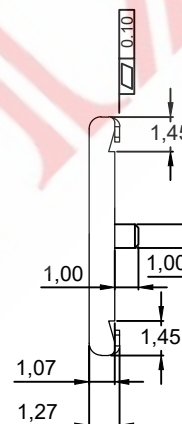
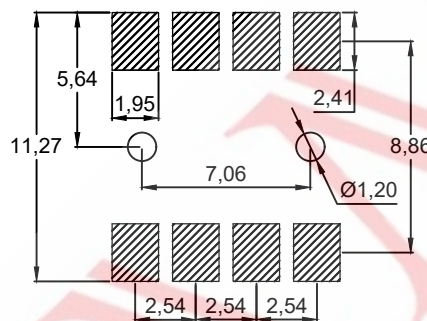
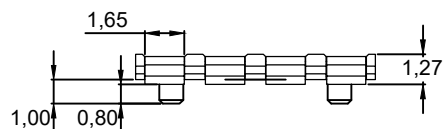


Performance:

1. Rated Current: 3.0 A
2. Rated Voltage: 60 V
3. Withstand Voltage: 500 V
4. Contact Resistance: 30 mΩ
5. Insulation Resistance: 500 MΩ
6. Operating Temperature: -55° C to +125° C
7. Service Life: More than 10,000 times
8. Plastic Parts (Material): PA9T
9. Contact Points (Material): Brass C2680, Gold Plated

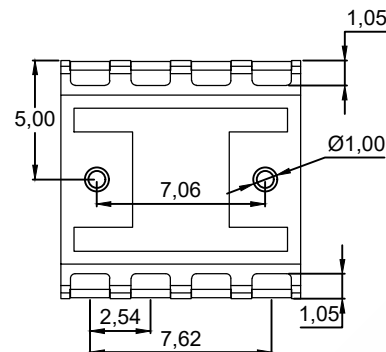


01	F	3	1	4	3	2	0
$\frac{}{\textcircled{A}}$	$\frac{}{\textcircled{B}}$	$\frac{}{\textcircled{C}}$	$\frac{}{\textcircled{D}}$	$\frac{}{\textcircled{E}}$	$\frac{}{\textcircled{F}}$	$\frac{}{\textcircled{G}}$	$\frac{}{\textcircled{H}}$

A. Series: 01:127 Series
B. Spring contact pitch: F-2.54mm
C. Fixing method: 3-180° SMT
D. Product height: 1-H1.27
E. PIN NO: 4-4PIN
F. Main body material: 3-PA9T
G. Spring contact material: 2-C2680 GOLD PLATED
H. Mold code: 0-Convention

RECOMMENDED PCB LAYOUT

TOP VIEW(. XX±0.05)

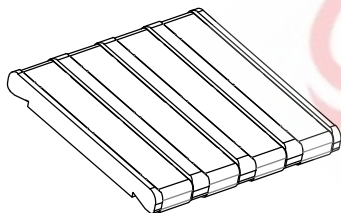

SAMZO COMPONENTS
Electronic switch and connector manufacturer