


PIN RECEPTACLES

FOR .065" - .082" DIAMETER PINS

0394

0394-0-15-XX-07-XX-10-0


Solder mount in .120 min. mounting hole

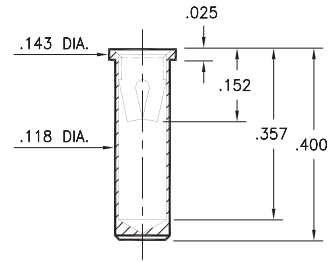

0393

0393-0-15-XX-07-XX-10-0


Solder mount in .144 min. mounting hole

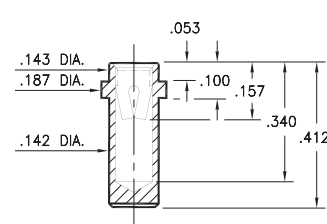

0391

0391-0-15-XX-07-XX-10-0


Solder mount in .159 min. mounting hole

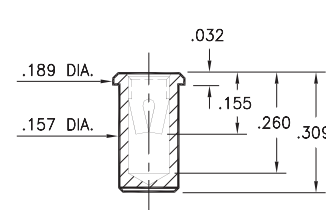

9016

9016-0-15-XX-07-XX-10-0


Press-fit in .131 mounting hole

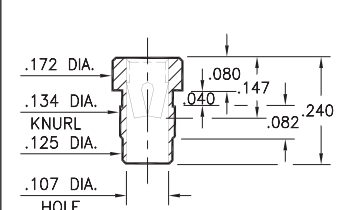

0493

0493-0-15-XX-07-XX-10-0


Press-fit in .144 mounting hole

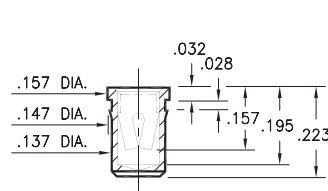

0490

0490-0-15-XX-07-XX-04-0


Press-fit in .144 mounting hole

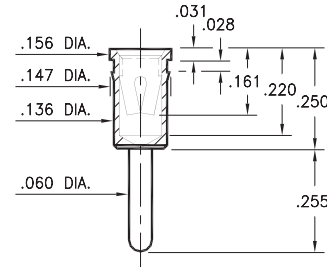

0616

0616-0-18-XX-07-XX-10-0


Press-fit in .144 mounting hole
Accepts wire sizes up to .035" dia.

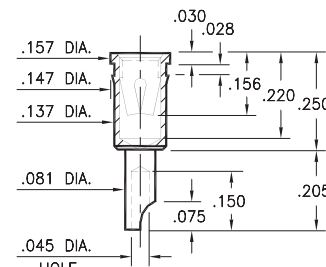

0387

0387-0-15-XX-07-XX-04-0


Solder mount in .063 min. mounting hole

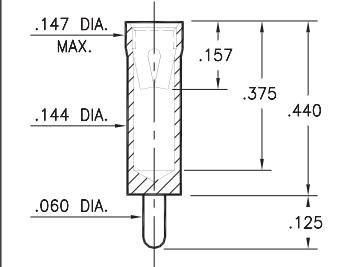

0370

0370-0-19-XX-07-XX-10-0


Wire crimp termination. Accepts wire sizes 20 AWG Max. / 24 AWG Min.

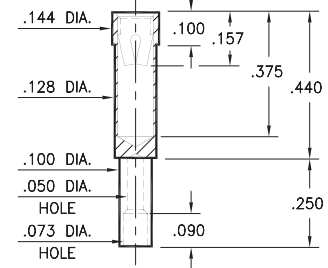

4040

4040-0-19-XX-07-XX-10-0


Wire crimp termination. Accepts wire sizes 16 AWG Max. / 20 AWG Min.

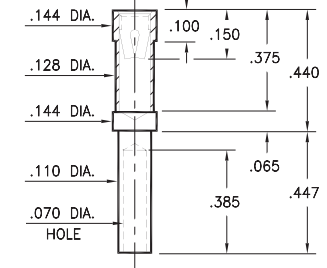

0491

0491-0-19-XX-07-XX-04-0


For use in stackable patch cords

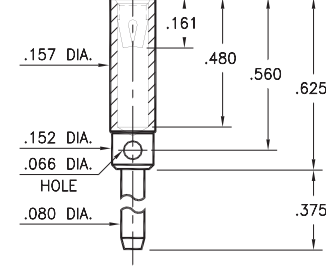

9214

9214-0-15-XX-07-XX-10-0

Solder mount in .083 min. mounting hole

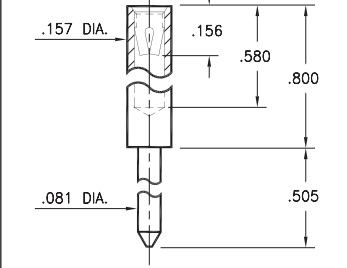

SPECIFICATIONS:

Shell Material: Brass Alloy 360, 1/2 Hard

Contact Material: Beryllium Copper Alloy 172, HT

Dimensions: Inches

Tolerances On: Lengths: $\pm .005$

Diameters: $\pm .002$

Angles: $\pm 2^\circ$



ORDER CODE: XXXX - X - 1X - XX - 07 - XX - XX - 0

BASIC PART #

SPECIFY SHELL FINISH:

- 01 200 μ " TIN/LEAD OVER NICKEL
- ◆ 80 200 μ " TIN OVER NICKEL (RoHS)
- ◆ 15 10 μ " GOLD OVER NICKEL (RoHS)

SPECIFY CONTACT FINISH:

- 01 200 μ " TIN/LEAD OVER NICKEL
- ◆ 80 200 μ " TIN OVER NICKEL (RoHS)
- ◆ 27 30 μ " GOLD OVER NICKEL (RoHS)

SELECT CONTACT:

#07 CONTACT (DATA ON PAGE 261)

(For alternate contact choices, see group H on page 248)



Mill-Max Mfg. Corp. • 190 Pine Hollow Road, P.O. Box 300, Oyster Bay, NY 11771 • 516-922-6000 • Fax: 516-922-9253 • www.mill-max.com