


610-011 Rotatable Coupling "E" Nut

CONNECTOR DESIGNATORS **A-F-H-L-S** ROTATABLE COUPLING

Product Series — **610**
 Connector Designator — **F**
 Angle and Profile — **S**
 S = Straight
 Finish (Table II) — **011**
 Basic Part No. — **M**
 Shell Size (Table I) — **12**

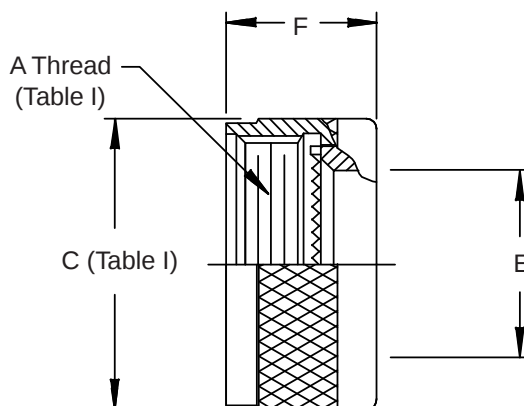

See inside back cover fold-out or pages 13 and 14 for Tables I and II.

TABLE III: CABLE ENTRY				
Shell Size		E Dia		F
Conn. Desig.	H	Ref		Max
A-F-L-S				
08	09	.270 (6.9)		.710 (18.0)
10	11	.375 (9.5)		.710 (18.0)
12	13	.511 (13.0)		.710 (18.0)
14	15	.585 (14.9)		.710 (18.0)
16	17	.710 (18.0)		.710 (18.0)
18	19	.789 (20.0)		.710 (18.0)
20	21	.914 (23.2)		.710 (18.0)
22	23	1.039 (26.4)		.710 (18.0)
24	25	1.154 (29.3)		.710 (18.0)
28		1.389 (35.3)		.890 (22.6)
32		1.635 (41.5)		.890 (22.6)
36		1.850 (47.0)		.890 (22.6)

Metric dimensions (mm) are indicated in parentheses.