



RJ45 AND USB 2.0

Contacts, Tools, and Accessories




660-011 Series 66 Protective Covers for 28840 Type Receptacle Connectors

MIL-DTL-28840 Type

How To Order							
Sample Part Number	660	-011	M	D	H	5	-01
Series	660 = Series 66						
Cover Type	-011 = Metal Receptacle Cover (See Note 2)						
Material and Finish	See Material and Finish Table						
Shell Size Designator	C, D, E						
Lanyard Type	D, S, F, G, H, R, T, U (See Lanyard Type Table)						
Lanyard Length	Length in inches; i.e. 3 = 3 inches						
Ring Style Dash No.	See Tables I, II or III for Ring Selection and Dash Number. Omit for "SK" slip knot attachment						

Table I: Dash No. for Small Ring

 
Dash No.	P Dia ± .010 (0.3)	Dash No.	P Dia ± .010 (0.3)
01	.140 (3.6)	06	.125 (3.2)
02	.182 (4.6)	07	.218 (5.5)
03	.191 (4.9)	09	.156 (4.0)
04	.197 (5.0)	00	no eyelet
05	.167 (4.2)		



For attachment to panel

Table II: Dash No. for Solid Ring (Type A)

Dash No.	Shell Size	N
208	15 (C)	1.203 (30.6)
109	17 (D)	1.266 (32.2)
111	19 (E)	1.521 (38.6)

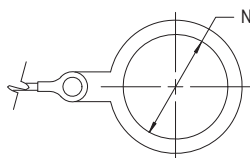

For attachment behind jam nut

Dimensions


Shell Size Designator	Shell Size (Ref.)	F Thread	F Max
C	15	1.062 - 0.1P-0.2L-DS	1.260 (32.0)
D	17	1.125 - 0.1P-0.2L-DS	1.457 (37.0)
E	19	1.312 - 0.1P-0.2L-DS	1.535 (39.0)

Lanyard Type

Sym	Attachment
D	Bead chain, cres passivated, w/ terminal
F	Wire rope, nylon jacket w/ terminal
G	Nylon rope
H	Wire rope, fluoropolymer jacket w/ terminal
N	Attachment omitted
R	Wire rope, PVC jacket w/terminal
T	Wire rope, no jacket, w/terminal
S	#8 Sash chain, cres, passivate
U	Wire rope, polyurethane jacket with terminal

Materials and Finishes²

NF	Aluminum/Cadmium, Olive Drab
M	Aluminum/Electroless Nickel
MT	Aluminum/Nickel PTFE
ZR	Aluminum/Zinc-Nickel Black
Z1	Stainless Steel/Passivate

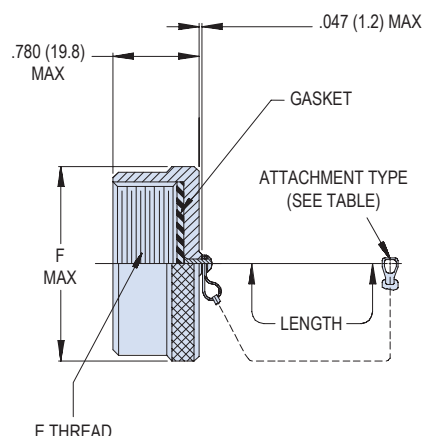

NOTES

1. Length tolerance for Sash Chain (S) is ± 1 link, for all other attachments ± .25.
2. For plug covers contact factory
3. Material and Finish
 - Gasket: Silicone
 - Components, rivet: Stainless Steel/Passivate

Lanyard Types

Bead Chain (Type D)	Sash Chain (Type S)	Rope (Types F, G, H, R, T, U)