


# PIN RECEPTACLES

**FOR 0,38 - 0,46 DIAMETER PINS (#09 CONTACT)  
FOR 0,38 - 0,51 DIAMETER PINS (#11 CONTACT)  
AND 0,38 - 0,56 DIAMETER PINS (#21 CONTACT)**

## 0467

**0467-0-15-XX-21-XX-04-0**

Press-fit in 0,94 mounting hole

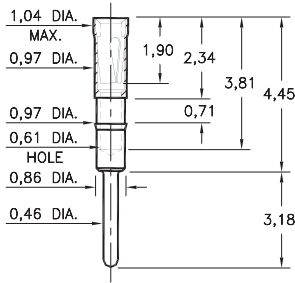

## 0552


**0552-X-15-XX-X1-XX-10-0**

Solder mount in 1,02 min. mounting hole

Also available on 16mm wide carrier tape:

1,500 parts per 330mm reel

Order as: 0552-X-57-XX-X1-XX-10-0

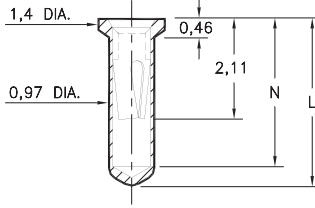


| Basic Part Number | Length L | Depth N |
|-------------------|----------|---------|
| 0552-1            | 3,45     | 3,05    |
| 0552-2            | 4,32     | 3,81    |

## 5522

**5522-0-15-XX-09-XX-10-0**


Solder mount in 1,02 min. mounting hole

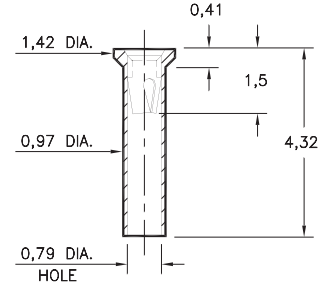

## 0569

**0569-0-15-XX-X1-XX-10-0**


Solder mount in 1,02 min. mounting hole

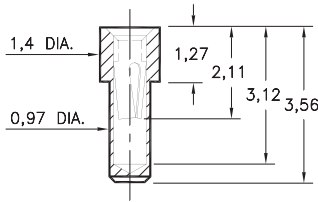

## 6023

**6023-0-15-XX-21-XX-10-0**


Solder mount in 1,02 min. mounting hole

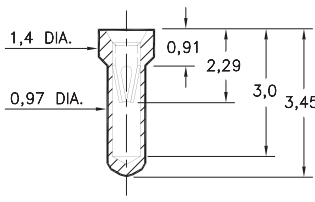

## 6214

**6214-0-15-XX-21-XX-10-0**


Solder mount in 1,02 min. mounting hole

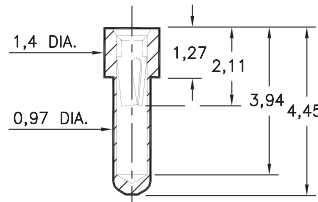

## 2086

**2086-0-15-XX-21-XX-04-0**


Press-fit in 1,02 mounting hole

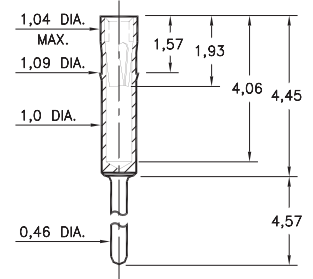

## 0461

**0461-X-15-XX-X1-XX-04-0**

Solder mount in 0,51 min. mounting hole

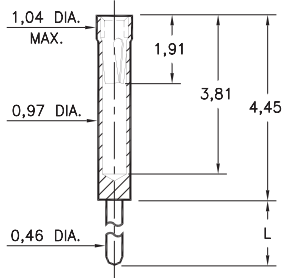

| Basic Part Number | Length L |
|-------------------|----------|
| 0461-0            | 10,16    |
| 0461-1            | 6,99     |
| 0461-2            | 4,57     |
| 0461-3            | 3,18     |
| 0461-4            | 1,52     |
| 0461-5            | 11,18    |

## 8579


**8579-X-15-XX-X1-XX-10-0**

Solder mount in 1,02 min. mounting hole

Also available on 24mm wide carrier tape:

1,200 parts per 330mm reel

Order as: 8579-0-57-XX-X1-XX-10-0

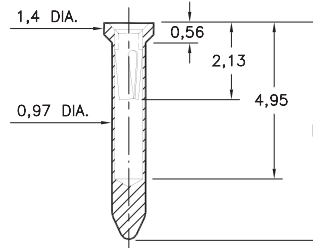

| Basic Part Number | Length L |
|-------------------|----------|
| 8579-0            | 5,94     |
| 8579-1            | 7,49     |

### SPECIFICATIONS:

**Shell Material:** Brass Alloy 360, 1/2 Hard

**Contact Material:** Beryllium Copper Alloy 172, HT

**Dimensions:** Millimeters

**Tolerances On:** Lengths:  $\pm 0,13$   
Diameters:  $\pm 0,051$   
Angles:  $\pm 2^\circ$



**ORDER CODE: XXXX - X - 15 - XX - XX - XX - 0**

**BASIC PART #**

**SPECIFY SHELL FINISH:**

- 01 5,08 $\mu$ m TIN/LEAD OVER NICKEL
- 80 5,08 $\mu$ m TIN OVER NICKEL (RoHS)
- 15 0,25 $\mu$ m GOLD OVER NICKEL (RoHS)

**SPECIFY CONTACT FINISH:**

- 02 2,54 $\mu$ m TIN/LEAD OVER NICKEL
- 84 2,54 $\mu$ m TIN OVER NICKEL (RoHS)
- 27 0,76 $\mu$ m GOLD OVER NICKEL (RoHS)

**SELECT CONTACT:**

**#09, #11 or #21 CONTACT (DATA ON PAGES 250 & 251)**

(For alternate contact choices, see group A on page 248)



Mill-Max Mfg. Corp. • 190 Pine Hollow Road, P.O. Box 300, Oyster Bay, NY 11771 • 516-922-6000 • Fax: 516-922-9253 • www.mill-max.com