


# PIN RECEPTACLES

FOR 0,81 - 1,17 DIAMETER PINS

## 0344

0344-X-19-XX-34-XX-10-0

Swage mount in 1,70 hole

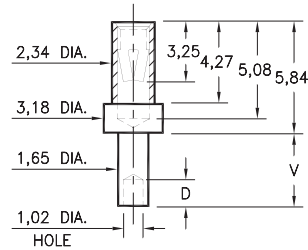


| Basic Part Number | Board Thickness | Length V | Depth D |
|-------------------|-----------------|----------|---------|
| 0344-1            | 0,78            | 1,57     | 1,02    |
| 0344-2            | 1,57            | 2,39     | 1,57    |
| 0344-3            | 2,39            | 3,18     | 1,57    |
| 0344-4            | 3,18            | 3,96     | 1,57    |

## 0349

0349-X-31-XX-34-XX-10-0

Swage mount in 3,28 hole

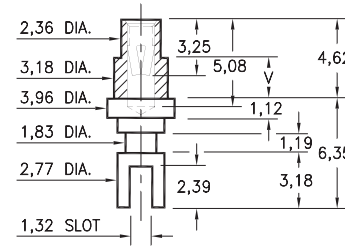


| Basic Part Number | Board Thickness | Length V |
|-------------------|-----------------|----------|
| 0349-2            | 1,57            | 2,39     |
| 0349-3            | 2,39            | 3,18     |
| 0349-4            | 3,18            | 3,96     |

## 0323

0323-X-15-XX-34-XX-10-0


Swage mount in 2,39 hole

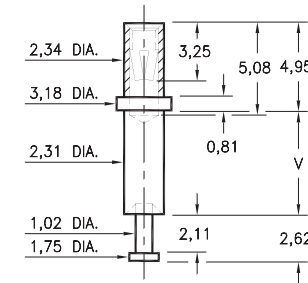

## 0324

0324-X-15-XX-34-XX-10-0

Swage mount in 2,39 hole

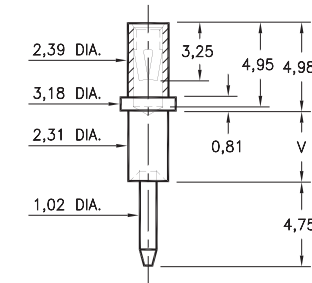


| Basic Part Number | Board Thickness | Length V |
|-------------------|-----------------|----------|
| 032X-1            | 0,79            | 1,57     |
| 032X-2            | 1,57            | 2,39     |
| 032X-3            | 2,39            | 3,18     |
| 032X-4            | 3,18            | 3,96     |
| 032X-5            | 4,78            | 5,56     |

## 0348

0348-0-33-XX-34-XX-10-0


Wire crimp termination. Accepts wire sizes 20 AWG Max. / 24 AWG Min.

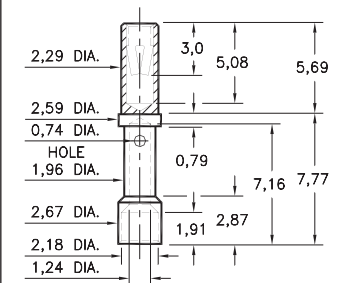

## 0405

0405-0-15-XX-34-XX-04-0


Press-fit in 2,13 mounting hole

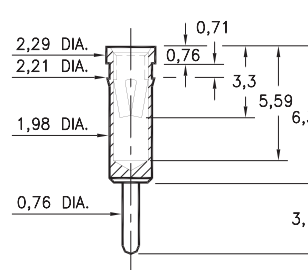

## 0336

0336-0-15-XX-34-XX-04-0


Press-fit in 2,26 mounting hole

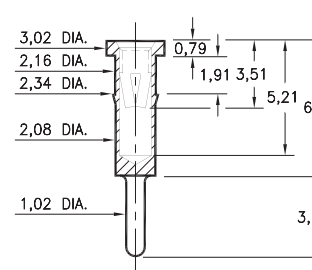

## 0322

0322-0-15-XX-34-XX-10-0


Solder mount in 2,26 min. mounting hole

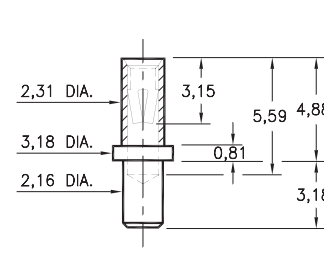

## 0325

0325-0-15-XX-34-XX-10-0

Press-fit in 2,29 mounting hole

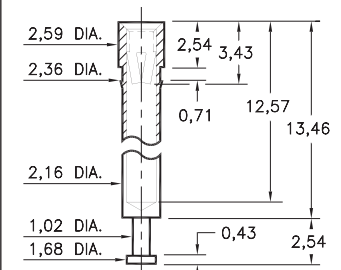

### SPECIFICATIONS:

Shell Material: Brass Alloy 360, 1/2 Hard

Contact Material: Beryllium Copper Alloy 172, HT

Dimensions: Millimeters

Tolerances On: Lengths:  $\pm 0,13$   
Diameters:  $\pm 0,051$   
Angles:  $\pm 2^\circ$

RoHS-2  
2011/65/EU

ORDER CODE: XXXX - X - XX - XX - 34 - XX - XX - 0

BASIC PART #

SPECIFY SHELL FINISH:

- 01 5,08µm TIN/LEAD OVER NICKEL
- ◆ 80 5,08µm TIN OVER NICKEL (RoHS)
- ◆ 15 0,25µm GOLD OVER NICKEL (RoHS)

SPECIFY CONTACT FINISH:

- 01 5,08µm TIN/LEAD OVER NICKEL
- ◆ 80 5,08µm TIN OVER NICKEL (RoHS)
- ◆ 27 0,76µm GOLD OVER NICKEL (RoHS)

SELECT CONTACT:

#34 CONTACT (DATA ON PAGE 258)

(For alternate contact choices, see group E on page 248)



Mill-Max Mfg. Corp. • 190 Pine Hollow Road, P.O. Box 300, Oyster Bay, NY 11771 • 516-922-6000 • Fax: 516-922-9253 • www.mill-max.com