



# D-SUB STANDARD – IP67

Solder pin – Angled – .276"/7.0 mm – Precision machined contacts – Metal bracket

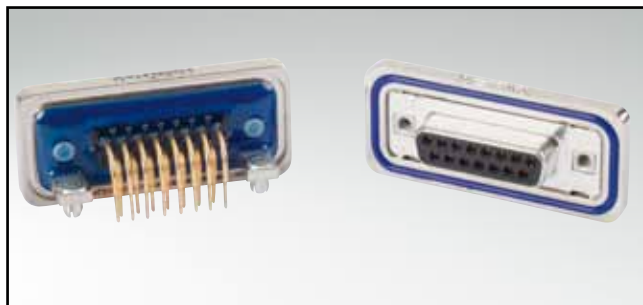


RoHS compliant - CSA listed, File No.LR115000-1 UL listed, File No. E202784


## SOCKET CONNECTOR

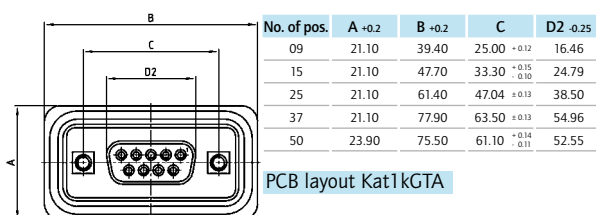

Mounting style: Mounting bracket, threaded insert

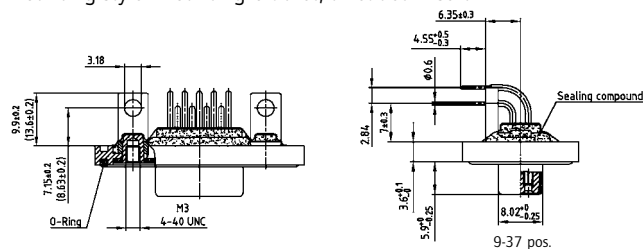


Mounting style: PCB clip, threaded insert

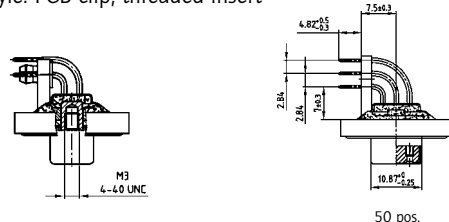


## DESCRIPTION

- Mounting styles:
  - with mounting bracket and 4-40 UNC or M3 threaded insert including hex locking bolt
  - with mounting bracket, PCB clip and M3 or UNC 4-40 threaded insert including hex locking bolt
- Quality class 3 (also available in quality class 1)
- Shell: Brass tin plated (stainless steel available on request)
- Nickel plated die-cast frame (Black plastic frame on request)


## PLUG CONNECTOR

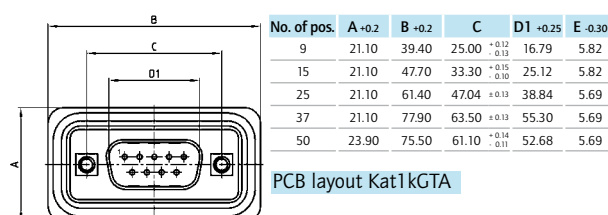

Mounting style: Mounting bracket, threaded insert

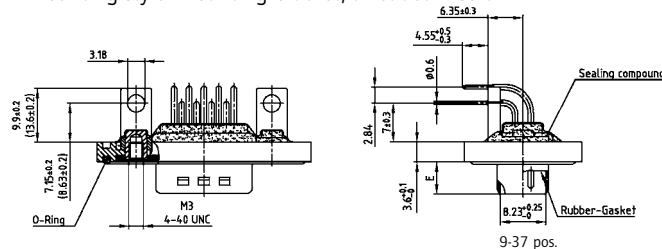

Mounting style: PCB clip, threaded insert

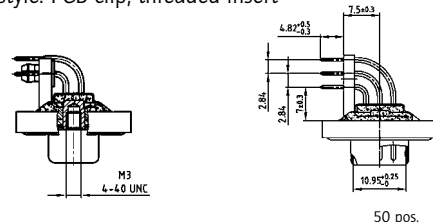

## ORDER DATA

| SOCKET CONNECTOR |                                     |                   |
|------------------|-------------------------------------|-------------------|
| No. of pos.      | Mounting style                      | Part Number       |
| 09               | M3 Threaded insert                  | 6 STD09SAU99R10 X |
| 15               | M3 Threaded insert                  | 6 STD15SAU99R10 X |
| 25               | M3 Threaded insert                  | 6 STD25SAU99R10 X |
| 37               | M3 Threaded insert                  | 6 STD37SAU99R10 X |
| 50               | M3 Threaded insert                  | 6 STD50SAU99R10 X |
| 09               | 4-40 UNC Threaded insert            | 6 STD09SAU99R20 X |
| 15               | 4-40 UNC Threaded insert            | 6 STD15SAU99R20 X |
| 25               | 4-40 UNC Threaded insert            | 6 STD25SAU99R20 X |
| 37               | 4-40 UNC Threaded insert            | 6 STD37SAU99R20 X |
| 50               | 4-40 UNC Threaded insert            | 6 STD50SAU99R20 X |
| 09               | PCB clip / M3 Threaded insert       | 6 STD09SAU99R30 X |
| 15               | PCB clip / M3 Threaded insert       | 6 STD15SAU99R30 X |
| 25               | PCB clip / M3 Threaded insert       | 6 STD25SAU99R30 X |
| 37               | PCB clip / M3 Threaded insert       | 6 STD37SAU99R30 X |
| 50               | PCB clip / M3 Threaded insert       | 6 STD50SAU99R30 X |
| 09               | PCB clip / 4-40 UNC Threaded insert | 6 STD09SAU99R40 X |
| 15               | PCB clip / 4-40 UNC Threaded insert | 6 STD15SAU99R40 X |
| 25               | PCB clip / 4-40 UNC Threaded insert | 6 STD25SAU99R40 X |
| 37               | PCB clip / 4-40 UNC Threaded insert | 6 STD37SAU99R40 X |
| 50               | PCB clip / 4-40 UNC Threaded insert | 6 STD50SAU99R40 X |

| PLUG CONNECTOR |                                     |                   |
|----------------|-------------------------------------|-------------------|
| No. of pos.    | Mounting style                      | Part Number       |
| 09             | M3 Threaded insert                  | 6 STD09PAU99R10 X |
| 15             | M3 Threaded insert                  | 6 STD15PAU99R10 X |
| 25             | M3 Threaded insert                  | 6 STD25PAU99R10 X |
| 37             | M3 Threaded insert                  | 6 STD37PAU99R10 X |
| 50             | M3 Threaded insert                  | 6 STD50PAU99R10 X |
| 09             | 4-40 UNC Threaded insert            | 6 STD09PAU99R20 X |
| 15             | 4-40 UNC Threaded insert            | 6 STD15PAU99R20 X |
| 25             | 4-40 UNC Threaded insert            | 6 STD25PAU99R20 X |
| 37             | 4-40 UNC Threaded insert            | 6 STD37PAU99R20 X |
| 50             | 4-40 UNC Threaded insert            | 6 STD50PAU99R20 X |
| 09             | PCB clip / M3 Threaded insert       | 6 STD09PAU99R30 X |
| 15             | PCB clip / M3 Threaded insert       | 6 STD15PAU99R30 X |
| 25             | PCB clip / M3 Threaded insert       | 6 STD25PAU99R30 X |
| 37             | PCB clip / M3 Threaded insert       | 6 STD37PAU99R30 X |
| 50             | PCB clip / M3 Threaded insert       | 6 STD50PAU99R30 X |
| 09             | PCB clip / 4-40 UNC Threaded insert | 6 STD09PAU99R40 X |
| 15             | PCB clip / 4-40 UNC Threaded insert | 6 STD15PAU99R40 X |
| 25             | PCB clip / 4-40 UNC Threaded insert | 6 STD25PAU99R40 X |
| 37             | PCB clip / 4-40 UNC Threaded insert | 6 STD37PAU99R40 X |
| 50             | PCB clip / 4-40 UNC Threaded insert | 6 STD50PAU99R40 X |

PCB clip .122"/3.1 ± .004"/0.10 mm hole diameter and .063"/1.6 mm circuit board thickness