




MICRO SWITCH
a Honeywell Division
FED. MFG. CODE 91929

ASSEMBLY - TOGGLE SWITCH

CATALOG LISTING

68AT59 SERIES CHART 2

CATALOG LISTING 	KEYWAY POSITION		CENTER POSITION		OPPOSITE KEY-WAY POSITION		RECOMMENDED LOCKING COMBINATIONS
	C-NC	C-NO	C-NO	C-NC	C-NC	C-NO	
68AT59-1	1,2,3,4	5,6,7,8	NONE	ALL	5,6,7,8	1,2,3,4	A,B,D,E,F,G,H,J,K,L,M,N,P
68AT59-3	1,2,3,4	5,6,7,8	NONE	NONE	5,6,7,8	1,2,3,4	D,F,G
68AT59-5	1,2,3,4*	5,6,7,8*	NONE	ALL	5,6,7,8	1,2,3,4	K,N
68AT59-7	1,2,3,4*	5,6,7,8*	NONE	ALL	5,6,7,8*	1,2,3,4*	E,L,N
* ASTERISK DENOTES MOMENTARY POSITION							

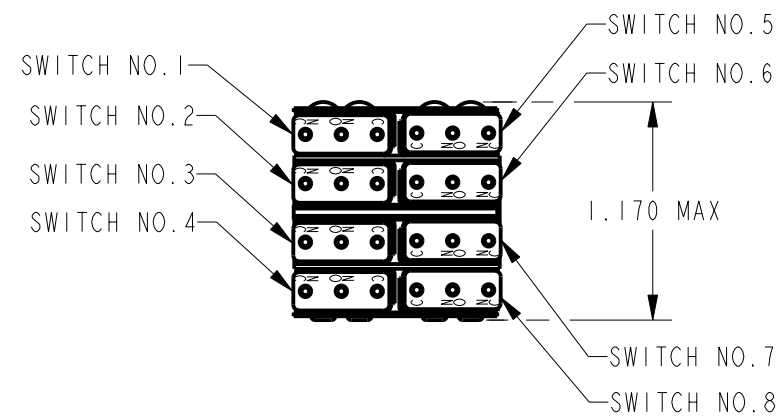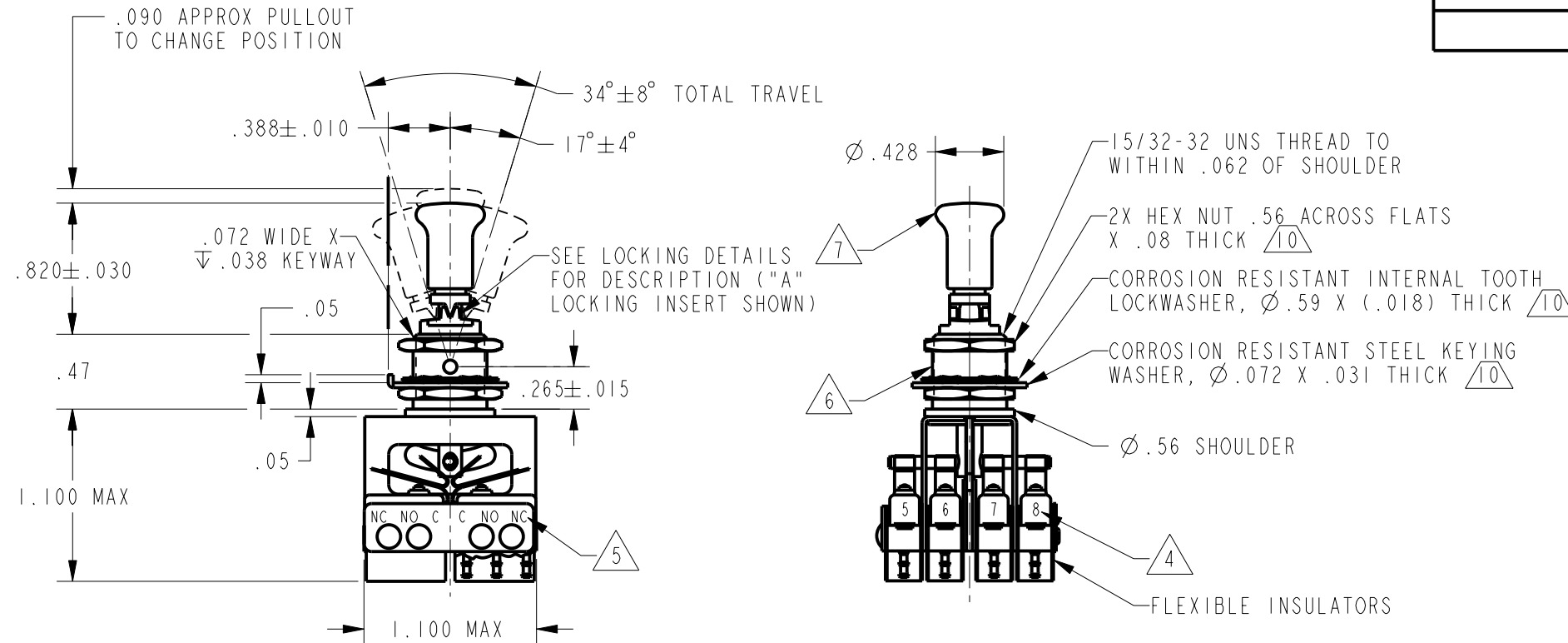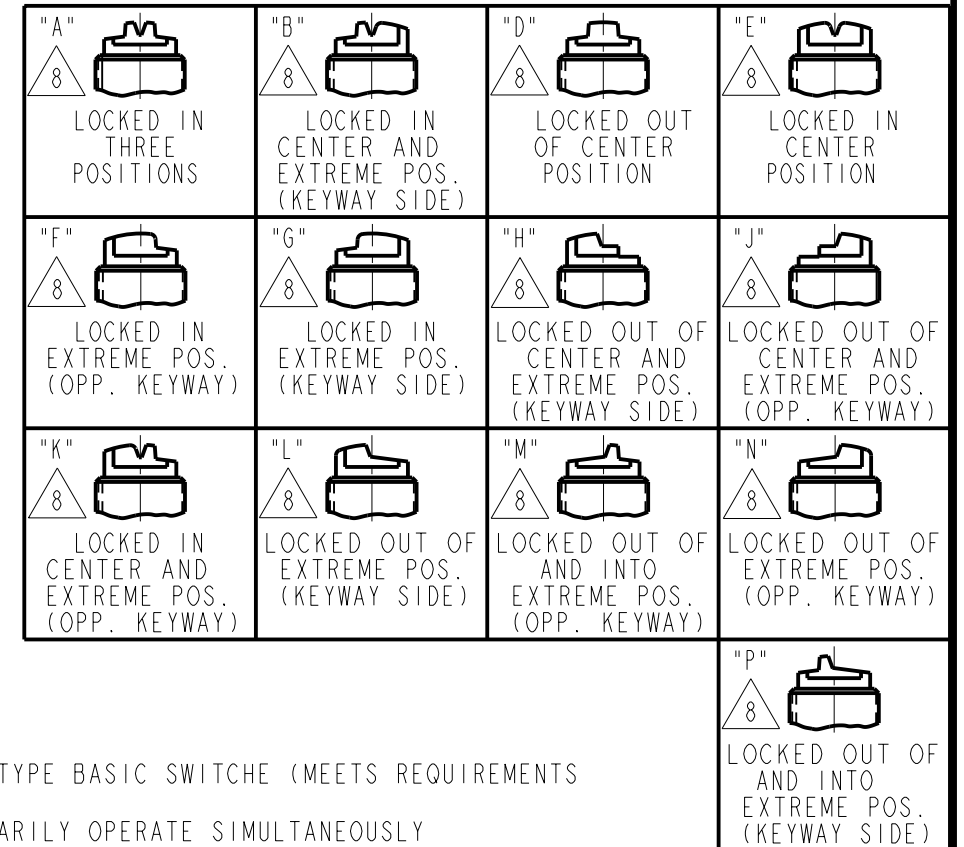


- NOTES

 - 1 - UNIT INCLUDES 8X "SX" TYPE BASIC SWITCHE (MEETS REQUIREMENTS OF MIL-S-6743)
 - 2 - SWITCHES DO NOT NECESSARILY OPERATE SIMULTANEOUSLY
 - 3 - TERMINALS ARE PLATED FOR SOLDERING
 - 4 - SWITCH NUMBERS STAMPED ON END OF BASIC SWITCHES
 - 5 - TERMINAL DESIGNATION STAMPED ON BOTH SIDES OF UNIT
 - 6 - DULL FINISH ON BUTTON, LEVER AND BUSHING
 - 7 - MATTE FINISH
 - 8 - SUFFIX LETTER MUST BE ADDED FOR DESIRED TYPE TOGGLE LOCKING (SEE CHART FOR RECOMMENDED LOCKING COMBINATIONS)
 - 9 - FOR REPLACEMENT BUTTON SEE MICRO SWITCH CAT. LISTING 15PA90-6W
 - 10 - HARDWARE FURNISHED ASSEMBLED WITH SWITCH OR IN PACKET PER MIL-PRF-8805
 - 11 - REPLACEMENT NOUNT HARDWARE PACKET 15PA313-AT

THIS DRAWING COVERS A PROPRIETARY ITEM AND IS THE PROPERTY OF MICRO SWITCH, A DIVISION OF HONEYWELL. THIS DRAWING IS NOT TO BE COPIED OR USED WITHOUT THE APPROVAL OF MICRO SWITCH

CHARACTERISTICS	ELECTRICAL DATA
PULLOUT FORCE ---3 LB MIN-5 LB MAX	CONTACT ARRANGEMENT 8X S P D T

 THIRD ANGLE PROJECTION



SCALE	FULL	
DO NOT SCALE PRINT		
UNLESS OTHERWISE SPECIFIED TOLERANCES ARE		
ONE PLACE	(.0)	+ .030
TWO PLACE	(.00)	+ .015
THREE PLACE	(.000)	+ .005
ANGLES		±
WEIGHT	.11 LB EST	

ELECTRICAL RATING

LOAD	SEA LEVEL		50,000 FT
	28 VDC	115 VAC, 60HZ	28 VDC
	(AMPERES)	(AMPERES)	(AMPERES)
RESISTIVE	7	7	4
INDUCTIVE	4	7	2.5
ANSI Y14.5M-1982 APPLIES			