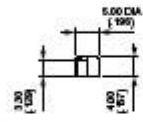
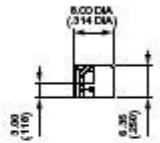
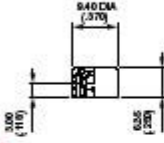
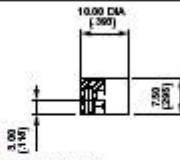
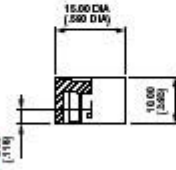
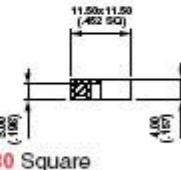
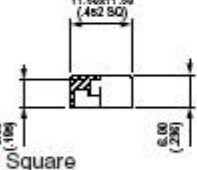





9000 SERIES - MINIATURE MOMENTARY PUSHBUTTON SWITCHES

OPTION DRAWINGS & SPECIAL OPTIONS

CAPS Note: replace last '0' in p/n with color code. (order separately)

 U900	 U1140	 U1720	 U480 Standard																		
 U630	 U2430 Square	 U2020 Square	<table><tr><th colspan="2">Colors</th></tr><tr><td>1</td><td>blue</td></tr><tr><td>2</td><td>black</td></tr><tr><td>3</td><td>green</td></tr><tr><td>4</td><td>gray</td></tr><tr><td>5</td><td>yellow</td></tr><tr><td>6</td><td>red</td></tr><tr><td>7/1</td><td>white</td></tr><tr><td>9</td><td>orange</td></tr></table>	Colors		1	blue	2	black	3	green	4	gray	5	yellow	6	red	7/1	white	9	orange
Colors																					
1	blue																				
2	black																				
3	green																				
4	gray																				
5	yellow																				
6	red																				
7/1	white																				
9	orange																				

DRESS NUTS Chrome plated. Order separately.

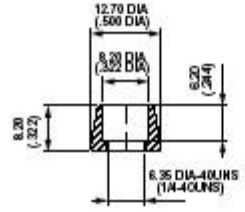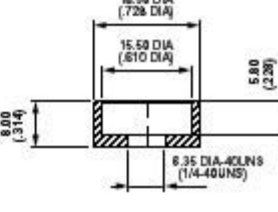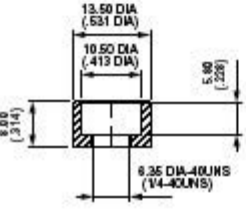 U1636 (for cap U1140)	 U825 (for cap U630)	 U840 (for cap U480)
--	--	---

SPECIAL OPTIONS

F Tin plated terminals (for p.c. terminals only).

X601 Silver plated brass contacts
 Contact ratings: 0.2A 250VAC, 0.4A 125VAC or 0.5A 30VDC
 Electric life: 20,000 cycles minimum.
 Minimum quantity: 5,000 pieces.

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE

C