

Miniature Incandescent Indicators

FOR MOUNTING IN 11/16 CLEARANCE HOLE
6V TO 120V OPERATION



**T-2
WITH TELEPHONE
SLIDE BASE
(PSB type)**

See lamp ratings
on page J.




MATERIALS AND FINISHES

- **Mounting Bushing and Lens Holder:** Brass, white nickel finish. Optional—polished chrome.
- **Mounting Nut:** Steel, cadmium plated with yellow iridescent chromate finish.
- **Internal-tooth Lockwasher:** Steel, cadmium plated with yellow iridescent chromate finish.
- **Terminals:** Amp Connector No. 42198-2. Brass, white nickel finish. Leads may be soldered through holes provided in the contacts.
- **Lens Cap:** (52—, 95—, 135— Series)—High temperature plastic.

NOTE: To specify optional polished chrome finish, change the first digit of the catalog number suffix from "1" to "3". Example: 135-1059-3273-302.


WITH SCREW-IN LENS CAPS

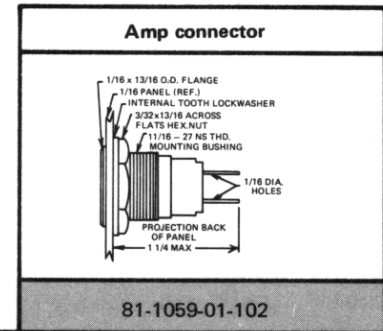


**95 SERIES
52 SERIES
135 SERIES
81 SERIES**

BASE PART NUMBER


81-1059-01-102

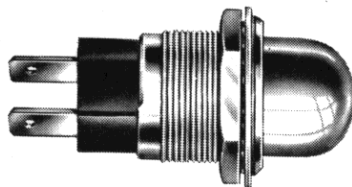


95-1059-3171-102 Stovepipe lens

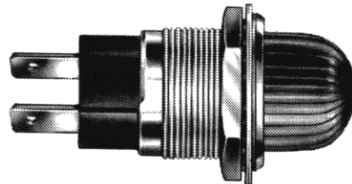


52-1059-3191-102 Stovepipe lens

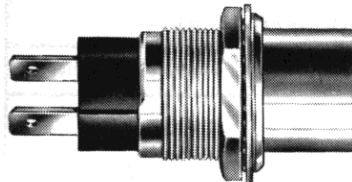

135-1059-3271-102 Cylindrical lens

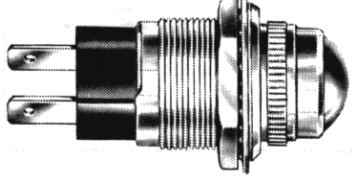

81-1059-0111-102 Convex lens

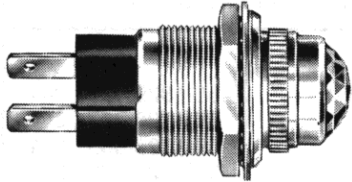

81-1059-0431-102 Faceted lens

CAP PART NUMBERS

COMPLETE ASSEMBLY PART NUMBERS

BASE PART NUMBER	CAP PART NUMBERS	COMPLETE ASSEMBLY PART NUMBERS
95-1059-3171-102	STOVEPIPE 95-3171 translucent	95-1059-3171-102
52-1059-3191-102	STOVEPIPE 52-3191 internal fluting	52-1059-3191-102
135-1059-3271-102	CYLINDRICAL 135-3271 translucent	135-1059-3271-102
81-1059-0111-102	CONVEX 81-0111-100 back frosted	81-1059-0111-102
81-1059-0431-102	FACETED 81-0431-100 unfrosted	81-1059-0431-102

Part numbers shown in gray are normally in inventory at your Dialight Distributor.

Order complete with lamp to be assured of receiving the indicator light and correct lamp together for immediate use.

For legends on flat faced lens, see page P.