


# HORIZONTAL & MODIFIED HEADERS

(2.00 mm) .0787" PITCH • MMT/MTMM SERIES

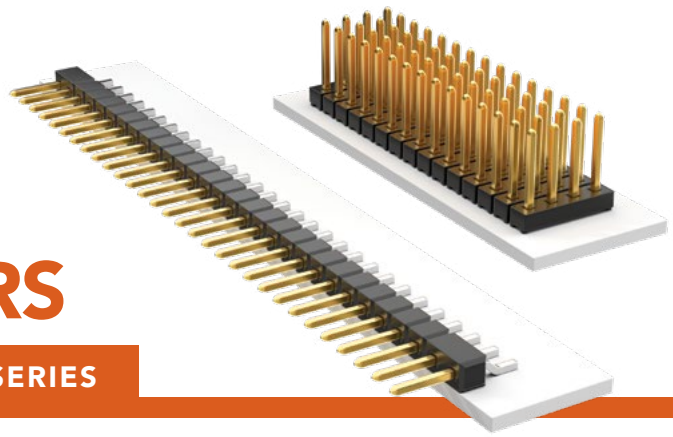

## MMT/MTMM

### Board Mates:

CLT, SQT\*, SQW, ESQT, TLE, SMM, MMS

### Cable Mates:

TCSD

### \*Important Note:

SQT will not mate to the MMT -02 lead style.

## SPECIFICATIONS

### Insulator Material:

Black Liquid Crystal Polymer

### Terminal Material:

Phosphor Bronze

### Plating:

Au or Sn over

50 μ" (1.27 μm) Ni

### Operating Temp Range:

-55 °C to +105 °C with Tin;

-55 °C to +125 °C with Gold

## PROCESSING

### Lead-Free Solderable:

Yes

### SMT Lead Coplanarity (MMT):

(0.10 mm) .004" max (02-25)

(0.15 mm) .006" max (26-36)\*

\*(.004" stencil solution

may be available; contact

ipg@samtec.com)

MMT	1	NO. PINS PER ROW	LEAD STYLE	PLATING OPTION	ROW OPTION	OPTION
		02 thru 36	-01 = (3.20 mm) .126" post  -02 = (4.45 mm) .175" post	-F = Gold flash on post, Matte Tin on tail  -L = 10 μ" (0.25 μm) Gold post, Matte Tin on tail  -T = Matte Tin	-SH = Single Row  -DH = Double Row  -MT = Double Row Mixed Technology	-K = (4.00 mm) .157" DIA Polyimide Film Pick & Place Pad (3 positions min.)  -P = Pick & Place Pad (2 positions min.)  -"XXX" = Polarized Position Specify position of omitted pin  -TR = Tape & Reel  -FR = Full Reel Tape & Reel (must order max. quantity per reel; contact Samtec for quantity breaks)

**ALSO AVAILABLE**  
 MOQ Required  
 Alignment pins  
 Locking clips  
 Molded pick & place pads

MTMM	1	NO. PINS PER ROW	LEAD STYLE	PLATING OPTION	ROW OPTION	POST HEIGHT	OPTION
		01 thru 50	Specify LEAD STYLE from chart	-F = Gold flash on post, Matte Tin on tail  -L = 10 μ" (0.25 μm) Gold post, Matte Tin on tail  -T = Matte Tin	-S = Single Row  -D = Double Row  -Q = Quad Row	- "XXX" = Post Height in inches (0.13 mm) .005" increments  Example: -070 = (1.78 mm) .070"	- "XXX" = Polarized Position Specify position of omitted pin

LEAD STYLE	OAL
-02	(6.48) .255
-03	(7.67) .302
-04	(8.20) .323
-05	(9.58) .377
-06	(10.08) .397
-07	(11.58) .456
-08	(12.09) .476
-09	(13.59) .535
-10	(14.10) .555
-11	(15.09) .594
-12	(15.60) .614
-13	(17.09) .673
-14	(19.08) .751
-15	(21.08) .830

### Note:

Some lengths, styles and options are non-standard, non-returnable.