

WRTP Series Weatherproof Double-pole Rocker Switches

Approvals

UL recognized; CSA approved; VDE approval pending.
Load rating: 20A 125/250 VAC. 3/4 HP, 125/250 VAC. 14A 14VDC. Contacts: fine silver for long life dependability.
Dielectric strength: 1250 volts (live parts to ground).
Life: 35,000 operations at maximum rating.
Insulation resistance: 5 megohms.

Water & Dust Resistance

Designed to meet IP-64.

High Inrush

125 Amp inrush capability (AgNi contacts).

Low Level Control

For low level/dry circuit applications (<100 am) contact factory for part number.

Terminals

Style A - 1/4-inch quick-connect

Mechanical Features

100,000 mechanical operations

Markings

 
 
 
 
 
 
 
 
 
 
 
 
 
 
 
 
 
 
 
 
 
 
 
Letters, numbers and symbols can be applied to rocker actuator or to integral nylon bezel; see inside back cover for details.



Mounting

Snap-in type panel mounting for ease of installation without additional mounting hardware.

Lighted Types

Please inquire.

Circuit	Switching			
11	DPST Maintained			
22	DPDT Maintained			
33	DPDT Maintained Center Off			
44	DPST (Momentary) Normally Open			
55	DPDT (Momentary) Normally Closed			
66	DPDT (Momentary) Transfer			
77	DPDT Maintained Center Off (Momentary)			
88	DPDT (Momentary) Center Off (Momentary)			

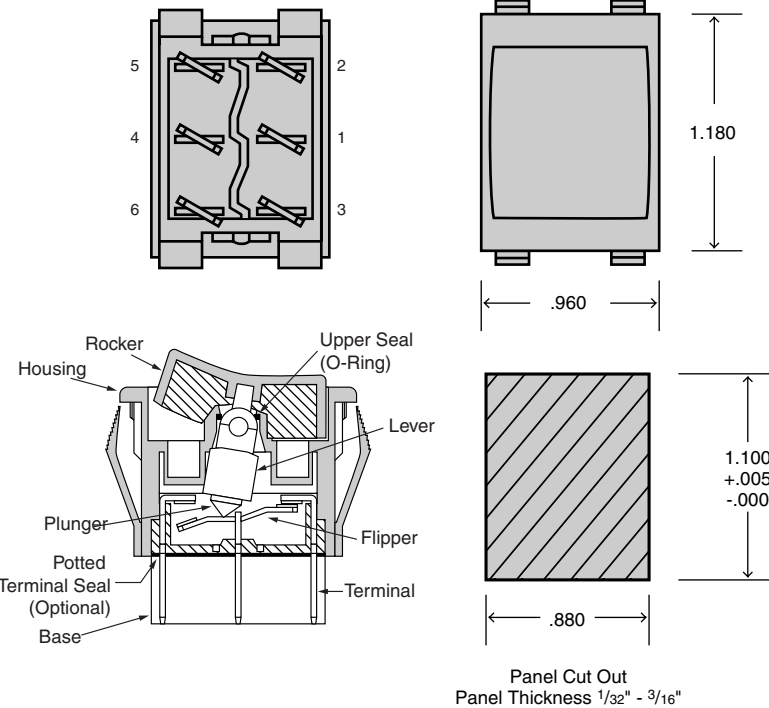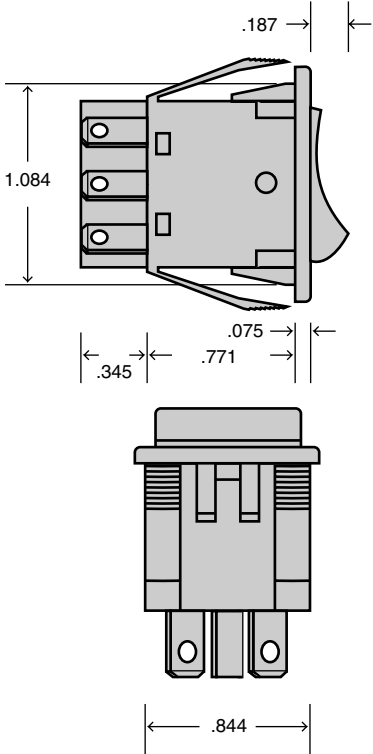

Ordering Information:

WRTP



 
Circuit

11=DPST Maintained
22=DPDT Maintained
33=DPDT Maintained Center Off
44=DPST (Momentary) Normally Open
55=DPST (Momentary) Normally Closed
66=DPDT (Momentary) Transfer
77=DPDT Maintained Center Off (Momentary)
88=(Momentary) Center Off (Momentary)




Terminal Option

A=Fine Silver (Normal Duty)
G=Gold Plated Contacts
H=High Inrush Contacts



Actuator Color

 7=White
9=Black
12=Red



Housing Color

M9=Matte Black
(For other colors contact factory)



Accessories (Optional)

B=Protective Barrier
FL=LED Bracket
E=Epoxy Seal
G=Panel Gasket



Phone (203) 272-2794 • Fax (203) 272-3492 • <http://www.osloswitch.com>

MADE IN U.S.A.



Phone (203) 272-2794 • Fax (203) 272-3492 • <http://www.osloswitch.com>

MADE IN U.S.A.