

# Series 804 Push-Pull Mighty Mouse Protective Receptacle Cover

## 667-202 Ordering Information



Accessories

### Protect Connectors From Damage

Machined aluminum covers prevent ingress of contamination and water.

### Stainless Steel Fittings and Rings


Choose small diameter eye fittings for panel attachment. Larger rings fit under the jam nut or over cable jackets. Split rings can be installed on fully assembled cables.

**Polyurethane-Coated SST Wire Rope** offers high strength, excellent abrasion resistance and good flexibility. Or, choose Fluoropolymer jacket for high temperature exposure.

**Braided Nylon Rope** provides excellent flexibility and good abrasion resistance, and can be ordered with slip knot fittings for easy installation on any size cable.

How To Order							
Sample Part Number	667-202	M	9	H	6	-14	R
Series (See Table I)	667-202 = Receptacle Cover						
Shell Material / Finish	<b>C</b> = Aluminum / Black Anodize (Non-Conductive) RoHS Compliant <b>M</b> = Aluminum / Electroless Nickel RoHS Compliant <b>NF</b> = Aluminum / Cadmium with Olive Drab Chromate <b>ZN</b> = Aluminum / Zinc-Nickel with Olive Drab Chromate <b>ZNU</b> = Aluminum / Zinc-Nickel with Black Chromate <b>MT</b> = Aluminum / Nickel-PTFE RoHS Compliant <b>Z1</b> = Stainless Steel / Passivated RoHS Compliant						
Shell Size	5, 6, 7, 8, 9, 10, 11, 12, 14,						
Attachment Type	<b>D</b> = Bead Chain, CRES, Passivate <b>F</b> = Wire Rope, Nylon Jacket <b>G</b> = Nylon Rope <b>H</b> = SST Wire Rope, Fluoropolymer Jacket <b>N</b> = No Attachment <b>R</b> = Wire Rope, PVC Jacket <b>S</b> = SST Sash Chain <b>SK</b> = Nylon Rope With Slip Knot <b>T</b> = SST Wire Rope, No Jacket <b>U</b> = SST Wire Rope, Polyurethane Jacket  "SST" = Stainless Steel						
Attachment Length (inches)	Omit for attachment type <b>N</b> (No Attachment) Example: "-6" equals six inch length						
Attachment Code (See Table II)	Small Ring = <b>01</b> thru <b>06</b> Large Ring = <b>14</b> thru <b>33</b> Split Ring = <b>50</b> thru <b>68</b>						
Pull Ring Option	<b>R</b> = Supplied with Pull Ring (Omit for none)						

 Table I: Cover Style



667-202  
Push Pull Receptacle  
Cover with Pull Ring


Table II: Attachment Code

Omit for attachment types **N** (No Attachment) and **SK** (Slip Knot)




Small Ring

 **-01** - .126 (3.20) I.D.  
**-02** - .145 (3.68) I.D.  
**-04** - .188 (4.78) I.D.  
**-06** - .197 (5.00) I.D.



Large Ring

**-15** - .445 (11.3) I.D.  
**-33** - .510 (13.0) I.D.  
**-17** - .635 (16.1) I.D.  
**-18** - .695 (17.7) I.D.  
**-27** - .766 (19.4) I.D.  
**-31** - .820 (20.) I.D.  
**-19** - .885 (22.5) I.D.  
**-28** - 1.015 (25.8) I.D.  
**-20** - 1.135 (28.8) I.D.

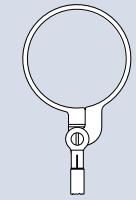

Split Ring

**-50** - .420 (10.67) I.D.  
**-52** - .480 (12.19) I.D.  
**-54** - .635 (16.13) I.D.  
**-56** - .745 (18.92) I.D.  
**-58** - .885 (22.48) I.D.  
**-60** - 1.010 (25.65) I.D.  
**-64** - 1.125 (28.58) I.D.  
**-68** - 1.345 (34.16) I.D.

Dimensions in Inches (millimeters) are subject to change without notice.