 


Miniature Incandescent Indicators



T-3 1/4
MINIATURE
BAYONET BASE

See lamp ratings
on page K.

Recognized under the component
program of Underwriters'
Laboratories Inc.

75W., 125V.




How to designate the three digit part number suffix (-XXX)

FINISH	RESISTOR	HARDWARE
1 - White nickel	0 - None	1 - Brass
2 - Black nickel		3 - Water-tight, on the face of the panel.
3 - Polished chrome		
4 - Satin chrome		

NOTE: The part numbers given in this catalog indicate **standard** indicator lights. The table above provides the standard and optional designations for **Finish** and **Hardware** where appropriate. Example: 95-1310-0931-203 (black nickel finish with water-tight construction).

Part numbers listed in this catalog designate products with **RED** lens.
For ordering lens colors other than red, consult chart on page 2D.

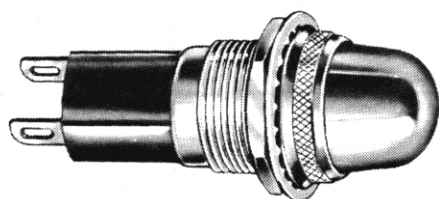

26-0410-1111-301
Screw-in lens cap

26 SERIES

BASE PART NUMBERS

WITH SCREW-IN LENS CAPS

solder terminals	screw terminals	quick connect terminals
1/16 x 13/16 O.D. FLANGE 1/16 PANEL (REF.) .030 : .005 x .61 : .64 : .010 O.D. INTERNAL TOOTH LOCKWASHER 3/32 x 13/16 ACROSS FLATS HEX. NUT 11/16 27 NS THD. MOUNTING BUSHING * SIGN MARKED ON THE TERMINAL CONNECTED TO THE CENTER CONTACT 5/64 x 1/8 SLOTS PROJECTION BACK OF PANEL 1/41/64 MAX.	1/16 DIA. HOLES SCREWS No. 4-36 THD.	1/16 DIA. HOLES
26-0410-11-301	26-1310-11-301	26-5710-11-301
COMPLETE ASSEMBLY PART NUMBERS		
26-0410-1131-301	26-1310-1131-301	26-5710-1131-301
26-0410-1191-301	26-1310-1191-301	26-5710-1191-301
26-0410-1111-301	26-1310-1111-301	26-5710-1111-301

These assemblies should be specified when lamps rated
over 2 watts are used.

Part numbers shown in gray are normally
in inventory at your Dialight Distributor.