


JTG06R (MS27484) — crimp
straight plug (with grounding fingers)

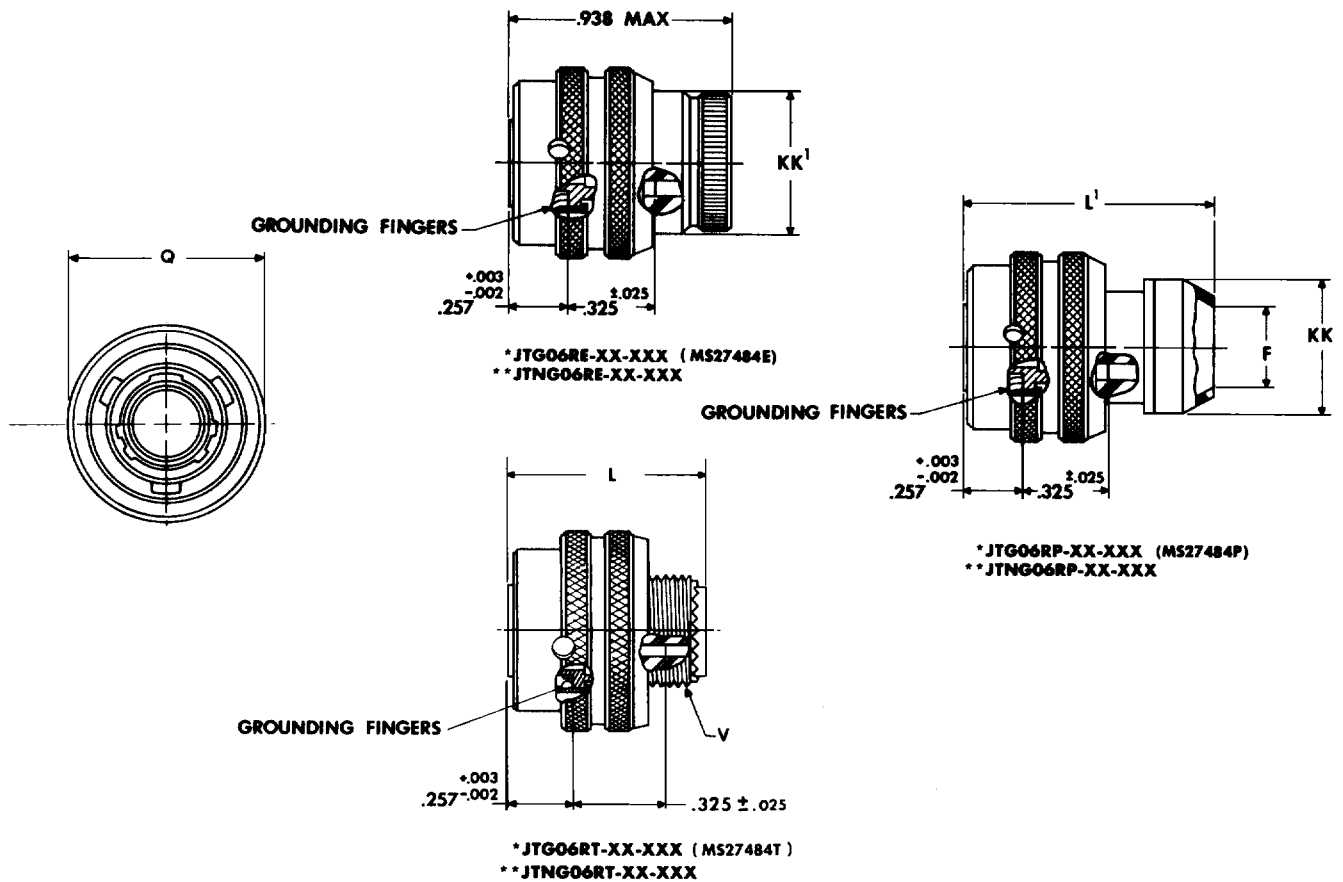

** Clear iridite finish (gold color), N₂O₄ resistant, to complete order number see page 47.

** Clear iridite finish (gold color), N₂O₄ resistant, to complete order number see page 47.

Shell Size	L Max.	L ¹ Max.	Q Dia. Max.	KK Dia. Max.	KK ² Max.	F Dia.	V Thread Modified	
							Class 2A	Modified Major Dia.
8	.891	1.000	.734	.625	.578	.444	.4375-28UNEF	.421- .417
10	.891	1.000	.844	.750	.703	.558	.5625-24UNEF	.542- .538
12	.891	1.000	1.016	.875	.828	.683	.6875-24UNEF	.667- .663
14	.891	1.000	1.141	1.000	.953	.808	.8125-20UNEF	.791- .787
16	.891	1.000	1.265	1.125	1.078	.909	.9375-20UNEF	.916- .912
18	.891	1.000	1.391	1.250	1.203	1.034	1.0625-18UNEF	1.034-1.030
20	.891	1.000	1.500	1.375	1.328	1.159	1.1875-18UNEF	1.158-1.154
22	.891	1.000	1.625	1.500	1.453	1.284	1.3125-18UNEF	1.283-1.279
24	.891	1.062	1.750	1.625	1.578	1.409	1.4375-18UNEF	1.408-1.404

All dimensions for reference only.