



T-3 1/4
MINIATURE
BAYONET BASE

See lamp ratings
on page K.

Recognized under the component
program of Underwriters'
Laboratories Inc.

75W., 125V.




Miniature Incandescent Indicators

WITH LIGHT SHIELD LENS CAPS
FOR MOUNTING IN 11/16" CLEARANCE HOLE
FOR 2 TO 120V OPERATION

MATERIAL AND FINISHES

- **Mounting Bushing and Light Shield Cap:** Standard—brass polished chrome finish. Optional—black nickel or satin chrome finish.
- **Mounting Nut:** Brass, white nickel finish.
- **Internal-tooth Lockwasher:** Phosphor bronze, white nickel finish.
- **Terminals:** Solder — brass, hot tinned with elongated slot. Screw—brass, white nickel finish.

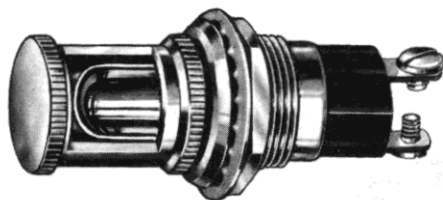

21-1310-2900-301

PUSH-IN CAPS

21 SERIES
22 SERIES
89 SERIES
90 SERIES

BASE PART NUMBERS

solder terminal	screw terminal
21-0410-29-301	21-1310-29-301

CAP PART NUMBERS	COMPLETE ASSEMBLY PART NUMBERS	
	PUSH-IN CAP with SNAP LOCK 21-2900-300 one opening, 1/2"x1/2"	21-0410-2900-301
	PUSH-IN CAP with SNAP LOCK 22-2900-300 one opening, 3/32"x1/2"	22-0410-2900-301
	PUSH-IN CAP with SNAP LOCK 89-2900-300 one opening, 3/16"x9/16"	89-0410-2900-301
	PUSH-IN CAP with SNAP LOCK 90-2900-300 one opening, 3/16"x1/2"	90-0410-2900-301

Part numbers shown in gray are normally
in inventory at your Dialight Distributor.

Order complete with lamp to be assured of receiving the
indicator light and correct lamp together for immediate use.